


FLAT BARS
フラットバー
—ミガキ平鋼—

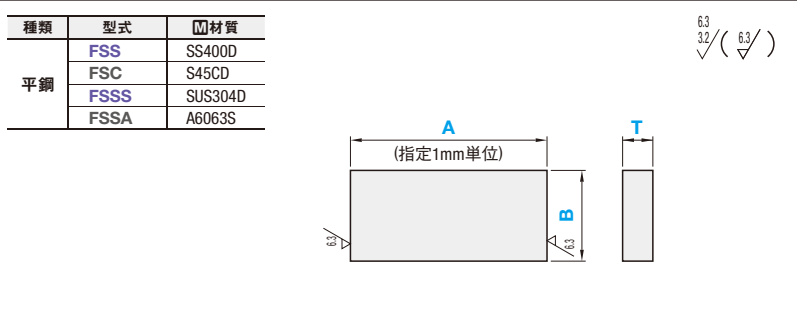

Price 価格 (例) FSS-250-32-9のとき
A寸法 × 面積単価 = 価格(1円単位は切捨)
250 × 3.7 = 920(円)

数量スライド価格 (1円単位切り捨て) P89
数量 1~4 5~19 20以上
値引率 基準単価 5% (表示数量を超えは
お見積り)

■ FSS (材質SS400D) 価格

A 1mm単位	T	5	6	9	10	12	16	19	22	25	30
30~50	16	AX12.4	AX12.4	AX12.5	AX12.3	AX12.6	AX12.7	—	—	—	—
51~150	16	AX 6	AX 6	AX 6.1	AX 6.1	AX 6.2	AX 6.3	—	—	—	—
151~300	16	AX 3.4	AX 3.4	AX 3.5	AX 3.5	AX 3.6	AX 3.6	—	—	—	—
301~800	16	AX 2.5	AX 2.5	AX 2.4	AX 2.5	AX 2.4	AX 2.1	—	—	—	—
30~50	22	AX12.4	AX12.5	AX12.6	AX12.4	AX12.7	AX12.9	AX13.1	—	—	—
51~150	22	AX 6.1	AX 6.1	AX 6.2	AX 6.2	AX 6.3	AX 6.5	AX 6.6	—	—	—
151~300	22	AX 3.4	AX 3.5	AX 3.6	AX 3.6	AX 3.6	AX 4.7	AX 4.8	—	—	—
301~800	22	AX 2.5	AX 2.4	AX 2.4	AX 2.3	AX 2.3	AX 3.3	AX 3.5	—	—	—
30~50	25	AX12.5	AX12.5	AX12.7	AX12.6	AX12.8	AX13	AX13.2	AX14.4	—	—
51~150	25	AX 6.1	AX 6.1	AX 6.2	AX 6.2	AX 6.4	AX 6.5	AX 7.3	AX 7.9	—	—
151~300	25	AX 3.5	AX 3.5	AX 3.7	AX 3.6	AX 3.7	AX 4.8	AX 5	AX 5.8	—	—
301~800	25	AX 2.4	AX 2.4	AX 2.3	AX 2.2	AX 2.2	AX 3.3	AX 3.4	AX 4.4	—	—
30~50	32	AX12.5	AX12.6	AX12.8	AX12.7	AX13	AX13.3	AX13.5	AX14.8	AX15	—
51~150	32	AX 6.2	AX 6.2	AX 6.3	AX 6.4	AX 6.5	AX 6.7	AX 7.6	AX 8.2	AX 8.9	—
151~300	32	AX 3.5	AX 3.6	AX 3.7	AX 3.7	AX 4.8	AX 4.5	AX 4.7	AX 6.2	AX 6.4	—
301~800	32	AX 2.5	AX 2.4	AX 2.2	AX 3.4	AX 3.2	AX 3.3	AX 3.5	AX 4.2	AX 4.4	—
30~50	38	AX12.6	AX12.7	AX12.9	AX13.2	AX13.5	AX13.7	AX15.1	AX15.3	—	—
51~150	38	AX 6.2	AX 6.2	AX 6.4	AX 6.5	AX 6.6	AX 6.9	AX 7.8	AX 8.4	AX 9.2	—
151~300	38	AX 3.6	AX 3.7	AX 4.7	AX 4.8	AX 4.6	AX 5.7	AX 5.9	AX 5.4	AX 5.6	—
301~800	38	AX 2.4	AX 2.3	AX 3.3	AX 3.2	AX 3.3	AX 4.3	AX 4.6	AX 5.4	AX 5.7	—
30~50	50	AX12.8	AX12.8	AX13.1	AX13.1	AX13.5	AX13.9	AX14.2	AX15.7	AX16	AX17.6
51~150	50	AX 6.3	AX 6.4	AX 6.6	AX 6.7	AX 6.9	AX 7.9	AX 8.2	AX 9.5	AX10.4	AX11.8
151~300	50	AX 3.6	AX 3.7	AX 4.6	AX 4.5	AX 5.7	AX 5.6	AX 5.3	AX 6.7	AX 7.1	AX 7.7
301~800	50	AX 2.3	AX 2.2	AX 3.3	AX 3.3	AX 4.3	AX 4.1	AX 4.4	AX 6	AX 5.3	AX 5.8
30~50	60	—	AX14	AX14.3	AX14.3	AX14.7	AX15.2	AX15.6	—	AX16.6	—
51~150	60	—	AX 6.8	AX 7.1	AX 7.8	AX 8.1	AX 8.9	AX10	—	AX10.9	—
151~300	60	—	AX 4.9	AX 4.7	AX 5.6	AX 5.7	AX 5.5	AX 5.8	—	AX 8.7	—
301~800	60	—	AX 3.4	AX 3.3	AX 4.2	AX 4.3	AX 5.5	AX 5.8	—	AX 5.7	—
30~50	75	—	AX12.9	AX13.3	AX13.5	AX14.2	AX15.2	AX15.6	AX17.1	AX18	AX19.6
51~150	75	—	AX 6.7	AX 8	AX 8.2	AX 8.9	AX10.3	AX11.1	AX12	AX12.4	AX13.8
151~300	75	—	AX 4.6	AX 4.9	AX 5.5	AX 5.7	AX 7.1	AX 7.9	AX 9	AX 9.4	AX10.6
301~800	75	—	AX 3.4	AX 4.2	AX 4.3	AX 4.5	AX 5.9	AX 6.2	AX 7.2	AX 7.6	AX 8.7
30~50	100	—	AX18.6	AX19.8	AX19.9	AX20.5	AX21.3	AX22.5	AX26.1	AX28.1	AX32.2
51~150	100	—	AX 8.6	AX 9.8	AX 9.8	AX11	AX12.6	AX14.2	AX16.7	AX17.9	AX21.2
151~300	100	—	AX 7.1	AX 6.2	AX 7.4	AX 7.3	AX 9.3	AX10.3	AX12.5	AX13.6	AX16.1
301~800	100	—	AX 5.2	AX 5.6	AX 5.4	AX 5.2	AX 7	AX 7.9	AX10	AX11.1	AX13
30~50	125	—	AX21.2	AX22.8	—	AX23.6	AX24	AX26.9	AX31	AX33.1	AX37.9
51~150	125	—	AX10.1	AX11.5	—	AX13	AX14.9	AX15.8	AX18.5	AX20.5	AX23.5
151~300	125	—	AX 6.8	AX 7.7	—	AX 9.3	AX11.1	AX12.6	AX14.9	AX16.5	AX18.4
301~800	125	—	AX 4.6	AX 5.2	—	AX 7	AX 8.6	AX 9.9	AX11.9	AX13.6	AX16.3

■ FSC (材質S45CD) 価格

A 1mm単位	T	5	6	9	12	16	19	22	25	30
30~50	16	AX12.8	AX13.1	AX13.2	AX13.3	AX13.5	—	—	—	—
51~150	16	AX 6.7	AX 6.8	AX 6.8	AX 6.9	AX 7.1	—	—	—	—
151~300	16	AX 3.4	AX 3.5	AX 3.5	AX 3.6	AX 4.7	—	—	—	—
301~800	16	AX 2.4	AX 2.4	AX 2.3	AX 2.3	AX 3.2	—	—	—	—
30~50	22	AX12.9	AX13.2	AX13.3	AX13.4	AX13.7	—	—	—	—
51~150	22	AX 6.8	AX 6.9	AX 6.9	AX 7	AX 7.3	—	—	—	—
151~300	22	AX 3.5	AX 3.6	AX 3.7	AX 4.7	AX 4.6	—	—	—	—
301~800	22	AX 2.5	AX 2.4	AX 2.3	AX 3.3	AX 3.2	—	—	—	—
30~50	25	AX13.2	AX13.3	AX13.4	AX13.5	AX13.8	AX14.1	AX15.4	—	—
51~150	25	AX 6.8	AX 6.9	AX 7	AX 7.1	AX 7.4	AX 7.6	AX 8.7	—	—
151~300	25	AX 3.6	AX 3.6	AX 3.7	AX 4.8	AX 4.7	AX 4.9	AX 5.3	—	—
301~800	25	AX 2.4	AX 2.4	AX 2.3	AX 3.3	AX 3.3	AX 3.5	AX 4.8	—	—
30~50	32	—	AX13.4	AX13.5	AX13.7	AX14.1	AX14.4	AX15.9	AX16.2	—
51~150	32	—	AX 7	AX 7.1	AX 7.3	AX 7.6	AX 7.9	AX 9.1	AX 9.9	—
151~300	32	—	AX 3.8	AX 4.8	AX 4.6	AX 5.5	AX 5.6	AX 5.5	AX 5.7	—
301~800	32	—	AX 2.4	AX 3.3	AX 3.2	AX 4.4	AX 4.2	AX 5.2	AX 5.5	—
30~50	38	—	AX13.5	AX13.7	AX13.9	AX14.3	AX14.7	AX16.3	AX16.6	—
51~150	38	—	AX 7.1	AX 7.2	AX 7.4	AX 7.8	AX 8.1	AX 9.4	AX10.3	—
151~300	38	—	AX 3.9	AX 4.5	AX 4.5	AX 5.4	AX 5.7	AX 6.4	AX 6.7	—
301~800	38	—	AX 2.4	AX 3.2	AX 3.1	AX 4.2	AX 4.5	AX 5	AX 5.2	—
30~50	50	—	AX13.7	AX13.9	AX14.2	AX14.9	AX15.3	AX17.1	AX17.5	AX19.3
51~150	50	—	AX 7.3	AX 7.5	AX 7.7	AX 8.7	AX 9.1	AX10.7	AX11.5	AX13.2
151~300	50	—	AX 5	AX 4.5	AX 5.3	AX 5.4	AX 5.6	AX 7.5	AX 8.4	AX 9.2
301~800	50	—	AX 3.5	AX 3.3	AX 4.1	AX 5	AX 5.4	AX 5.5	AX 6.5	AX 7.1
30~50	60	—	AX15	AX15.2	AX15.5	AX16.3	AX16.8	—	AX18.2	—
51~150	60	—	AX 7.8	AX 8	AX 8.8	AX 9.9	AX10.5	—	AX12.1	—
151~300	60	—	AX 5	AX 5.8	AX 5.5	AX 6.5	AX 6.8	—	AX10.1	—
301~800	60	—	AX 3.5	AX 4.3	AX 5.1	AX 5.1	AX 5.4	—	AX 7.5	—
30~50	75	—	AX13.7	AX14	AX14.8	AX16.1	AX16.6	AX18.4	AX19.4	AX21.2
51~150	75	—	AX 7.5	AX 8.7	AX 9.5	AX11.1	AX11.6	AX13.2	AX13.7	AX15.3
151~300	75	—	AX 4.8	AX 5.5	AX 6.3	AX 7.9	AX 8.4	AX10.2	AX11.1	AX12.5
301~800	75	—	AX 3.6	AX 4.3	AX 5.1	AX 6.7	AX 7.1	AX 8.4	AX 9.3	AX10.6
30~50	100	—	AX20.1	AX20.9	AX20.5	AX21.8	AX23.5	AX27.8	AX33	AX37.9
51~150	100	—	AX10.1	AX10.6	AX11.5	AX13.5	AX15	AX19.5	AX19.4	AX23.1
151~300	100	—	AX 7.4	AX 7.1	AX 7.9	AX10.1	AX11.5	AX14.6	AX16.4	AX19
301~800	100	—	AX 5.4	AX 5.5	AX 5.8	AX 8	AX 9.4	AX11.8	AX13.8	AX16.1
30~50	125	—	AX23.1	AX24.1	AX23.7	AX25.8	AX27.8	—	AX37.6	—
51~150	125	—	AX11.6	AX12.2	AX13.3	AX15.7	AX17.5	—	AX22.2	—
151~300	125	—	AX 7.2	AX 8.6	AX 9.9	AX12	AX13.8	—	AX19.8	—
301~800	125	—	AX 6.3	AX 6.1	AX 7.5	AX 9.6	AX11.4	—	AX16	—

■ FSSS (材質SUS304D) 価格

A 1mm単位	T	5	6	9	10	12	16	19	22	25	30
30~50	15	AX19.7	AX20.2	AX21.1	—	—	—	—	—	—	—
51~150	15	AX11.1	AX11.3	AX11.6	—	—	—	—	—	—	—
151~300	15	AX 5	AX 5.1	AX 5.5	—	—	—	—	—	—	—
301~800	15	AX 3.2	AX 3.3	AX 3.6	—	—	—	—	—	—	—
30~50	20	AX19.9	AX20.5	AX21.5	AX21.7	AX22.5	AX23.3	—	—	—	—
51~150	20	AX11.3	AX11.5	AX12	AX12.2	AX12.9	AX13.6	—	—	—	—
151~300	20	AX 5.2	AX 5.3	AX 5.8	AX 6	AX 6.7	AX 7.8	—	—	—	—
301~800	20	AX 3.3	AX 3.5	AX 4.4	AX 4.6	AX 5.2	AX 6.3	—	—	—	—
30~50	25	AX20.2	AX20.8	AX21.9	AX22.2	AX23.1	AX24	AX25.7	—	AX28.9	—
51~150	25	AX11.5	AX11.8	AX12.4	AX12.6	AX13.4	AX14.2	AX16.1	—	AX16.8	—
151~300	25	AX 5.4	AX 5.6	AX 6.2	AX 7.3	AX 7.7	AX 8.9	AX11.3	—	AX13.6	—
301~800	25	AX 3.5	AX 3.7	AX 5.1	AX 5.3	AX 6.2	AX 7.4	AX 9.7	—	AX12.3	—
30~50	32	AX20.5	AX21.2	AX22.5	AX22.8	AX23.9	AX25.1	AX27.1	AX30.4	AX31.7	—
51~150	32	AX11.8	AX12.1	AX12.9	AX13.1	AX14.1	AX15.2	AX18.3	AX19.8	AX20.9	—
151~300	32	AX 5.6	AX 5.9	AX 7.6	AX 7.8	AX 8.8	AX10.6	AX14.1	AX16.1	AX17.3	—
301~800	32	AX 3.8	AX 4.5	AX 6.1	AX 6.3	AX 7.3	AX 9.1	AX11.9	AX13.8	AX14.8	—
30~50	38	AX20.8	AX21.5	AX23	AX23.4	AX24.5	AX25.9	AX29.2	AX32.7	AX34.2	—
51~150	38	AX12.1	AX12.4	AX13.3	AX13.6	AX14.7	AX15.9	AX19.4	AX22	AX24.3	—
151~300	38	AX 5.9	AX 6.2	AX 8.5	AX 8.8	AX 9.8	AX12.3	AX16	AX17.3	AX19.7	—
301~800	38	AX 4.5	AX 4.8	AX 6.5	AX 7.2	AX 8.3	AX10.2	AX13.8	AX15.8	AX17	—
30~50	50	AX21	AX21.9	AX24.6	AX25.6	AX27.4	AX31.1	AX34.3	AX39.1	—	—
51~150	50	AX11.6	AX12.4	AX14.9	AX15.7	AX17.3	AX20.5	AX23.4	AX26.4	—	—
151~300	50	AX 8.2</									