

ワイヤーカット用プレート(上下2面研磨)

—標準タイプ・板厚(T)0.01mm指定タイプ—




■精度基準

- 基準面直角度 100mmに対し0.015以下
- 板厚平行度 100mmに対し0.008以下
- 平面度 (板厚T) T5.00~10.00 T10.01~20.00 T20.01~40.00 T40.01~50.00
100mmに対し 0.02 0.015 0.01 0.008



RoHS

STAVAXWP (標準タイプ)
T-STAVAXWP (板厚(T)0.01mm指定タイプ)

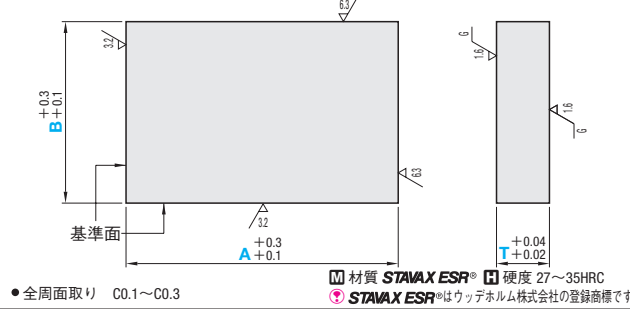

●全周面取り C0.1~C0.3
■材質 STAVAX ESR® ■硬度 27~35HRC
●STAVAX ESR®はウツホルム株式会社の登録商標です。

STAVAXWP 標準タイプ ¥基準単価

型式	A	B	T	5	6	8	10	13	15	20	25	30	35	40	50		
STAVAXWP	20	20	20	2,270	2,270	2,190	1,880	1,890	1,900	1,950	2,000	2,090	2,170	2,230	2,390		
	40			2,510	2,510	2,430	2,120	2,130	2,200	2,320	2,430	2,560	2,660	2,890			
	60			2,740	2,740	2,660	2,340	2,350	2,360	2,480	2,620	2,770	2,920	3,100	3,390		
	80			2,980	2,980	2,890	2,560	2,580	2,590	2,750	2,920	3,110	3,310	3,510	3,900		
	100			3,210	3,210	3,120	2,790	2,800	2,810	3,000	3,230	3,460	3,700	3,940	4,400		
	125			3,950	3,950	3,840	3,430	3,450	3,460	3,670	3,940	4,220	4,490	4,760	5,310		
	150			4,660	4,660	4,540	4,050	4,080	4,090	4,350	4,670	4,970	5,280	5,590	6,190		
	180			5,330	5,330	5,200	4,650	4,680	4,690	4,990	5,360	5,730	6,080	6,450	7,180		
	200			5,770	5,770	5,630	5,040	5,070	5,090	5,440	5,820	6,230	6,630	7,040	7,840		
	40			2,870	2,870	2,790	2,460	2,480	2,490	2,630	2,860	3,090	3,420	3,660	4,070		
	60			3,240	3,240	3,150	2,820	2,840	2,850	3,060	3,380	3,700	4,130	4,450	5,020		
	80			3,600	3,600	3,520	3,180	3,200	3,210	3,460	3,870	4,290	4,850	5,270	6,000		
	100			3,990	3,990	3,900	3,560	3,580	3,590	3,890	4,390	4,900	5,550	6,060	6,960		
	125			4,810	4,810	4,700	4,300	4,320	4,340	4,700	5,310	5,940	6,740	7,360	8,430		
	150			5,620	5,620	5,500	5,030	5,060	5,080	5,520	6,240	6,980	7,920	8,660	9,880		
	180	6,440	6,440	6,310	5,780	5,820	5,840	6,370	7,230	8,100	9,240	10,110	11,560				
	200	7,020	7,020	6,880	6,320	6,350	6,380	6,950	7,900	8,870	10,100	11,070	12,670				
	250	-	-	-	7,760	7,810	7,840	8,550	9,720	10,920	12,440	13,640	15,630				
	300	-	-	-	8,970	9,020	9,060	9,900	11,300	12,730	14,530	15,960	18,330				
	60	3,740	3,740	3,650	3,320	3,340	3,350	3,620	4,080	4,520	5,130	5,590	6,490				
	80	4,270	4,270	4,180	3,830	3,860	3,870	4,220	4,780	5,360	6,120	6,700	7,850				
	100	4,780	4,780	4,690	4,330	4,360	4,380	4,810	5,490	6,200	7,110	7,820	9,220				
	125	5,720	5,720	5,620	5,210	5,240	5,260	5,760	6,620	7,490	8,590	9,470	11,220				
	150	6,650	6,650	6,530	6,070	6,100	6,130	6,740	7,760	8,790	10,080	11,110	13,180				
	180	7,680	7,680	7,550	7,030	7,070	7,100	7,820	9,020	10,240	11,780	13,020	15,460				
	200	8,350	8,350	8,220	7,660	7,710	7,740	8,550	9,890	11,220	12,930	14,290	16,980				
	250	-	-	-	9,450	9,510	9,550	10,520	12,170	13,850	15,940	17,620	20,970				
	300	-	-	-	10,990	11,060	11,100	12,280	14,250	16,240	18,730	20,710	24,710				
	80	4,930	4,930	4,840	4,480	4,510	4,530	4,980	5,700	6,440	7,390	8,150	9,630				
	100	5,590	5,590	5,500	5,130	5,160	5,180	5,720	6,630	7,520	8,680	9,600	11,420				
125	6,710	6,710	6,600	6,180	6,220	6,240	6,900	7,980	9,100	10,500	11,630	13,860					
150	7,810	7,810	7,680	7,200	7,250	7,270	8,050	9,350	10,680	12,340	13,650	16,320					
180	9,020	9,020	8,890	8,350	8,410	8,440	9,370	10,900	12,480	14,440	16,010	19,150					
200	9,830	9,830	9,680	9,120	9,170	9,210	10,250	11,940	13,680	15,850	17,580	21,050					
250	-	-	-	11,270	11,340	11,380	12,650	14,750	16,900	19,570	21,730	26,030					
300	-	-	-	13,170	13,250	13,300	14,820	17,340	19,890	23,070	25,640	30,770					
100	6,430	6,430	6,330	5,940	5,980	6,000	6,660	7,740	8,870	10,260	11,370	13,590					
125	7,690	7,690	7,580	7,140	7,180	7,210	8,010	9,360	10,710	12,410	13,790	16,520					
150	8,960	8,960	8,830	8,340	8,390	8,420	9,370	10,950	12,580	14,580	16,190	19,430					
180	10,360	10,360	10,230	9,680	9,740	9,780	10,910	12,780	14,700	17,080	19,010	22,840					
200	11,300	11,300	11,150	10,570	10,640	10,680	11,950	14,020	16,120	18,760	20,890	25,120					
250	-	-	-	13,090	13,170	13,220	14,760	17,350	19,960	23,210	25,840	31,100					
300	-	-	-	15,350	15,450	15,510	17,360	20,450	23,560	27,440	30,560	36,830					
125	-	-	-	8,480	8,530	8,560	9,560	11,200	12,870	14,950	16,620	19,980					
150	-	-	-	9,810	9,870	9,910	11,090	13,050	15,010	17,480	19,460	23,430					
180	-	-	-	11,440	11,510	11,560	12,940	15,260	17,610	20,520	22,860	27,590					
200	-	-	-	12,520	12,600	12,650	14,180	16,330	19,340	22,550	25,140	30,350					
250	-	-	-	15,470	15,570	15,630	17,530	20,680	23,900	27,870	31,080	37,530					
300	-	-	-	18,210	18,320	18,390	20,680	24,440	28,260	32,990	36,840	44,510					
150	-	-	-	11,310	11,380	11,420	12,820	15,120	17,450	20,360	22,720	27,410					
180	-	-	-	13,200	13,280	13,330	14,980	17,330	20,490	23,940	26,740	32,310					
200	-	-	-	14,470	14,560	14,610	16,420	19,460	22,520	26,320	29,410	35,580					
250	-	-	-	17,830	17,940	18,010	20,270	24,030	27,820	32,530	36,340	43,980					
300	-	-	-	21,070	21,200	21,280	23,970	28,430	32,970	38,560	43,100	52,210					
180	-	-	-	15,410	15,500	15,560	17,510	20,770	24,060	28,130	31,460	38,090					
200	-	-	-	16,860	16,960	17,030	19,200	22,800	26,430	30,940	34,610	41,930					
250	-	-	-	20,820	20,950	21,030	23,690	28,150	32,670	38,230	42,750	51,840					
300	-	-	-	24,550	24,710	24,800	28,010	33,300	38,690	45,320	50,710	61,510					
200	-	-	-	18,460	18,580	18,650	21,040	25,030	29,050	34,020	38,060	46,160					
250	-	-	-	22,800	22,940	23,030	25,990	30,890	35,890	42,030	47,030	57,060					
300	-	-	-	26,900	27,070	27,170	30,700	36,550	42,510	49,810	55,770	67,720					
250	-	-	-	28,170	28,340	28,450	32,110	38,190	44,380	51,970	58,160	70,570					
300	-	-	-	32,970	33,180	33,300	37,690	44,930	52,280	61,340	68,750	83,520					
300	-	-	-	38,790	39,030	39,180	44,370	53,030	61,800	72,590	81,410	99,050					



Order 注文例

型式	-	A	-	B	-	T	-	(CC・AB・TK)
STAVAXWP	-	100	-	100	-	25	-	
T-STAVAXWP	-	250	-	250	-	20.01	-	



Delivery 出荷日

3 日目発送



Price 価格

■数量スライド価格 (●1円未満切り捨て) P.47
数量 1~4 5~9 10~19 表示数量超は
値引率 基準単価 5% 10% 価格・出荷日お見積り



Alterations 追加工

型式	-	A	-	B	-	T	-	(CC・AB・TK)
T-STAVAXWP	-	250	-	250	-	20.01	-	CC0.5

Alterations	標準・板厚(T)0.01mm指定タイプに適用		
	C寸法変更	A・B寸法公差変更	T寸法公差変更
Code	CC	AB	TK
Spec.	全周の面取り寸法を変更します。 CC0 (面取りなし) CC0.5 (C0.5) CC1 (C1)	A・B寸法の公差を変更します。 Code A・B公差 AB1 +0.02 AB2 ±0.03(規格公差) AB3 ±0.1 AB4 -0.2 AB5 -0.3	T寸法の公差を変更します。 Code T公差 TK1 ±0.10 TK2 ±0.03(規格公差) TK3 ±0.02 TK4 ±0.01 TK5 -0.02
¥/1Code	0	0	0

T-STAVAXWP 板厚(T)0.01mm指定タイプ ¥基準単価

型式	A	B	T	5.00~6.00	6.01~8.00	8.01~10.00	10.01~20.00	20.01~30.00	30.01~40.00	40.01~50.00	
T-STAVAXWP	20	20	20	2,600	2,500	2,150	2,200	2,340	2,480	2,650	
	40			2,870	2,780	2,410	2,480	2,730	2,970	3,210	
	60			3,140	3,040	2,670	2,790	3,110	3,450	3,770	
	80			3,400	3,310	2,930	3,100	3,490	3,910	4,330	
	100			3,670	3,570	3,180	3,380	3,880	4,390	4,890	
	125			4,510	4,390	3,920	4,140	4,730	5,310	5,890	
	150			5,330	5,190	4,630	4,910	5,580	6,220	6,870	
	180			6,100	5,940	5,310	5,630	6,420	7,180	7,970	
	200			6,600	6,430	5,760	6,130	6,990	7,840	8,700	
	40			3,280	3,190	2,820	2,970	3,470	4,080	4,520	
	60			3,700	3,600	3,230	3,450</				