 


NAK55
6F6G
6面サーフェイス


GROUND PLATES

研磨プレート

—標準タイプ・フリーサイズタイプ—



■精度基準
 ●基準面直角度 100mmに対し0.008以下
 ●板厚平行度 100mmに対し0.008以下
 ●平面度 (板厚T) T3.00~10.00 T10.01~20.00 T20.01~40.00 T40.01~50.00
 100mmに対し 0.02 0.015 0.01 0.008

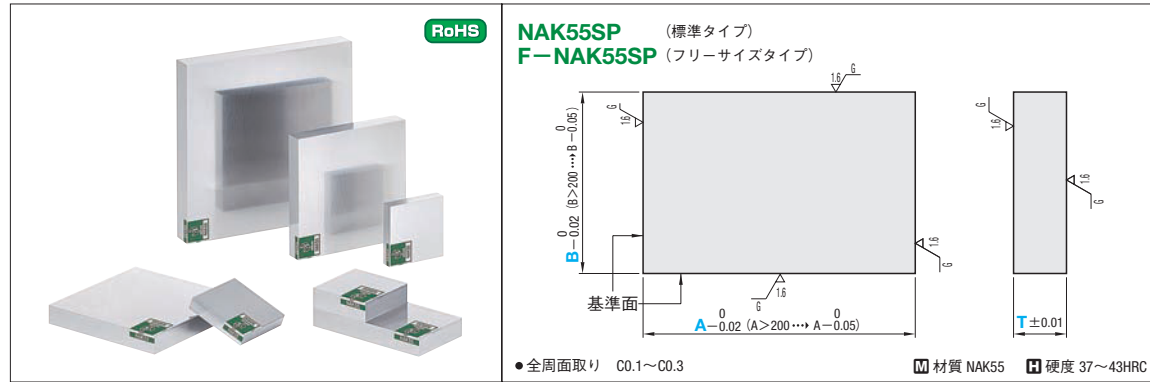

NAK55SP (標準タイプ)
F-NAK55SP (フリーサイズタイプ)

●全周面取り C0.1~C0.3 □材質 NAK55 □硬度 37~43HRC

NAK55SP 標準タイプ ¥基準単価

型式	A	B	T	3	5	6	8	10	13	15	20	25	30	35	40	50	
NAK55SP	10	10	10	3,710	3,490	3,450	3,320	2,830	2,850	2,870	2,890	2,920	2,950	2,970	3,000	3,030	
			20	3,720	3,510	3,470	3,340	2,840	2,860	2,880	2,910	2,930	2,960	2,980	3,010	3,040	
			40	3,760	3,540	3,500	3,370	2,870	2,890	2,910	2,930	2,960	2,980	3,010	3,030	3,060	3,180
			60	3,790	3,570	3,530	3,400	2,890	2,910	2,930	2,960	3,020	3,100	3,170	3,230	3,370	
			80	3,820	3,600	3,560	3,420	2,910	2,940	2,970	3,060	3,140	3,220	3,300	3,390	3,540	
			100	3,870	3,650	3,600	3,470	2,950	3,010	3,070	3,150	3,250	3,350	3,440	3,540	3,720	
	20	20	20	3,740	3,530	3,480	3,350	2,850	2,870	2,890	2,910	2,930	2,960	3,010	3,060	3,170	
			40	3,770	3,560	3,510	3,380	2,880	2,890	2,930	2,990	3,070	3,150	3,230	3,310	3,450	
			60	3,810	3,590	3,550	3,420	2,910	2,980	3,060	3,140	3,240	3,340	3,440	3,550	3,740	
			80	3,910	3,690	3,640	3,510	3,000	3,100	3,190	3,290	3,410	3,530	3,660	3,780	4,020	
			100	4,010	3,790	3,740	3,610	3,090	3,210	3,320	3,440	3,580	3,720	3,870	4,030	4,300	
			125	—	4,230	4,180	4,030	3,460	3,600	3,740	3,870	4,030	4,200	4,370	4,540	4,850	
	40	40	150	—	4,670	4,610	4,450	3,830	3,980	4,150	4,310	4,500	4,680	4,860	5,040	5,380	
			180	—	5,020	4,960	4,790	4,130	4,320	4,520	4,700	4,910	5,130	5,330	5,550	5,960	
			200	—	5,280	5,210	5,030	4,350	4,550	4,760	4,970	5,190	5,430	5,660	5,910	6,350	
			40	3,860	3,640	3,590	3,460	2,950	3,040	3,130	3,220	3,360	3,510	3,660	3,820	4,010	4,260
			60	4,000	3,780	3,740	3,610	3,090	3,220	3,330	3,460	3,650	3,840	4,250	4,450	4,790	
			80	4,160	3,940	3,890	3,760	3,240	3,390	3,530	3,690	3,930	4,170	4,650	4,900	5,330	
	60	60	100	4,310	4,090	4,040	3,900	3,380	3,560	3,750	3,930	4,220	4,510	5,040	5,340	5,860	
			125	—	4,530	4,470	4,330	3,760	3,970	4,200	4,420	4,770	5,130	5,740	6,110	6,720	
			150	—	4,970	4,900	4,750	4,140	4,390	4,660	4,910	5,330	5,750	6,440	6,880	7,560	
			180	—	5,390	5,320	5,160	4,510	4,810	5,100	5,410	5,900	6,400	7,200	7,710	8,520	
			200	—	5,660	5,590	5,420	4,760	5,080	5,420	5,750	6,290	6,840	7,690	8,260	9,150	
			250	—	—	—	—	5,710	6,120	6,530	6,940	7,610	8,290	9,320	10,020	11,130	
	80	80	300	—	—	—	6,480	6,960	7,460	7,940	8,740	9,550	10,760	11,590	12,900		
			60	4,210	3,990	3,940	3,810	3,890	3,910	4,050	4,350	4,400	4,720	5,200	5,430	5,990	
			80	4,410	4,200	4,140	4,010	3,920	4,000	4,160	4,500	4,590	4,900	5,440	5,700	6,320	
			100	4,610	4,390	4,340	4,200	4,000	4,080	4,240	4,640	4,740	5,140	5,700	5,990	6,720	
			125	—	4,860	4,800	4,650	4,320	4,370	4,590	4,980	5,140	5,560	6,210	6,530	7,280	
			150	—	5,320	5,260	5,100	4,600	4,670	4,910	5,360	5,560	6,020	6,720	7,090	7,480	
100	100	180	—	5,810	5,730	5,570	4,870	4,990	5,230	5,720	5,950	6,450	7,200	7,640	8,110		
		200	—	6,130	6,060	5,890	5,170	5,270	5,560	6,100	6,340	6,950	7,750	8,210	8,720		
		250	—	—	—	—	6,030	6,130	6,440	7,040	7,250	7,920	8,800	9,280	9,670		
		300	—	—	—	—	6,880	7,000	7,330	8,000	8,210	8,910	9,860	10,360	10,640		
		40	4,650	4,440	4,380	4,250	4,190	4,260	4,520	4,870	5,060	5,430	6,070	6,400	7,020		
		60	4,910	4,690	4,630	4,500	4,290	4,370	4,630	5,030	5,190	5,650	6,320	6,660	7,070		
125	125	125	—	5,220	5,150	5,010	4,600	4,670	4,960	5,440	5,620	6,160	6,920	7,350	7,800		
		150	—	5,750	5,680	5,530	4,870	5,010	5,280	5,830	6,100	6,660	7,520	7,960	8,530		
		180	—	6,310	6,230	6,060	5,200	5,310	5,650	6,230	6,530	7,170	8,110	8,640	9,280		
		200	—	6,680	6,600	6,430	5,480	5,680	6,000	6,640	7,000	7,680	8,710	9,280	10,020		
		250	—	—	—	—	6,560	6,710	7,110	7,910	8,280	9,120	10,290	10,960	11,750		
		300	—	—	—	—	7,600	7,760	8,240	9,120	9,560	10,530	11,880	12,640	13,510		
150	150	100	5,210	4,990	4,930	4,790	4,580	4,640	4,910	5,400	5,620	6,180	6,950	7,360	7,840		
		125	—	5,580	5,510	5,360	4,870	4,990	5,280	5,870	6,130	6,750	7,620	8,130	8,720		
		150	—	6,170	6,100	5,940	5,200	5,330	5,680	6,320	6,610	7,350	8,280	8,880	9,620		
		180	—	6,800	6,710	6,550	5,480	5,700	6,040	6,750	7,120	7,940	8,980	9,620	10,480		
		200	—	7,220	7,130	6,960	5,810	6,000	6,420	7,170	7,640	8,480	9,670	10,360	11,330		
		250	—	—	—	—	7,060	7,270	7,760	8,750	9,280	10,340	11,760	12,660	13,840		
180	180	300	—	—	—	8,270	8,590	9,150	10,320	10,960	12,190	13,910	14,960	16,370			
		40	6,240	6,420	6,840	7,630	8,050	8,930	10,160	10,850	11,800						
		60	6,580	6,820	7,250	8,150	8,600	9,570	10,910	11,710	12,760						
		80	7,440	7,720	8,280	9,410	10,080	11,280	12,960	14,020	15,480						
		100	8,840	9,220	9,880	11,250	12,080	13,590	15,600	16,920	18,750						
		125	9,920	10,360	11,140	12,720	13,670	15,390	17,680	19,200	21,350						
200	200	150	11,630	12,070	12,900	14,560	15,540	17,400	19,880	21,460	23,570						
		180	—	—	—	—	—	—	—	—	—	—	—	—	—		
		200	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		250	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		300	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		300	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
250	250	180	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		200	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		250	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		300	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		300	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		300	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
300	300	200	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		250	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		300	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		300	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		300	—	—	—	—	—	—	—	—	—	—	—	—	—	—	
		300	—	—	—	—	—	—	—	—	—	—	—	—	—	—	

Order 注文例
 型式 - A - B - T
 NAK55SP - 100 - 100 - 25
 F-NAK55SP - 250.02 - 249.98 - 20.01

Delivery 出荷日
 3 日目発送

Price 価格
 ■数量スライド価格 (●1円未満切り捨て) P.47
 数量 1~4 5~9 10~19 表示数量超えは
 値引率 基準単価 5% 10% 価格・出荷日お見積り

Alterations 追加工
 型式 - A - B - T - (CC・AB・TK)
 F-NAK55SP - 250.02 - 249.98 - 20.01 - AB2

Alterations	標準・フリーサイズに適用		
	C寸法変更	A・B寸法公差変更	T寸法公差変更
Code	CC	AB	TK
Spec.	全周の面取り寸法を変更します。 CC0 (面取りなし) CC0.5 (C0.5) CC1 (C1)	A・B寸法の公差を変更します。 Code A・B公差 AB1 ±0.03 (±0.06) AB2 ±0.02 (±0.05) AB3 ±0.01 (±0.025) AB4 ±0.02 (規格公差) AB5 ±0.01 (規格公差) ● () 内公差はA・B>200	T寸法の公差を変更します。 Code T公差 TK1 ±0.18 TK2 ±0.04 TK3 ±0.02 TK4 ±0.01 (規格公差) TK5 ±0.02
¥/1Code	0	0	0

F-NAK55SP フリーサイズタイプ A・B・T寸指定0.01mm ¥基準単価

型式	A	B	T	3.00~5.00	5.01~8.00	8.01~9.99	10.00~20.00	20.01~30.00	30.01~40.00	40.01~50.00
F-NAK55SP	10.00~29.99	10.00~29.99	10.00~29.99	4,440	4,130	3,980	3,450	3,630	3,780	3,930
			30.00~60.00	4,600	4,290	4,130	3,780	4,100	4,350	4,610
			60.01~80.00	4,740	4,430	4,270	4,000	4,390	4,720	5,050
			80.01~100.00	4,900	4,580	4,430	4,220	4,710	5,100	5,500
			100.01~125.00	—	5,090	4,910	4,760	5,340	5,810	6,260
			125.01~150.00	—	5,600	5,410	5,290	5,990	6,510	7,030
	30.00~60.00	30.00~60.00	150.01~180.00	—	6,050	5,850	5,810	6,640	7,250	7,870
			180.01~200.00	—	6,350	6,140	6,150	7,070	7,750	8,430
			30.00~60.00	4,950	4,640	4,480	4,700	5,200	6,240	6,520
			60.01~80.00	5,190	4,880	4,720	4,870	5,880	6,560	6,840
			80.01~100.00	5,420	5,100	4,940	5,020	6,170	6,890	7,190
			100.01~125.00	—	5,640	5,470	5,380	6,680	7,520	7,840
	60.01~80.00									