



RoHS

クラウンタイプ  
ROBAWC

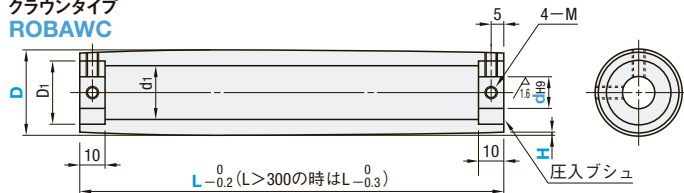


6.3 / ( 1.6 )

溝付ストレートタイプ  
ROBAWM

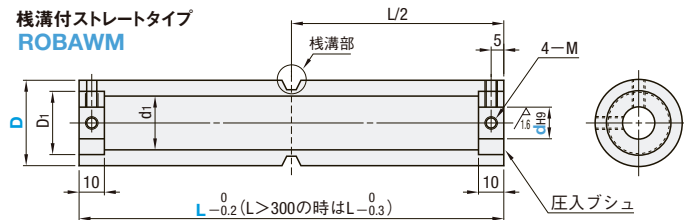

溝付部

■キー溝形状

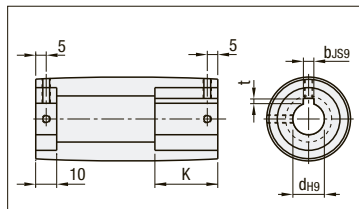

■新JIS (B1301) キー溝寸法表

呼び	dH9	bJS9	t公差	
N8	8	3	±0.0125	1.4
N10	10	4	±0.0150	1.8
NK10	10	4		2.3
N12	12	5		2.8
N15	15	6	±0.0180	3.3
N20	20	8		±0.20
N25	25	8		
N30	30	10		
N35	35	10		

M 材質 A5052  
S 表面処理 白アルマイト

<訂正用>

■新JIS (B1301) キー溝寸法表

呼び	dH9	bJS9	t公差	
N8	8	3	±0.0125	1.4
N10	10	4	±0.0150	1.8
NK10	10	4		2.3
N12	12	5		2.8
N15	15	6	±0.0180	3.3
N20	20	8		±0.20
N25	25	8		
N30	30	10		
N35	35	10		