


P寸と(W)寸の関係の訂正と注釈の追加


M材質	H硬度	①ツバ付き		②ツバ無し	
		丸	ダイヤ	丸	ダイヤ
S45C	—	KJKST	KJKDT	KJKS	KJKD
S45C	45HRC~	KJKSTH	KJKDTH	KJKSH	KJKDH
SUS304	—	KJKSTS	KJKDTS	KJKSS	KJKDS

P	(W)
4.00~ 6.00	1.5
6.01~ 8.00	1.8
8.01~13.00	3.0
13.01~16.00	4.0
16.01~20.00	5.0
20.01~23.00	6.0


■①ツバ付(丸)

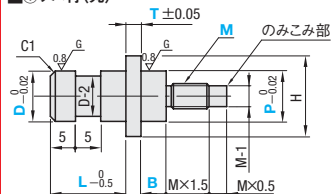


■①ツバ付(ダイヤ)

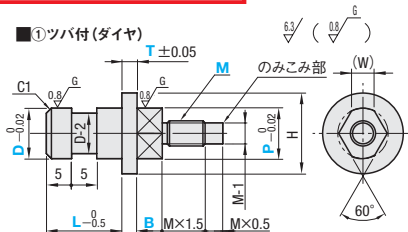

■②ツバ無し(丸)

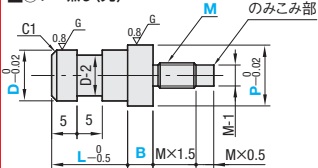

■②ツバ無し(ダイヤ)

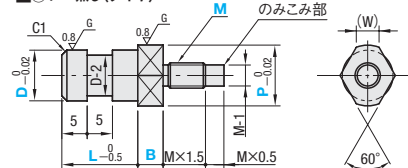


各段のつなぎ部に幅1mm程度のニゲ溝深さ(0.2mm程度)が、また先端部にセンター穴がつけます。


<訂正用>

P	(W)
4.00~ 6.00	1.5
6.01~ 8.00	1.8
8.01~13.00	3.0
13.01~16.00	4.0
16.01~20.00	5.0
20.01~23.00	6.0


■①ツバ付(丸)

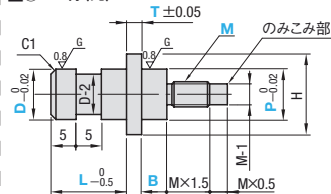


■①ツバ付(ダイヤ)

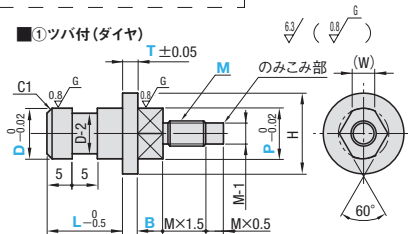

■②ツバ無し(丸)

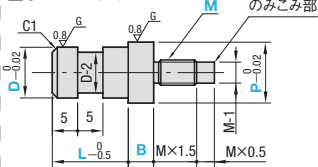

■②ツバ無し(ダイヤ)

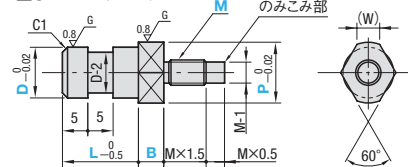

各段のつなぎ部に幅1mm程度のニゲ溝深さ(0.2mm程度)が、また先端部にセンター穴がつけます。