


図中に注記追加

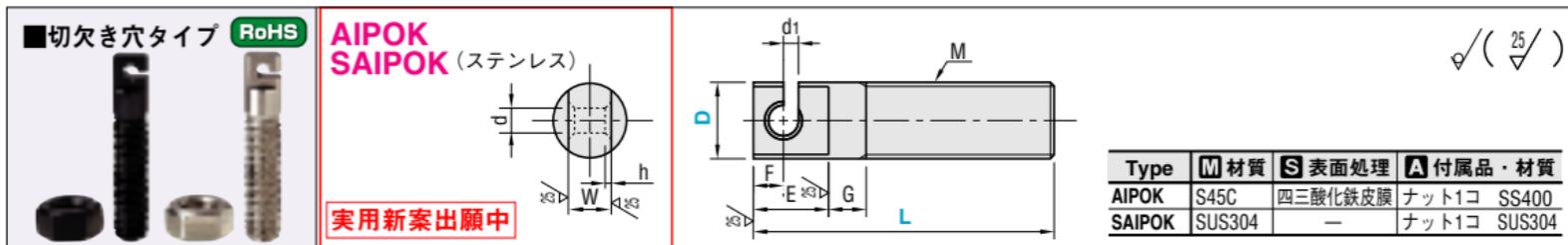

Catalog No.		L						M (並目)	d	d1	W	G	E	F	h	使用最大荷重N		AIPOK ¥単価		SAIPOK ¥単価			
Type	D															AIPOK	SAIPOK	1~49本	50本以上	1~49本	50本以上		
切り欠き穴タイプ AIPOK SAIPOK (ステンレス)	4	15	20	25	30			M 4	1.5	1.0	2.5	5	3.5	1.75	0.3	80	50	350	333	420	399		
	5	15	20	25	30	40		M 5	2.0		3.0		4.0	2.0	0.4	115	72	360	342	430	409		
	6		20	25	30	40	50		M 6		3.5		5.0	2.5	0.5	179	113	390	371	450	428		
	8			25	30	40	50	60	70	M 8	3.0		1.5	5.0	7.0	3.5	1.0	300	189	400	380	460	437
	10				30	40	50	60	70	M10	4.0		2.0	6.0	10.0	4.0	1.2	433	273	420	399	530	504
	12					40	50	60	70	M12	5.0		2.5	7.0	12.0	5.0	1.4	590	372	450	428	640	608

$$\text{kgf} = N \times 0.101972$$

<訂正用>

