


赤枠部 数値を変更



SRBN
SSRBN
(ステンレス)

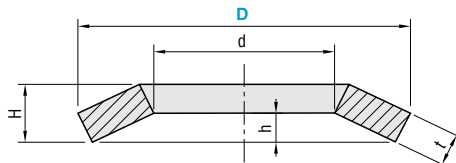

t	荷重許容差 (75%タワミ時)
	+25% -7.5%
0.3~1.1	+15% -7.5%
1.2~3	

Type	M 材質	S 表面処理	H 硬度
SRBN	S65~70C	四三酸化鉄皮膜	43~50HRC JIS B 2706-1995
SSRBN	SUS304-CSP	—	37~46HRC JIS B 2706-1995 相当

Catalog No.		荷重 タイプ	D	d	t	H	h	SRBN 円単価				SSRBN 円単価						
Type	D							SRBN	SSRBN	1~9コ	10~49	50~99	100~500	1~9コ	10~49	50~99	100~500	
8	A	0	4.2	±0.15	0.3	0.55	±0.10	0.25	117	105	94	58	22	14	99	63	25	17
					0.4	0.60		0.20	205	185	94	59	22	14	100	63	26	17
10	A	-0.15	5.2	±0.15	0.4	0.70	±0.10	0.30	205	185	96	60	23	15	101	64	26	18
					0.5	0.75		0.25	323	291	98	61	24	16	101	64	26	18
12.5	A	0	6.2	±0.15	0.5	0.85	±0.10	0.35	294	264	100	63	26	17	102	65	27	18
					0.7	1.00		0.30	657	591	101	64	26	18	103	66	27	19
14	A	0	7.0	±0.15	0.5	0.90	±0.10	0.40	274	247	102	65	27	19	105	67	29	20

<訂正用>

1

荷重許容差
(75%タワミ時)

2

荷重(75%タワミ時)N