


HIGH TORQUE TIMING BELTS -P2M-P3M-P5M-P8M- ハイトルクタイミングベルト (P2M・P3M・P5M・P8M)



RoHS PTBN

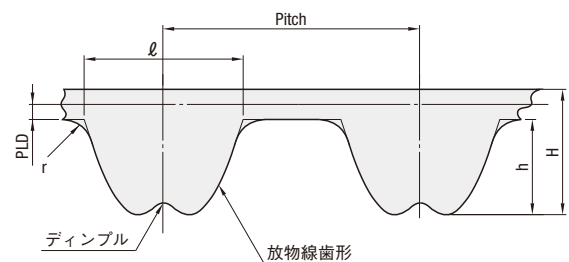

● 使用温度: -15~80℃

- 特長・注意事項 ▶ P.1137
- 選定方法 ▶ P.1967
- ベルト周長は心線の長さです。

| Type | 材質 |
|------|------------------------------------|
| PTBN | 本体 クロロプレノゴム(歯面:ナイロン歯布) 心線 ガラス繊維 |

| 種類 | Pitch | ℓ | H | h | PLD | r | 単位質量 g/m (幅:10mm) |
|-----|-------|------|-----|------|-------|-----|-------------------|
| P2M | 2 | 1.30 | 1.3 | 0.73 | 0.254 | 0.2 | 14.0 |
| P3M | 3 | 1.95 | 2.1 | 1.09 | 0.381 | 0.3 | 22.0 |
| P5M | 5 | 3.25 | 3.6 | 1.81 | 0.571 | 0.5 | 41.0 |
| P8M | 8 | 5.20 | 5.5 | 2.90 | 0.686 | 0.8 | 56.0 |



型式

Type ベルトNo. ベルト呼び幅

PTBN 200 P2M 060



3 日目発送



■ 数量スライド価格 (●1円未満切り捨て) P.89

| 数量 | 1~4 | 5~12 | 13~19 | 20~49 |
|-----|------|------|-------|-------|
| 値引率 | 基準単価 | 5% | 10% | 18% |

● 表示数量を超えればお見積り

種類 P2M (Pitch: 2mm)

| Type | 型式 | 歯数 | ベルト周長 (mm) | ¥基準単価 呼び幅 | | | |
|---------|-----------|----------|------------|-----------|-----|-----|-----|
| PTBN | 060 (6mm) | 80 P2M | 40 | 80 | 400 | | |
| | | 84 P2M | 42 | 84 | 400 | | |
| | | 88 P2M | 44 | 88 | 400 | | |
| | | 98 P2M | 49 | 98 | 400 | | |
| | | 100 P2M | 50 | 100 | 400 | | |
| | | 112 P2M | 56 | 112 | 400 | | |
| | | 116 P2M | 58 | 116 | 400 | | |
| | | 118 P2M | 59 | 118 | 400 | | |
| | | 124 P2M | 62 | 124 | 410 | | |
| | | 126 P2M | 63 | 126 | 410 | | |
| | | 132 P2M | 66 | 132 | 410 | | |
| | | 134 P2M | 67 | 134 | 410 | | |
| | | 136 P2M | 68 | 136 | 410 | | |
| | | 140 P2M | 70 | 140 | 410 | | |
| | | 142 P2M | 71 | 142 | 410 | | |
| | | 144 P2M | 72 | 144 | 420 | | |
| | | 146 P2M | 73 | 146 | 420 | | |
| | | 152 P2M | 76 | 152 | 420 | | |
| | | 154 P2M | 77 | 154 | 420 | | |
| | | 160 P2M | 80 | 160 | 420 | | |
| | | 162 P2M | 81 | 162 | 420 | | |
| | | 166 P2M | 83 | 166 | 420 | | |
| | | 170 P2M | 85 | 170 | 420 | | |
| | | 172 P2M | 86 | 172 | 420 | | |
| | | 176 P2M | 88 | 176 | 430 | | |
| | | 180 P2M | 90 | 180 | 430 | | |
| | | 186 P2M | 93 | 186 | 430 | | |
| | | 190 P2M | 95 | 190 | 430 | | |
| 196 P2M | 98 | 196 | 430 | | | | |
| 200 P2M | 100 | 200 | 430 | | | | |
| 204 P2M | 102 | 204 | 440 | | | | |
| 208 P2M | 104 | 208 | 440 | | | | |
| 212 P2M | 106 | 212 | 440 | | | | |
| 214 P2M | 107 | 214 | 440 | | | | |
| 216 P2M | 108 | 216 | 440 | | | | |
| 220 P2M | 110 | 220 | 440 | | | | |
| 224 P2M | 112 | 224 | 440 | | | | |
| 230 P2M | 115 | 230 | 450 | | | | |
| PTBN | 060 (6mm) | 234 P2M | 117 | 234 | 450 | | |
| | | 236 P2M | 118 | 236 | 450 | | |
| | | 240 P2M | 120 | 240 | 450 | | |
| | | 244 P2M | 122 | 244 | 460 | | |
| | | 246 P2M | 123 | 246 | 460 | | |
| | | 250 P2M | 125 | 250 | 460 | | |
| | | 258 P2M | 129 | 258 | 470 | | |
| | | 262 P2M | 131 | 262 | 470 | | |
| | | 266 P2M | 133 | 266 | 470 | | |
| | | 270 P2M | 135 | 270 | 470 | | |
| | | 274 P2M | 137 | 274 | 480 | | |
| | | 280 P2M | 140 | 280 | 480 | | |
| | | 284 P2M | 142 | 284 | 480 | | |
| | | 290 P2M | 145 | 290 | 490 | | |
| | | 300 P2M | 150 | 300 | 490 | | |
| PTBN | 060 (6mm) | 302 P2M | 151 | 302 | 490 | | |
| | | 310 P2M | 155 | 310 | 500 | | |
| | | 318 P2M | 159 | 318 | 500 | | |
| | | 320 P2M | 160 | 320 | 500 | | |
| | | 324 P2M | 162 | 324 | 500 | | |
| | | 328 P2M | 164 | 328 | 500 | | |
| | | 330 P2M | 165 | 330 | 500 | | |
| | | 334 P2M | 167 | 334 | 500 | | |
| | | 340 P2M | 170 | 340 | 500 | | |
| | | 348 P2M | 174 | 348 | 500 | | |
| | | 354 P2M | 177 | 354 | 500 | | |
| | | 360 P2M | 180 | 360 | 500 | | |
| | | 370 P2M | 185 | 370 | 510 | | |
| | | 378 P2M | 189 | 378 | 520 | | |
| | | 380 P2M | 190 | 380 | 520 | | |
| PTBN | 060 (6mm) | 390 P2M | 195 | 390 | 520 | | |
| | | 400 P2M | 200 | 400 | 520 | | |
| | | 408 P2M | 204 | 408 | 530 | | |
| | | 416 P2M | 208 | 416 | 530 | | |
| | | 420 P2M | 210 | 420 | 540 | | |
| | | 424 P2M | 212 | 424 | 540 | | |
| | | 426 P2M | 213 | 426 | 550 | | |
| | | 434 P2M | 217 | 434 | 550 | | |
| | | PTBN | 060 (6mm) | 440 P2M | 220 | 440 | 550 |
| | | | | 448 P2M | 224 | 448 | 560 |
| | | | | 464 P2M | 232 | 464 | 570 |
| | | | | 488 P2M | 244 | 488 | 590 |
| | | | | 490 P2M | 245 | 490 | 590 |
| | | | | 500 P2M | 250 | 500 | 590 |
| | | | | 516 P2M | 258 | 516 | 590 |
| 520 P2M | 260 | | | 520 | 590 | | |
| 530 P2M | 265 | | | 530 | 600 | | |
| 560 P2M | 280 | | | 560 | 600 | | |
| PTBN | 060 (6mm) | 576 P2M | 288 | 576 | 610 | | |
| | | 590 P2M | 295 | 590 | 610 | | |
| | | 600 P2M | 300 | 600 | 610 | | |
| | | 630 P2M | 315 | 630 | 620 | | |
| | | 638 P2M | 319 | 638 | 620 | | |
| | | 656 P2M | 328 | 656 | 630 | | |
| | | 676 P2M | 338 | 676 | 640 | | |
| | | 680 P2M | 340 | 680 | 640 | | |
| | | 704 P2M | 352 | 704 | 660 | | |
| | | 710 P2M | 355 | 710 | 670 | | |
| PTBN | 060 (6mm) | 754 P2M | 377 | 754 | 680 | | |
| | | 764 P2M | 382 | 764 | 680 | | |
| | | 774 P2M | 387 | 774 | 680 | | |
| | | 788 P2M | 394 | 788 | 690 | | |
| | | 800 P2M | 400 | 800 | 690 | | |
| | | 824 P2M | 412 | 824 | 690 | | |
| | | 846 P2M | 423 | 846 | 690 | | |
| | | 866 P2M | 433 | 866 | 690 | | |
| | | 898 P2M | 449 | 898 | 700 | | |
| | | 900 P2M | 450 | 900 | 700 | | |
| PTBN | 060 (6mm) | 940 P2M | 470 | 940 | 740 | | |
| | | 956 P2M | 478 | 956 | 740 | | |
| | | 992 P2M | 496 | 992 | 740 | | |
| | | 1040 P2M | 520 | 1040 | 750 | | |
| | | 1242 P2M | 641 | 1242 | 830 | | |

種類 P3M (Pitch: 3mm)

| Type | 型式 | 歯数 | ベルト周長 (mm) | ¥基準単価 呼び幅 | |
|----------|------------|---------|------------|-----------|-------|
| PTBN | 100 (10mm) | 120 P3M | 40 | 120 | 610 |
| | | 123 P3M | 41 | 123 | 610 |
| | | 138 P3M | 46 | 138 | 610 |
| | | 141 P3M | 47 | 141 | 610 |
| | | 144 P3M | 48 | 144 | 610 |
| | | 147 P3M | 49 | 147 | 610 |
| | | 150 P3M | 50 | 150 | 610 |
| | | 153 P3M | 51 | 153 | 620 |
| | | 159 P3M | 53 | 159 | 630 |
| | | 162 P3M | 54 | 162 | 630 |
| | | 171 P3M | 57 | 171 | 630 |
| | | 174 P3M | 58 | 174 | 630 |
| | | 177 P3M | 59 | 177 | 640 |
| | | 183 P3M | 61 | 183 | 640 |
| | | 186 P3M | 62 | 186 | 640 |
| | | 192 P3M | 64 | 192 | 650 |
| | | 195 P3M | 65 | 195 | 650 |
| | | 198 P3M | 66 | 198 | 650 |
| | | 201 P3M | 67 | 201 | 650 |
| | | 207 P3M | 69 | 207 | 660 |
| | | 210 P3M | 70 | 210 | 660 |
| | | 213 P3M | 71 | 213 | 670 |
| | | 219 P3M | 73 | 219 | 680 |
| | | 222 P3M | 74 | 222 | 680 |
| | | 225 P3M | 75 | 225 | 690 |
| | | 231 P3M | 77 | 231 | 690 |
| | | 234 P3M | 78 | 234 | 690 |
| 237 P3M | 79 | 237 | 690 | | |
| 240 P3M | 80 | 240 | 690 | | |
| 243 P3M | 81 | 243 | 690 | | |
| 246 P3M | 82 | 246 | 690 | | |
| 252 P3M | 84 | 252 | 700 | | |
| 255 P3M | 85 | 255 | 700 | | |
| 264 P3M | 88 | 264 | 700 | | |
| 270 P3M | 90 | 270 | 710 | | |
| 273 P3M | 91 | 273 | 710 | | |
| PTBN | 150 (15mm) | 276 P3M | 92 | 276 | 710 |
| | | 279 P3M | 93 | 279 | 720 |
| | | 285 P3M | 95 | 285 | 720 |
| | | 288 P3M | 96 | 288 | 720 |
| | | 291 P3M | 97 | 291 | 720 |
| | | 294 P3M | 98 | 294 | 720 |
| | | 300 P3M | 100 | 300 | 720 |
| | | 303 P3M | 101 | 303 | 720 |
| | | 306 P3M | 102 | 306 | 720 |
| | | 309 P3M | 103 | 309 | 720 |
| | | 312 P3M | 104 | 312 | 720 |
| | | 318 P3M | 106 | 318 | 720 |
| | | 330 P3M | 110 | 330 | 730 |
| | | 339 P3M | 113 | 339 | 740 |
| | | 345 P3M | 115 | 345 | 750 |
| | | 354 P3M | 118 | 354 | 750 |
| | | 360 P3M | 120 | 360 | 750 |
| | | 363 P3M | 121 | 363 | 760 |
| | | 369 P3M | 123 | 369 | 760 |
| | | 372 P3M | 124 | 372 | 760 |
| | | 384 P3M | 128 | 384 | 770 |
| | | 387 P3M | 129 | 387 | 770 |
| | | 393 P3M | 131 | 393 | 770 |
| | | 399 P3M | 133 | 399 | 770 |
| | | 402 P3M | 134 | 402 | 770 |
| | | 411 P3M | 137 | 411 | 770 |
| | | 420 P3M | 140 | 420 | 780 |
| 423 P3M | 141 | 423 | 800 | | |
| 432 P3M | 144 | 432 | 800 | | |
| 447 P3M | 149 | 447 | 820 | | |
| 450 P3M | 150 | 450 | 820 | | |
| 453 P3M | 151 | 453 | 820 | | |
| 459 P3M | 153 | 459 | 830 | | |
| 477 P3M | 159 | 477 | 840 | | |
| 483 P3M | 161 | 483 | 840 | | |
| 486 P3M | 162 | 486 | 840 | | |
| PTBN | 100 (10mm) | 489 P3M | 163 | 489 | 840 |
| | | 501 P3M | 167 | 501 | 840 |
| | | 504 P3M | 168 | 504 | 840 |
| | | 507 P3M | 169 | 507 | 850 |
| | | 510 P3M | 170 | 510 | 850 |
| | | 525 P3M | 175 | 525 | 860 |
| | | 537 P3M | 179 | 537 | 870 |
| | | 552 P3M | 184 | 552 | 890 |
| | | 561 P3M | 187 | 561 | 900 |
| | | 588 P3M | 196 | 588 | 900 |
| | | 600 P3M | 200 | 600 | 930 |
| | | 633 P3M | 211 | 633 | 960 |
| | | 660 P3M | 220 | 660 | 970 |
| | | 675 P3M | 225 | 675 | 980 |
| | | 681 P3M | 227 | 681 | 980 |
| | | 693 P3M | 231 | 693 | 1,000 |
| | | 699 P3M | 233 | 699 | 1,010 |
| | | 738 P3M | 246 | 738 | 1,020 |
| | | 753 P3M | 251 | 753 | 1,030 |
| | | PTBN | 150 (15mm) | 756 P3M | 252 |
| 789 P3M | 263 | | | 789 | 1,040 |
| 804 P3M | 268 | | | 804 | 1,060 |
| 852 P3M | 284 | | | 852 | 1,100 |
| 861 P3M | 287 | | | 861 | 1,110 |
| 879 P3M | 293 | | | 879 | 1,120 |
| 891 P3M | 297 | | | 891 | 1,120 |
| 918 P3M | 306 | | | 918 | 1,150 |
| 933 P3M | 311 | | | 933 | 1,170 |
| 948 P3M | 316 | | | 948 | 1,180 |
| 957 P3M | 319 | | | 957 | 1,180 |
| 1005 P3M | 335 | | | 1005 | 1,220 |
| 1023 P3M | 341 | | | 1023 | 1,230 |
| 1041 P3M | 347 | | | 1041 | 1,250 |
| 1050 P3M | 350 | | | 1050 | 1,260 |
| 1191 P3M | 397 | | | 1191 | 1,340 |

種類 P5M (Pitch: 5mm)

| Type | 型式 | 歯数 | ベルト周長 (mm) | ¥基準単価 呼び幅 | | | |
|---------|------------|---------|------------|-----------|-------|-----|-------|
| PTBN | 100 (10mm) | 215 P5M | 43 | 215 | 770 | | |
| | | 225 P5M | 45 | 225 | 770 | | |
| | | 255 P5M | 51 | 255 | 770 | | |
| | | 260 P5M | 52 | 260 | 820 | | |
| | | 275 P5M | 55 | 275 | 870 | | |
| | | 295 P5M | 59 | 295 | 930 | | |
| | | 300 P5M | 60 | 300 | 930 | | |
| | | 310 P5M | 62 | 310 | 940 | | |
| | | 320 P5M | 64 | 320 | 940 | | |
| | | 325 P5M | 65 | 325 | 940 | | |
| | | 340 P5M | 68 | 340 | 950 | | |
| | | 350 P5M | 70 | 350 | 950 | | |
| | | 370 P5M | 74 | 370 | 980 | | |
| | | 375 P5M | 75 | 375 | 1,000 | | |
| | | 400 P5M | 80 | 400 | 1,010 | | |
| | | 420 P5M | 84 | 420 | 1,040 | | |
| | | 425 P5M | 85 | 425 | 1,040 | | |
| | | 430 P5M | 86 | 430 | 1,050 | | |
| | | 440 P5M | 88 | 440 | 1,060 | | |
| | | PTBN | 150 (15mm) | 450 P5M | 90 | 450 | 1,060 |
| 475 P5M | 95 | | | 475 | 1,110 | | |
| 490 P5M | 98 | | | 490 | 1,120 | | |
| 500 P5M | 100 | | | 500 | 1,120 | | |
| 515 P5M | 103 | | | 515 | 1,170 | | |
| 520 P5M | 104 | | | 520 | 1,170 | | |
| 525 P5M | 105 | | | 525 | 1,170 | | |
| 530 P5M | 106 | | | 530 | 1,170 | | |
| 550 P5M | 110 | | | 550 | 1,170 | | |
| 555 P5M | 111 | | | 555 | 1,190 | | |
| 560 P5M | 112 | | | 560 | 1,220 | | |
| 565 P5M | 113 | | | 565 | 1,220 | | |
| 570 P5M | 114 | | | 570 | 1,220 | | |
| 575 P5M | 115 | | | 575 | 1,220 | | |
| 595 P5M | 119 | | | 595 | 1,230 | | |
| PTBN | 100 (10mm) | | | 600 P5M | 120 | 600 | 1,230 |
| | | | | 605 P5M | 121 | 605 | 1,240 |
| | | | | 625 P5M | 125 | 625 | |