

溶接サニタリー管


一標準タイプ

溶接サニタリー管

一片端溶接タイプ/両端溶接タイプ

◎ CADデータフォルダ名: 52_Sanitary_Vacuum_Tanks

■ フェルール×フェルール

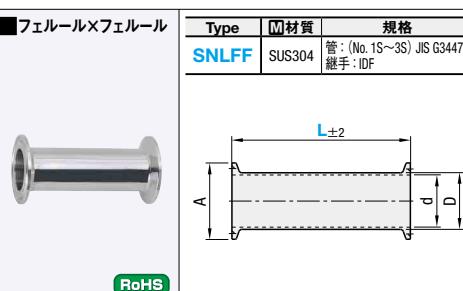


Type	M材質	規格
SNLFF	SUS304	管:(No.1S~3S) JIS G3447 継手:IDF




RoHS

Type	No.	L 指定 1mm単位	D	d	A	¥基準単価			
						最短L 200	L 201 300	L 301 400	L 401 500
1S	84~500	25.4	23	50.5	10,500	10,700	10,800	11,200	
1.5S	84~500	38.1	35.7	50.5	10,700	10,800	11,000	11,400	
2S	84~500	50.8	47.8	64	11,700	12,000	12,200	12,800	
2.5S	84~500	63.5	59.5	77.5	15,200	15,600	16,000	16,800	
3S	84~500	76.3	72.3	91	18,300	18,800	19,300	20,300	

■ フェルール×パイプ

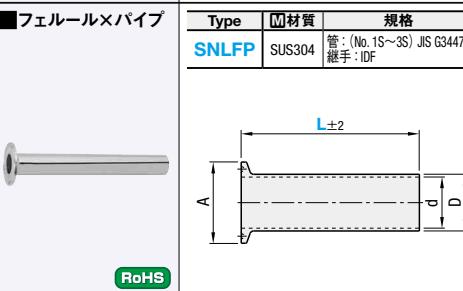


Type	M材質	規格
SNLFP	SUS304	管:(No.1S~3S) JIS G3447 継手:IDF

 


RoHS

Type	No.	L 指定 1mm単位	D	d	A	¥基準単価			
						最短L 200	L 201 300	L 301 400	L 401 500
1S	42~500	25.4	23	50.5	5,800	6,200	6,600	7,000	
1.5S	42~500	38.1	35.7	50.5	6,100	6,600	7,100	7,600	
2S	42~500	50.8	47.8	64	6,700	7,300	7,800	8,400	
2.5S	42~500	63.5	59.5	77.5	8,800	9,600	10,300	11,100	
3S	42~500	76.3	72.3	91	10,300	11,300	12,300	13,200	

■ エルボ×パイプ

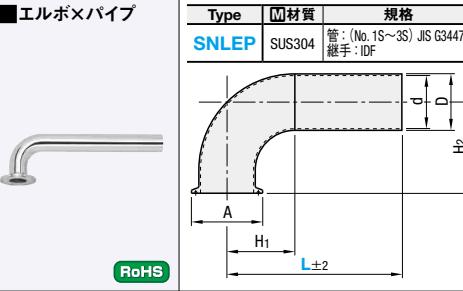


Type	M材質	規格
SNLEP	SUS304	管:(No.1S~3S) JIS G3447 継手:IDF

 


RoHS

Type	No.	L 指定 1mm単位	D	d	A	H1	H2	¥基準単価			
								最短L 200	L 201 300	L 301 400	L 401 500
1S	90~500	25.4	23	50.5	34	55	7,800	8,200	8,500	8,900	
1.5S	100~500	38.1	35.7	50.5	49	70	8,300	8,800	9,300	9,800	
2S	110~500	50.8	47.8	64	61	82	9,400	10,000	10,500	11,100	
2.5S	140~500	63.5	59.5	77.5	84	105	13,200	14,000	14,700	15,500	
3S	140~500	76.3	72.3	91	89	110	15,800	16,800	17,700	18,700	

■ フェルール×90°エルボ

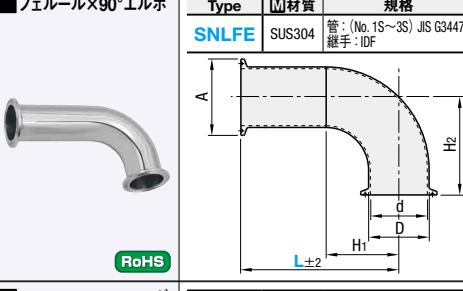


Type	M材質	規格
SNLFE	SUS304	管:(No.1S~3S) JIS G3447 継手:IDF

 


RoHS

Type	No.	L 指定 1mm単位	D	d	A	H1	H2	¥基準単価			
								最短L 200	L 201 300	L 301 400	L 401 500
1S	110~500	25.4	23	50.5	34	55	12,400	12,600	12,800	13,100	
1.5S	120~500	38.1	35.7	50.5	49	70	12,900	13,100	13,300	13,700	
2S	130~500	50.8	47.8	64	61	82	14,400	14,700	14,900	15,500	
2.5S	160~500	63.5	59.5	77.5	84	105	19,600	20,000	20,400	21,200	
3S	160~500	76.3	72.3	91	89	110	23,800	24,300	24,800	25,800	

■ フェルール×45°エルボ

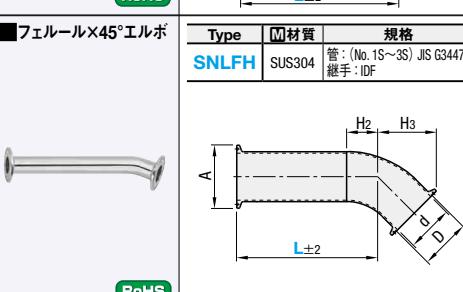

Type	M材質	規格
SNLFH	SUS304	管:(No.1S~3S) JIS G3447 継手:IDF

 

RoHS

Type	No.	L 指定 1mm単位	D	d	A	H2	H3	¥基準単価			
								最短L 200	L 201 300	L 301 400	L 401 500
1S	90~500	25.4	23	50.5	15.8	43.9	13,400	13,600	13,700	14,100	
1.5S	100~500	38.1	35.7	50.5	23.7	49.5	14,200	14,400	14,600	15,000	
2S	100~500	50.8	47.8	64	31.6	59.8	15,900	16,100	16,400	16,900	
2.5S	110~500	63.5	59.5	77.5	42	71.9	21,300	21,700	22,000	22,800	
3S	120~500	76.3	72.3	91	52.6	84.2	25,600	26,100	26,600	27,600	

Order
注文例

型式 - L

Delivery
出荷日 5 日目出荷Price
価格

数量区分 標準対応 小口 大口

数量 値引率 1~4 5~10 11~ 基準単価 5% お見積り

※表示数量超えはWOSにてご確認ください。

◎ CADデータフォルダ名: 52_Sanitary_Vacuum_Tanks

溶接サニタリー管

一片端溶接タイプ/両端溶接タイプ

◎ CADデータフォルダ名: 52_S