

サニタリー管用継手


-フェルール×溶接タイプ-

納期短縮

サニタリー管用継手


-両フェルールタイプ-

納期短縮

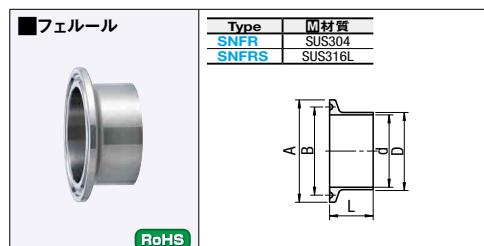


型式		D	d	A	B	L	SNFR		SNFRS	
Type	No.						¥基準単価	¥ライド単価	¥基準単価	¥ライド単価
SNFRS	8A	13.8	10.5	34.0	27.5	17.0	—	900	860	—
	10A	17.3	14.0				—	900	860	—
	15A	21.7	17.5				—	900	860	—
SNFR	1S	25.4	23.0	50.5	43.5	21.0	610	580	1,110	1,050
	1.5S	38.1	35.7	50.5	43.5		560	530	910	860
	2S	50.8	47.8	64.0	56.5		660	630	1,160	1,100
SNFRS	2.5S	63.5	59.5	77.5	70.5	21.0	1,100	1,050	1,670	1,590
	3S	76.3	72.3	91.0	83.5		1,370	1,300	2,190	1,950

※表示数量超えはWOSにてご確認ください。

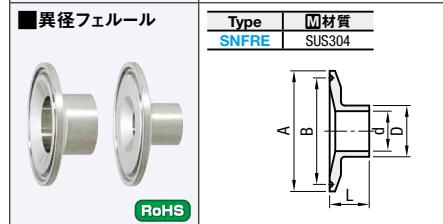


型式		呼び	D	d	A	B	L	¥基準単価	¥ライド単価
Type	No.		1~9コ	10~20					
SNFRE	1S	8A	13.8	10.5	50.5	43.5	21.0	2,130	2,020
	1.5S	10A	17.3	11.3				2,130	2,020
	2S	15A	21.7	15.7				2,130	2,020
SNFRE	1.5S	10A	17.3	11.3	50.5	43.5	21.0	2,130	2,020
	2.5S	15A	21.7	15.7				2,130	2,020
	3S	20A	27.2	21.2				2,900	2,760
SNFRE	2S	20A	27.2	21.2	64.0	56.5	21.0	2,900	2,760
	2.5S	25A	34.0	28.4				3,990	3,790
	3S	32A	42.7	37.1				3,990	3,790
SNFRE	3S	32A	42.7	37.1	91.0	83.5	21.0	5,400	5,130
	40A	40A	48.6	43.0				5,400	5,130

※表示数量超えはWOSにてご確認ください。

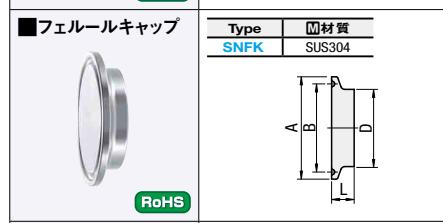


型式		D	A	B	L	¥基準単価	¥ライド単価
Type	No.	1~9コ	10~14				
SNFK	1S	38.1	50.5	43.5	11.0	820	800
	1.5S	50.8	64.0	56.5		820	800
	2S	63.5	77.5	70.5		1,270	1,210
SNFK	2.5S	63.5	77.5	70.5		1,820	1,730
	3S	76.3	91.0	83.5		2,360	2,240

※表示数量超えはWOSにてご確認ください。

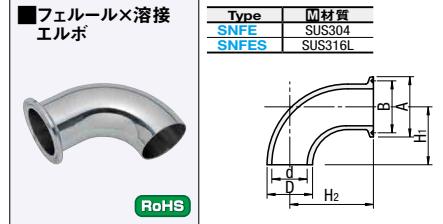


型式		D	d	A	B	H1	H2	¥基準単価	¥ライド単価
Type	No.	1~9コ	10~20	1~9コ	10~20				
SNFE	1S	25.4	23	50.5	43.5	34	55	2,570	2,440
	1.5S	38.1	35.7	50.5	43.5	49	70	2,870	2,730
	2S	50.8	47.8	64.0	56.5	61	82	3,410	3,240
SNFES	2.5S	63.5	59.5	77.5	70.5	84	105	5,590	5,310
	3S	76.3	72.3	91.0	83.5	89	110	6,960	6,610

※表示数量超えはWOSにてご確認ください。

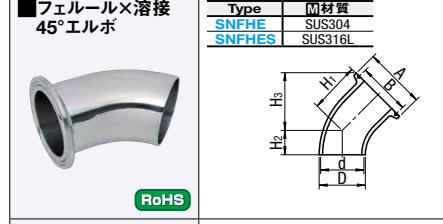

型式		D	d	A	B	H1	H2	H3	¥基準単価	¥ライド単価
Type	No.	1~9コ	10~20	1~9コ	10~20	1~9コ	10~20			
SNFHE	1S	25.4	23	50.5	43.5	36.8	43.9	3,210	2,770	3,650
	1.5S	38.1	35.7	50.5	43.5	44.7	50.5	3,780	3,270	4,620
	2S	50.8	47.8	64.0	56.5	52.6	61	4,420	3,830	5,960
SNFHES	2.5S	63.5	59.5	77.5	70.5	63.0	74.0	6,440	5,930	8,000
	3S	76.3	72.3	91.0	83.5	73.6	84.2	9,040	7,830	12,220


※表示数量超えはWOSにてご確認ください。

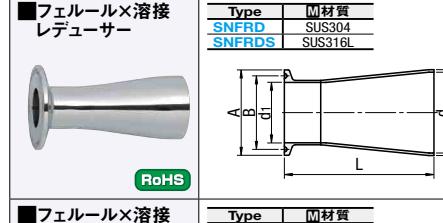

型式		D	d	d1	A	B	L	¥基準単価	¥ライド単価
Type	No.	1~9コ	10~20	1~9コ	10~20				
SNFRD	1.5S	38.1	35.7	23	50.5	43.5	88	5,050	4,560
	2S	50.8	47.8	35.7	50.5	43.5		5,290	4,770
	2.5S	63.5	59.5	47.8	64.0	56.5		7,330	6,620
SNFRDS	3S	76.3	72.3	59.5	77.5	70.5		9,480	8,560

※フェルール部のサイズは一段落ちとなります。例) No.2Sの場合、2S(パイプ側)×1.5S(フェルール部)

※表示数量超えはWOSにてご確認ください。

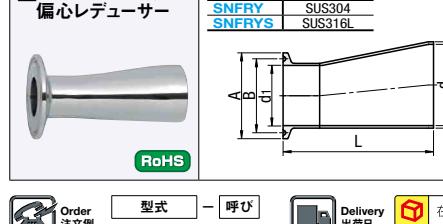

型式		D	d	d1	A	B	L	¥基準単価	¥ライド単価
Type	No.	1~9コ	10~20	1~9コ	10~20				
SNFRY	1.5S	38.1	35.7	23	50.5	43.5	88	5,480	4,890
	2S	50.8	47.8	35.7	50.5	43.5		5,810	5,180