


## サニタリー管用継手

一両溶接タイプ


納期短縮

## サニタリー管用継手/サニタリー変換継手


納期短縮

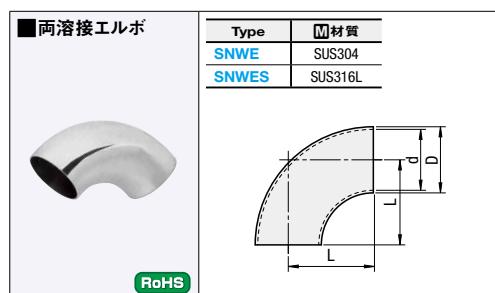


RoHS

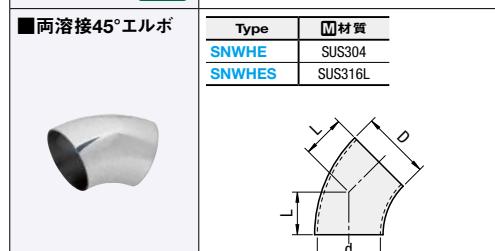


RoHS

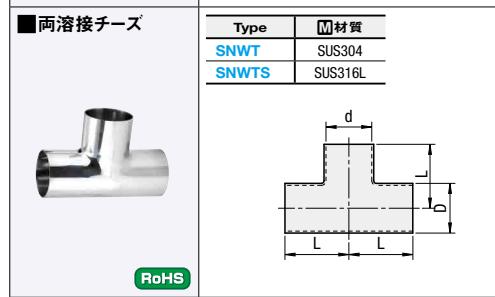

RoHS

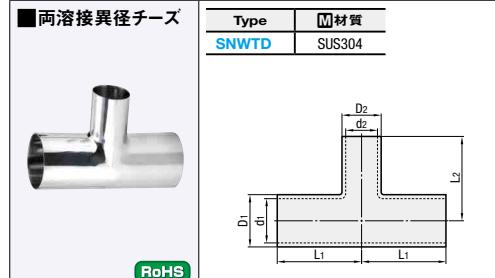

RoHS

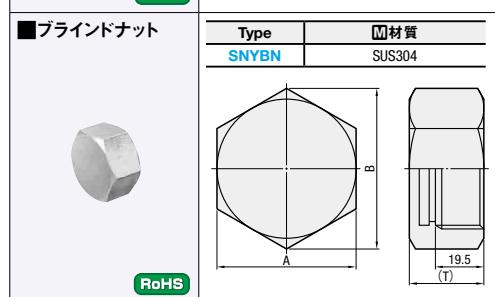

RoHS

Order  
注文例  
型式  
SNWE2S  
Delivery  
出荷日  
●下記以外  
在庫品 翌日出荷 P.127  
ご希望によりPM6:00迄、当日出荷受付致します。  
●SNWTS・SNWTD・SNYBN  
3 日目出荷

● CADデータフォルダ名: 52\_Sanitary\_Vacuum\_Tanks

型式		D	d	L	SNWE		SNWES	
Type	No.				¥基準単価	¥スライド単価	¥基準単価	¥スライド単価
SNWE	8A	13.8	10.5	38	—	—	4,300	3,870
	10A	17.3	14.0		—	—	4,070	3,660
	15A	21.7	17.5		—	—	3,860	3,470
SNWES	1S	25.4	23	34	1,610	1,530	2,000	1,800
	1.5S	38.1	35.7	49	1,660	1,580	2,270	2,040
	2S	50.8	47.8	61	2,010	1,910	2,870	2,580
	2.5S	63.5	59.5	84	3,530	3,350	5,910	5,320
	3S	76.3	72.3	89	4,910	4,660	6,940	6,250

※表示数量超えはWOSにてご確認ください。

型式		D	d	L	SNWHE		SNWHES	
Type	No.				¥基準単価	¥スライド単価	¥基準単価	¥スライド単価
SNWHE	1S	25.4	23	15.8	1,950	1,670	2,130	1,800
	1.5S	38.1	35.7	23.7	2,340	2,000	2,700	2,280
	2S	50.8	47.8	31.6	2,860	2,440	3,440	2,920
	2.5S	63.5	59.5	42	5,190	4,440	6,470	5,500
	3S	76.3	72.3	52.6	6,360	5,440	8,510	7,240

※表示数量超えはWOSにてご確認ください。

型式		D	d	L	SNWT		SNWTS	
Type	No.				¥基準単価	¥スライド単価	¥基準単価	¥スライド単価
SNWT	1S	25.4	23.0	34.0	3,040	2,740	4,650	4,190
	1.5S	38.1	35.7	49.0	3,190	2,870	4,810	4,330
	2S	50.8	47.8	61.0	3,710	3,340	5,850	5,270
	2.5S	63.5	59.5	84.0	6,240	5,620	8,580	7,720
	3S	76.3	72.3	89.0	7,330	6,600	10,410	9,370


※表示数量超えはWOSにてご確認ください。

型式		D1	d1	D2	d2	L1	L2	¥基準単価	
Type	No.							1~10コ	1~10コ
SNWTD	1.5S-1S	38.1	35.7	25.4	23.0	49	45	4,300	
	2S-1S	50.8	47.8	25.4	23.0	61	51	5,700	
	2S-1.5S	50.8	47.8	38.1	35.7	61	64	5,800	
	2.5S-1.5S	63.5	59.5	38.1	35.7	84	70	7,700	
	2.5S-2S	63.5	59.5	50.8	47.8	84	82	7,900	

※表示数量超えはWOSにてご確認ください。

型式		A	B	(T)	¥基準単価		¥スライド単価	
Type	No.				1~4コ	5~10	1~4コ	5~10
SNYBN	1S	46.0	53.1	30.0	5,000	4,900	5,000	4,900
	1.5S	56.0	64.6		5,300	4,900		
	2S	71.0	81.9		5,500	5,400		
	2.5S	85.0	98.1		7,800	7,700		
	3S	100.0	115.4		9,500	9,300		

※表示数量超えはWOSにてご確認ください。

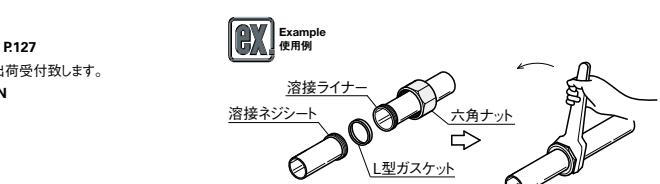


納期短縮


## サニタリー管用継手/サニタリー変換継手

納期短縮


一溶接ネジタイプ

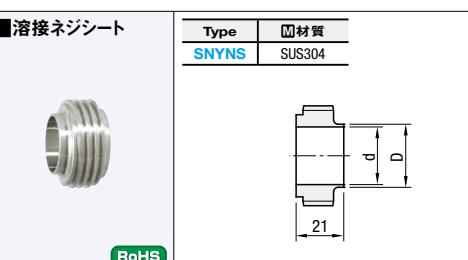


RoHS

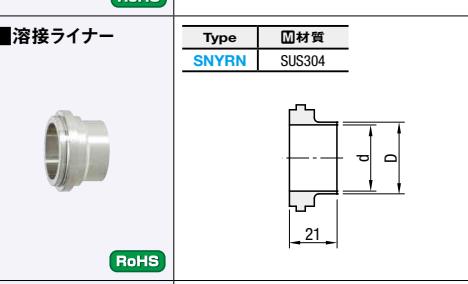


RoHS

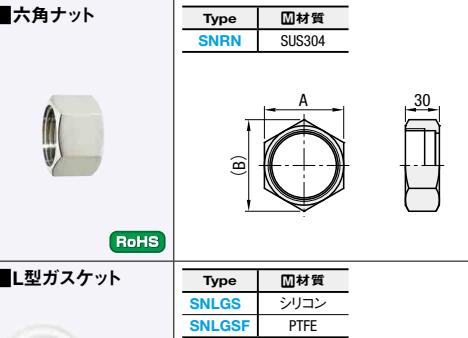


RoHS

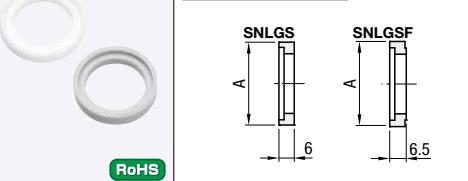

RoHS

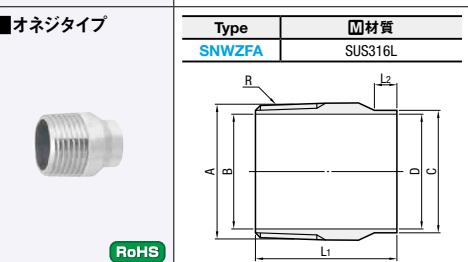

RoHS

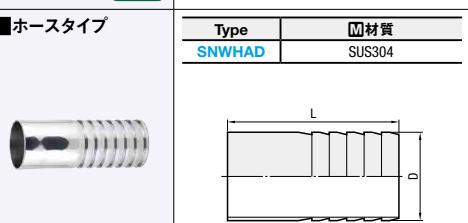

RoHS

● CADデータフォルダ名: 52\_Sanitary\_Vacuum\_Tanks

型式		D	d	¥基準単価		¥スライド単価	
Type	No.			1~9コ	10~20	1~9コ	10~20
SNYNS	1S	25.4	23	850	770	850	770
	1.5S	38.1	35.7	1,030	930	1,030	930
	2S	50.8	47.8	1,270	1,140	1,270	1,140
	2.5S	63.5	59.5	1,670	1,450	1,670	1,450
	3S	76.3	72.3	2,060	1,850	2,060	1,850

※表示数量超えはWOSにてご確認ください。

型式		A	(B)	¥基準単価		¥スライド単価	
Type	No.			1~9コ	10~20	1~9コ	10~20
SNYRN	1S	25.4	23	660	540	660	540
	1.5S	38.1	35.7	690	590	690	590
	2S	50.8	47.8	930	760	930	760
	2.5S	63.5	59.5	1,300	1,100	1,300	1,100
	3S	76.3	72.3	1,740	1,400	1,740	1,400

※表示数量超えはWOSにてご確認ください。

型式		A	B	¥基準単価		¥スライド単価	
Type	No.	SNLGS	SNLGSF	1~			