


SUS304フリープレート 価格表

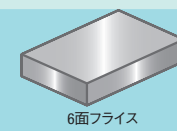

●大サイズ価格(例) L-PAFQM-650-300-14.5のとき
 A寸法 × 面積単価 = 価格(1円単位は切捨)
 650 × 115.6 = 75,140(円)

数量スライド価格 (1円単位切り捨て) P127

数量区分	標準対応	個別対応
数量	1~10	11~
値引率	基準単価	お見積り

◎表示数量超えはWOSにてご確認ください。

細長サイズ H-PAF (6面フライス) A・B・T 0.5mm単位

型式	A		T	A・B・T 0.5mm単位				
	5~5.5	6~7.5		8~9.5	10~14.5	15~19.5		
H-PAF	10~15	150 ~200	4,670	4,340	4,980	5,660	—	
		200.5~250	6,290	5,920	5,780	6,520	—	
		250.5~300	8,160	7,710	7,670	8,740	—	
		300.5~350	10,070	9,550	9,620	11,050	—	
		350.5~400	12,000	11,330	11,290	12,850	—	
	15.5~19.5	400.5~450	13,980	13,230	13,280	14,840	—	
		450.5~500	16,980	15,930	15,540	17,040	—	
		500.5~600	20,940	19,680	18,980	21,300	—	
		600.5~700	20,990	20,990	21,930	24,550	—	
		700.5~800	24,500	24,500	25,330	27,490	—	

大サイズ L-PAF (6面フライス) A・B・T 0.5mm単位

型式	A		B	T	A・B・T 0.5mm単位											
	5~5.5	6~7.5			8~9.5	10~14.5	15~17.5	18~19.5	20~21.5	22~24.5	25~29.5	30~34.5	35~39.5	40~50		
L-PAF	20~25	300 ~ 350	Ax24.2	Ax27.1	Ax27.1	Ax31	Ax35.8	Ax35.8	Ax37.8	Ax39.6	—	—	—	—		
		350.5~400	Ax23.3	Ax26.2	Ax27.1	Ax31	Ax35.8	Ax35.8	Ax37.8	Ax38.7	—	—	—	—		
		400.5~450	Ax23.3	Ax26.2	Ax26.2	Ax30	Ax34.8	Ax34.8	Ax37.8	Ax37.8	—	—	—	—		
		450.5~500	Ax19.4	Ax20.3	Ax21.3	Ax24.2	Ax27.1	Ax27.1	Ax30	Ax30	—	—	—	—		
		500.5~600	Ax19.4	Ax21.3	Ax21.3	Ax24.2	Ax28.1	Ax28.1	Ax31	Ax31	—	—	—	—		
	25.5~40	600.5~700	Ax28.1	Ax28.1	Ax21.3	Ax24.2	Ax27.1	Ax28.1	Ax29.9	Ax31	—	—	—	—		
		700.5~800	Ax28.8	Ax28.8	Ax21.2	Ax24	Ax26.9	Ax29.8	Ax29.8	Ax29.8	—	—	—	—		
		800.5~900	Ax19.4	Ax21.3	Ax22.2	Ax25.1	Ax29	Ax29	Ax31.9	Ax32.9	Ax36.7	Ax42.6	—	—		
		900.5~1000	Ax29.8	Ax29.8	Ax21.2	Ax24	Ax27.9	Ax28.8	Ax30.8	Ax31.7	Ax35.8	Ax41.5	—	—		
		1000.5~1100	Ax20.3	Ax22.2	Ax23.3	Ax27.1	Ax31	Ax31.9	Ax33.8	Ax34.8	Ax38.7	Ax44.4	Ax48.3	Ax57		

大サイズ L-PAF (6面フライス) A・B・T 0.5mm単位

型式	A		B	T	A・B・T 0.5mm単位											
	6~7.5	8~9.5			10~14.5	15~17.5	18~19.5	20~21.5	22~24.5	25~29.5	30~34.5	35~39.5	40~50			
L-PAF	146.5~200	500.5~600	—	—	Ax70.5	Ax81.2	Ax89.8	Ax91.8	Ax97.5	Ax103.4	Ax113.9	Ax126.5	Ax137.2	Ax160.3		
		600.5~700	—	—	Ax69.6	Ax80.2	Ax87.9	Ax89.8	Ax95.7	Ax101.5	Ax111.1	Ax123.6	Ax134.3	Ax157.4		
		700.5~800	—	—	Ax71.1	Ax81.6	Ax90.3	Ax93.2	Ax98	Ax102.8	Ax113.3	Ax126.8	Ax137.3	Ax161.3		
		800.5~900	—	—	Ax70.1	Ax80.7	Ax89.3	Ax91.2	Ax96.9	Ax101.7	Ax112.4	Ax125.7	Ax135.3	Ax158.3		
		900.5~1000	—	—	Ax69.2	Ax79.7	Ax88.4	Ax91.2	Ax96	Ax100.8	Ax111.3	Ax123.9	Ax134.4	Ax157.5		
	200.5~250	1000.5~1100	—	—	—	Ax62.3	Ax72.2	Ax80.2	Ax85.9	Ax90.2	Ax95	Ax99.8	Ax109.3	Ax122.7	Ax133.3	
		1100.5~1200	—	—	—	Ax61.4	Ax71.2	Ax79.2	Ax84.9	Ax89.2	Ax94	Ax98.8	Ax108.3	Ax121.7	Ax132.3	
		1200.5~1300	—	—	—	Ax88.1	Ax93	Ax107.5	Ax117.2	Ax122	Ax129.8	Ax135.6	Ax149.2	Ax167.5	Ax182.1	
		1300.5~1400	—	—	—	Ax85.2	Ax90.1	Ax103.7	Ax113.3	Ax118.2	Ax125	Ax130.8	Ax144.4	Ax161.8	Ax175.3	
		1400.5~1500	—	—	—	Ax88	Ax101.6	Ax110.3	Ax115.1	Ax121.8	Ax127.7	Ax132.5	Ax146.2	Ax163.7	Ax177.2	

L-PAF