


COIL SPRINGS -HIGH DEFLECTION- SWR

コイルスプリング

-高タワミ用 SWR-

CADデータフォルダ名: 37_Springs

価格改訂

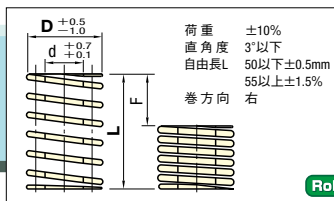

RoHS


COIL SPRINGS -MIDDLE DEFLECTION- SWS

コイルスプリング

-中タワミ用 SWS-

CADデータフォルダ名: 37_Springs

価格改訂

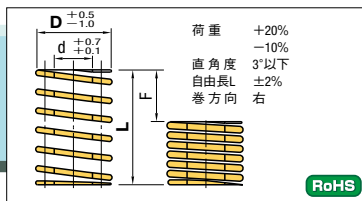

RoHS

D	d	L	N/mm(kgf/mm) (ばね定数)	F=LX50% Fmm	N (kgf/荷重)	型式 Type D-L	基準 単位
10.5	6.0	15	10.46 [1.07]	7.5	78.5 [8.0]	SWR105-	15 98
		20	7.85 [0.80]	10.0			20 98
		25	6.28 [0.64]	12.5			25 104
		30	5.23 [0.53]	15.0			30 109
		35	4.48 [0.46]	17.5			35 120
		40	3.92 [0.40]	20.0			40 131
		45	3.49 [0.36]	22.5			45 131
		50	3.14 [0.32]	25.0			50 142
		55	2.85 [0.29]	27.5			55 153
		60	2.62 [0.27]	30.0			60 164
		65	2.41 [0.25]	32.5			65 174
		70	2.24 [0.23]	35.0			70 185
		75	2.09 [0.21]	37.5			75 196
		80	1.96 [0.20]	40.0			80 207
12.5	7.0	15	11.77 [1.20]	7.5	88.3 [9.0]	SWR125-	15 104
		20	8.83 [0.90]	10.0			20 104
		25	7.06 [0.72]	12.5			25 109
		30	5.88 [0.60]	15.0			30 120
		35	5.04 [0.51]	17.5			35 131
		40	4.41 [0.45]	20.0			40 142
		45	3.92 [0.40]	22.5			45 153
		50	3.53 [0.36]	25.0			50 164
		55	3.21 [0.33]	27.5			55 174
		60	2.94 [0.30]	30.0			60 185
		65	2.72 [0.28]	32.5			65 196
		70	2.52 [0.26]	35.0			70 207
		75	2.35 [0.24]	37.5			75 213
		80	2.21 [0.23]	40.0			80 223
		90	1.96 [0.20]	45.0			90 245
		100	1.77 [0.18]	50.0			100 267
14.5	8.5	15	17.00 [1.73]	7.5	127.5 [13.0]	SWR145-	15 120
		20	12.75 [1.30]	10.0			20 131
		25	10.20 [1.04]	12.5			25 142
		30	8.50 [0.87]	15.0			30 153
		35	7.28 [0.74]	17.5			35 164
		40	6.37 [0.65]	20.0			40 174
		45	5.67 [0.58]	22.5			45 185
		50	5.10 [0.52]	25.0			50 196
		55	4.64 [0.47]	27.5			55 202
		60	4.25 [0.43]	30.0			60 207
		65	3.92 [0.40]	32.5			65 218
		70	3.64 [0.37]	35.0			70 229
		75	3.40 [0.35]	37.5			75 240
		80	3.19 [0.33]	40.0			80 251
		90	2.83 [0.29]	45.0			90 273
		100	2.55 [0.26]	50.0			100 294
		125	2.04 [0.21]	62.5			125 316
		150	1.70 [0.17]	75.0			150 338
17	10.5	20	19.61 [2.00]	10.0	196.1 [20.0]	SWR17-	20 142
		25	15.69 [1.60]	12.5			25 153
		30	13.08 [1.33]	15.0			30 164
		35	11.21 [1.14]	17.5			35 174
		40	9.81 [1.00]	20.0			40 185
		45	8.72 [0.89]	22.5			45 196
		50	7.85 [0.80]	25.0			50 202
		55	7.13 [0.73]	27.5			55 207
		60	6.54 [0.67]	30.0			60 218
		65	6.03 [0.62]	32.5			65 229
		70	5.60 [0.57]	35.0			70 240
		75	5.23 [0.53]	37.5			75 251
		80	4.90 [0.50]	40.0			80 262
		90	4.36 [0.44]	45.0			90 283
		100	3.92 [0.40]	50.0			100 300
		125	3.14 [0.32]	62.5			125 327
		150	2.62 [0.27]	75.0			150 360
		175	2.24 [0.23]	87.5			175 392

Order 注文例	型式 SWR37-40
Delivery 出荷日	在庫品 翌日出荷 〆 P127
〆ご希望によりPM6:00迄、 当日出荷受付致します。	
Price 価格	数量スライド価格 (〆1円未満切り捨て) P127
	数量区分 1~19 20~49 50~199 200~500 501~
	値引率 基準率値 5% 10% 15% お見積り
	〆表示数量超えはWOSにてご確認ください。

D	d	L	N/mm(kgf/mm) (ばね定数)	F=LX50% Fmm	N (kgf/荷重)	型式 Type D-L	基準 単位
21	13.5	25	23.54 [2.40]	12.5	294.2 [30.0]	SWR21-	25 174
		30	19.61 [2.00]	15.0			30 185
		35	16.81 [1.71]	17.5			35 196
		40	14.71 [1.50]	20.0			40 202
		45	13.08 [1.33]	22.5			45 207
		50	11.77 [1.20]	25.0			50 218
		55	10.07 [1.09]	27.5			55 229
		60	9.81 [1.00]	30.0			60 240
		65	9.05 [0.92]	32.5			65 251
		70	8.41 [0.86]	35.0			70 262
		75	7.85 [0.80]	37.5			75 273
		80	7.35 [0.75]	40.0			80 283
		90	6.54 [0.67]	45.0			90 294
		100	5.88 [0.60]	50.0			100 300
		110	5.35 [0.55]	55.0			110 311
		120	4.90 [0.50]	60.0			120 316
		125	4.71 [0.48]	62.5			125 327
		130	4.53 [0.46]	65.0			130 338
		140	4.20 [0.43]	70.0			140 349
		150	3.92 [0.40]	75.0			150 360
		175	3.36 [0.34]	87.5			175 387
		200	2.94 [0.30]	100.0			200 414
26	16.5	25	31.38 [3.20]	12.5	392.3 [40.0]	SWR26-	25 207
		30	26.15 [2.67]	15.0			30 218
		35	22.42 [2.29]	17.5			35 229
		40	19.61 [2.00]	20.0			40 240
		45	17.43 [1.78]	22.5			45 251
		50	15.69 [1.60]	25.0			50 262
		55	14.26 [1.45]	27.5			55 273
		60	13.08 [1.33]	30.0			60 283
		65	12.07 [1.23]	32.5			65 294
		70	11.21 [1.14]	35.0			70 300
		75	10.46 [1.07]	37.5			75 311
		80	9.81 [1.00]	40.0			80 316
		90	8.72 [0.89]	45.0			90 327
		100	7.85 [0.80]	50.0			100 338
		110	7.13 [0.73]	55.0			110 349
		120	6.54 [0.67]	60.0			120 360
		125	6.28 [0.64]	62.5			125 360
		130	6.03 [0.62]	65.0			130 371
		140	5.60 [0.57]	70.0			140 382
		150	5.23 [0.53]	75.0			150 382
		175	4.48 [0.46]	87.5			175 436
		200	3.92 [0.40]	100.0			200 496
		225	3.49 [0.36]	112.5			225 518
		250	3.14 [0.32]	125.0			250 545
31	21	35	28.02 [2.86]	17.5	490.3 [50.0]	SWR31-	35 240
		40	24.52 [2.50]	20.0			40 251
		45	21.79 [2.22]	22.5			45 262
		50	19.61 [2.00]	25.0			50 273
		55	17.83 [1.82]	27.5			55 283
		60	16.34 [1.67]	30.0			60 294
		65	15.09 [1.54]	32.5			65 305
		70	14.01 [1.43]	35.0			70 311
		75	13.08 [1.33]	37.5			75 316
		80	12.26 [1.25]	40.0			80 327
		90	10.90 [1.11]	45.0			90 349
		100	9.81 [1.00]	50.0			100 371
		110	8.92 [0.91]	55.0			110 382
		120	8.17 [0.83]	60.0			120 398
		125	7.85 [0.80]	62.5			125 409
		130	7.54 [0.77]	65.0			130 414
		140	7.00 [0.71]	70.0			140 436
		150	6.54 [0.67]	75.0			150 447
		160	6.13 [0.63]	80.0			160 469
		170	5.77 [0.59]	85.0			170 480
		180	5.45 [0.56]	90.0			180 496
		190	5.16 [0.53]	95.0			190 518
		200	4.90 [0.50]	100.0			200 523
		250	3.92 [0.40]	125.0			250 605