 


規格追加
赤字表示
追加

SHAFTS -ONE SIDE MALE SCREW TYPE-

シャフト
一片端おねじ




軸端部の直角度精度が高い(L 0.03)、精密シャフトはP.247をご覧ください。片端おねじ・軸径同寸タイプはP.195を参照ください。スパナ溝付・キリ穴付タイプはP.199を参照ください。



Table with columns: Type, D公差g6, D公差h5, D公差f8, 材質, 硬度, S表面処理. Lists various shaft types like SFAN, SFFAN, PSFAN, etc.

Table with columns: D, g6, h5, f8. Lists diameter and tolerance values for different shaft sizes.

D公差h5のとき、全体入れとなる場合があります。
SUS440Cまたは13Cr系ステンレスの低温黒色クロムメッキ品には識別溝がつきます。P.148参照。
D部面粗度はメッキ品は0.4/メッキ無し品は0.4です。

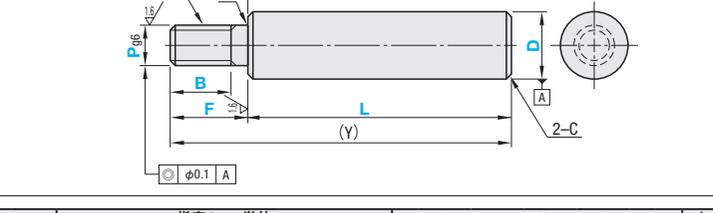

軸端加工部(ネジ有効長さ約10mm)加工のための焼きなましによる硬度低下の可能性があり。
低温黒色クロムメッキの特長
寸公差・真円度・真直度・直角度・同軸度・硬度変化

Table with columns: 型式, D, L, F, B, P. Lists shaft models and their dimensions.

Table with columns: 型式, D, L, F, B, P. Lists shaft models and their dimensions.

Table with columns: 型式, D, L, F, B, P. Lists shaft models and their dimensions.

Order 注文例
SFAN12 - 500 - F20 - B15 - P6
SFUN8 - 150 - F20 - B15 - P10
SF - SSFAN20 - 1051 - F50 - B30 - P10

Alteration 追加加工
SFAN30 - 250 - F40 - B30 - P10 - LKC
キー溝追加加工(KC)のみ 5日日出荷(RSFANは8日日出荷)

低溫黒色クロムメッキ品
8日日出荷

Table with columns: Alterations, Code, Spec., ¥/1Code. Lists shaft alteration options like LKC, FC, WFC.

Table with columns: Alterations, Code, Spec., ¥/1Code. Lists shaft alteration options like RC, WRC, PMC/PMS, KC.

Price 価格
数量スライド価格
SUJ2相当 D公差g6 D6~D12
SUJ2相当 D公差g6 D6~D12
SUJ2相当 D公差g6 D6~D12

Table with columns: 数量区分, 標準対応, 大径, 個別対応. Lists pricing tiers for different shaft quantities.

Table with columns: 数量区分, 標準対応, 大径, 個別対応. Lists pricing tiers for different shaft quantities.

Large table with columns: 型式, D, 最短L, L51, L101, L151, L201, L251, L301, L351, L401, L451, L501, L551, L601, L651, L701, L751, L801, L851, L901, L951, L1001, L1101, L1201, L1301, L1401. Lists standard shaft dimensions and tolerances.

Table with columns: 型式, D, 最短L, L51, L101, L151, L201, L251, L301, L351, L401, L451, L501, L551, L601, L651, L701, L751, L801, L851, L901, L951, L1001, L1101, L1201, L1301, L1401. Lists standard shaft dimensions and tolerances.

Table with columns: 型式, D, 最短L, L51, L101, L151, L201, L251, L301, L351, L401, L451, L501, L551, L601, L651, L701, L751, L801, L851, L901, L951, L1001, L1101, L1201, L1301, L1401. Lists standard shaft dimensions and tolerances.