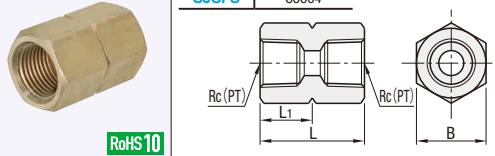
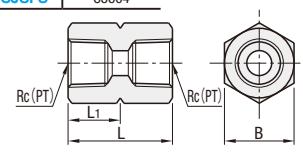
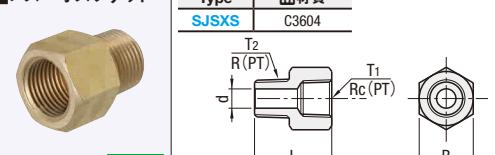
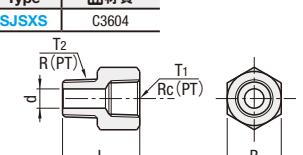
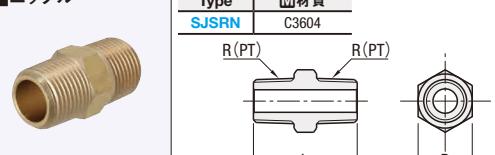
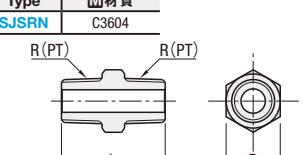
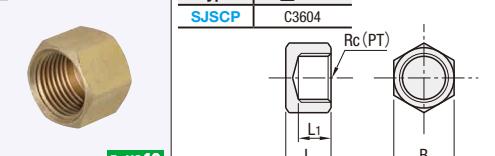
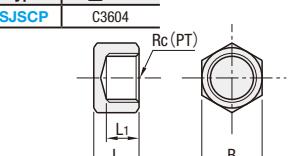
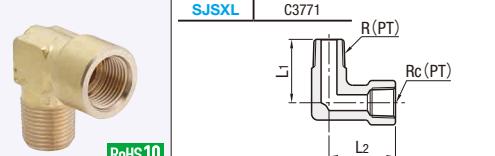
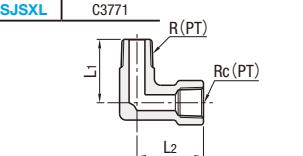
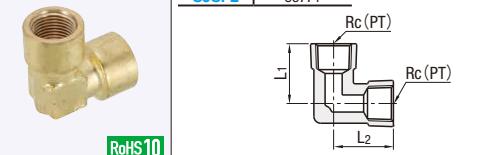
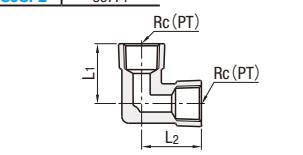
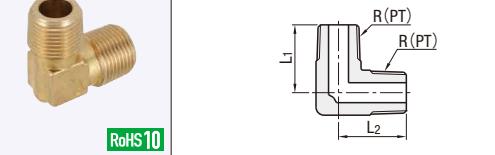
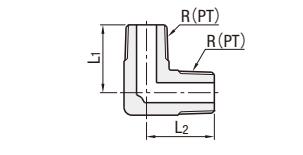
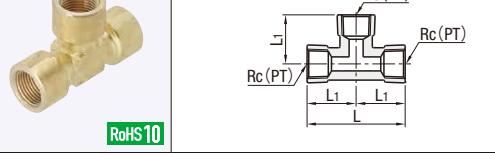
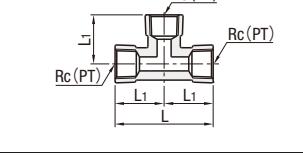


■ソケット	Type	■材質
	SJSFS	C3604
		
	RoHS10	
■メス・オスソケット	Type	■材質
	SJSXS	C3604
		
		
■ニップル	Type	■材質
	SJSRN	C3604
		
		
■キャップ	Type	■材質
	SJSCP	C3604
		
		
■メス・オスエルボ	Type	■材質
	SJSXL	C3771
		
		
■エルボ	Type	■材質
	SJSFL	C3771
		
		
■オスエルボ	Type	■材質
	SJSML	C3771
		
		
■チーズ	Type	■材質
	SJSFT	C3771
		
		

型式	Type	Rc (PT)	L	L1	B	￥基準単価	￥スライド単価
						1~9コ	10~20コ
SJSFS	Type	No.					
		6A	1/8	21	10.5	14	460 320
		8A	1/4	28	14	17	550 380
		10A	3/8	32	16	21	680 470
		15A	1/2	40	20	26	890 620

②表示数量超えはWOSにてご確認ください。

型式	Type	Rc (PT)	R (PT)	L	d	B	￥基準単価	￥スライド単価
							1~9コ	10~20コ
SJSXS	Type	No.						
		6A	1/8	1/8	20	5	14	420 270
		8A	1/4	1/4	24	8	17	470 320
		10A	3/8	3/8	28	11	21	580 400
		15A	1/2	1/2	33	15	26	690 510

②表示数量超えはWOSにてご確認ください。

型式	Type	R (PT)	L	B	￥基準単価	￥スライド単価
					1~9コ	10~20コ
SJSRN	Type	No.				
		6A	1/8	22	12	490 340
		8A	1/4	28	14	490 340
		10A	3/8	33	17	520 360
		15A	1/2	38	22	660 460

②表示数量超えはWOSにてご確認ください。

型式	Type	Rc (PT)	L	L1	B	￥基準単価	￥スライド単価
						1~9コ	10~20コ
SJSCP	Type	No.					
		6A	1/8	9	7	12	380 220
		8A	1/4	11	9	16	410 240
		10A	3/8	14	12	19	480 320
		15A	1/2	15	13	24	550 370

②表示数量超えはWOSにてご確認ください。

型式	Type	R · Rc (PT)	L1	L2	￥基準単価	￥スライド単価
					1~9コ	10~20コ
SJSXL	Type	No.				
		6A	1/8	19	22	680 540
		8A	1/4	24	25	830 660
		10A	3/8	28	29	1,170 930
		15A	1/2	32	34	1,570 1,250

②表示数量超えはWOSにてご確認ください。

型式	Type	Rc (PT)	L1	L2	￥基準単価	￥スライド単価
					1~9コ	10~20コ
SJSFL	Type	No.				
		6A	1/8	22	22	400 370
		8A	1/4	25	25	520 470
		10A	3/8	29	29	810 750
		15A	1/2	34	34	1,210 1,000



②表示数量超えはWOSにてご確認ください。

型式	Type	R (PT)	L1	L2	￥基準単価	￥スライド単価
					1~9コ	10~20コ
SJSML	Type	No.				
		6A	1/8	17	17	330 300
		8A	1/4	22	22	400 370
		10A	3/8	25	25	510 480
		15A	1/2	29	29	810 750

②表示数量超えはWOSにてご確認ください。

型式	Type	Rc (PT)	L	L1	￥基準単価	￥スライド単価
					1~9コ	10~20コ
SJSFT	Type	No.				
		6A	1/8	44	22	450 400
		8A	1/4	50	25	720 650
		10A	3/8	58	29	1,200 1,100
		15A	1/2	68	34	1,800 1,650

②表示数量超えはWOSにてご確認ください。

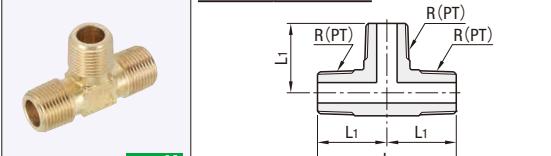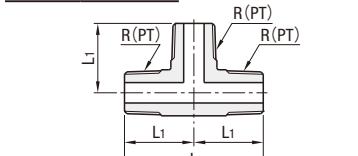■オスチーズ	Type	■材質
	SJSMT	C3771
		
		

②表示数量超えはWOSにてご確認ください。

■メス・オスチーズ	Type	■材質

<tbl_r cells="3" ix="5" maxcspan="1" maxrspan="1" usedcols