

銅管/銅管用継手

CADデータフォルダ名: 51_Pipes_Fitting_Valves

■銅管

Type	材質	規格
DKE	リン酸銅 (C1220)	JIS H: 3300

RoHS 10

型式		L		t	¥基準単価					
Type	D	指定1mm単位			L10 ~100	L101 ~200	L201 ~400	L401 ~600	L601 ~800	L801 ~1000
DKE	3	10~250	1	1	330	420	590	—	—	—
	4				330	420	590	680	—	—
	5	10~500			380	480	690	800	—	—
	6				420	530	750	880	—	—
	8				440	580	830	980	1,220	1,450
	10				480	610	860	1,020	1,250	1,480
	12	10~900	1.5	1.5	530	690	970	1,150	1,420	1,680
	14				580	780	1,180	1,580	1,980	2,380
	15				620	830	1,270	1,700	2,130	2,570
	16	10~1000			700	970	1,500	2,030	2,570	3,100
	18				780	1,080	1,680	2,280	2,880	3,480

■D寸・L寸公差

以上	以下	D	L
3	6	±0.1	±0.1
7	30	±0.2	±0.2
31	120	±0.3	±0.3
121	400	±0.5	±0.5
401	1000	±0.8	±0.8

■C寸法

以上	以下	C
D3	D12(12.7)	0.3
D14	D18	0.5

Order 注文例

型式 - L

DKE10 - 300

Delivery 出荷日

3 日日出荷

在庫品 翌日出荷 P.133

※ストークT 当日出荷 400円/1本 正午迄 P.134

※ストークA 翌日出荷 200円/1本 PM 6:00迄

※ストークAIは3本以上で1明細行当たり一律540円

Price 価格

数量スライド価格 (※1円未満切り捨て) P.133

数量区分	標準対応	個別対応
小口	1~9	10~29
大口	30~50	51~
値引率	基準単価 5%	10% お見積り

※表示数量超えはWOSにてご確認ください。

■銅管用継手

—おねじコネクター—



■銅管用継手

—おねじエルボコネクター—



Technical drawing of a 90-degree elbow fitting. The drawing shows the profile of the elbow with dimensions: D (outer diameter of the horizontal section), L1 (length of the horizontal section), L2 (length of the vertical section), T1 (thickness of the horizontal section), and T (thickness of the vertical section). The material is specified as 黄銅 (Brass) with a strength grade of 70.

材質 黄銅

■銅管用継手

—おねじコネクター—



■銅管用継手

—おねじコネクター—



Technical drawing of a T-shaped pipe fitting. The drawing shows a side view of the fitting, which has a central horizontal pipe section and a vertical flange on the right. Dimensions are labeled: 'T' points to the top of the vertical flange; 'T1' points to the top of the horizontal pipe section; 'D' is the outer diameter of the horizontal pipe; 'L2' is the length of the horizontal pipe section; 'L1' is the length of the vertical flange; and 'L' is the total length of the fitting. The material is specified as '材質 黄銅' (Material: Brass).

Order 注文例

型式 - T

DKPT8 - 2

Delivery 出荷日

在庫品 翌日出荷 P.133

※ご希望によりPM6:00迄、当日出荷受付致します。


Price 価格

数量スライド価格 (※1円未満切り捨て) P.133

数量区分	標準対応	個別対応
小口	1~9	10~29
大口	30~50	51~
値引率	基準単価 5%	10% お見積り

※表示数量超えはWOSにてご確認ください。

Example 使用例

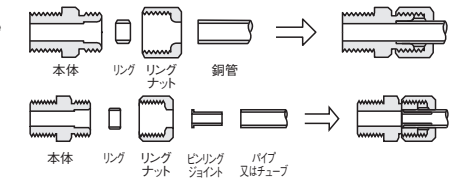

- ・ピンリングジョイント (※P.1350) は、肉厚の薄い金属パイプや硬質チューブを銅管用継手と使用する際にご利用頂けます。
- ・接続管にリングナットおよびリングをはめ、接続管の先端を本体の当り止めまで挿入し、ナットを手締りしてください。なお、手締り後の締付においてはスパナおよびトルクレンチ等を使用して、締付を行ってください。
- ・なまし銅管は軟らかいため、本リングタイプではなく、なまし銅管用継手 (※P.1352) をご使用ください。

継手仕様

使用流体	エア・水・工業油
常用使用圧力	3.5MPa
最高使用圧力	7.0MPa
使用温度範囲	-20~150℃ (凍結なきこと)

銅管用継手

CADデータフォルダ名: 51_Pipes_Fitting_Valves

■銅管用継手

—ユニオン—

DKUS

RoHS 10

材質 黄銅