



油圧・水圧用継手

-ストレートタイプ-





油圧・水圧用継手



-ストレートタイプ・45°エルボタイプ・エルボタイプ-

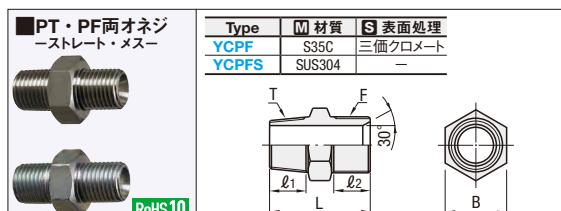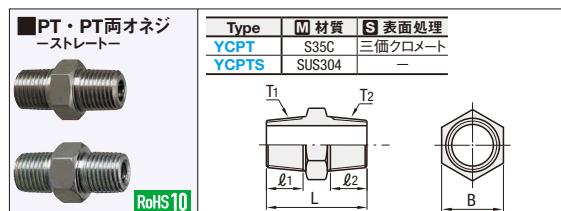



型式 Type	No.	T R(PT)	T ₂ R(PT)	L	l ₁	l ₂	B	¥基準単価	
								YCPPT	YCPPTS
YCPPT	11	1/8	1/8	26	10	10	12	200	650
YCPPTS	12	1/8	1/4	31	10	13	17	260	660
()内は YCPTSの寸法 になります。	13	1/8	3/8	33	10	15	21	270	-
YCPTS	22	1/4	1/4	34	13	13	17	280	680
()内は YCPTSの寸法 になります。	23	1/4	3/8	36	13	15	21	280	690
YCPTS	33	3/8	3/8	37	15	15	21	290	720
()内は YCPTSの寸法 になります。	34	3/8	1/2	40(46)	14(16)	17(19)	26(22)	450	1,300
YCPTS	44	1/2	1/2	43	17	17	26(22)	460	1,250
()内は YCPTSの寸法 になります。	46	1/2	3/4	46(48)	17(18)	19	32(27)	650	1,430
YCPTS	66	3/4	3/4	48	19	19	32(27)	680	1,530

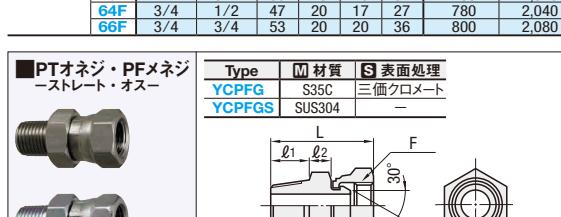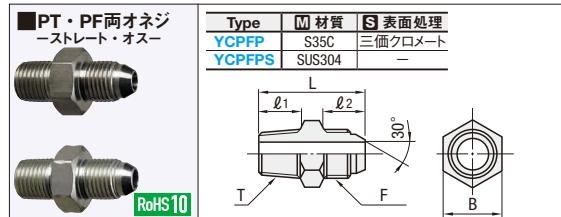

型式 Type	No.	T R(PT)	F G(PF)	L	l ₁	l ₂	B	¥基準単価	
								YCPFP	YCPFPS
YCPFP	11F	1/8	1/8	31	10	13	14	200	650
YCPFPS	12F	1/8	1/4	34	10	16	19	240	660
()内は YCPFPSの寸法 になります。	13F	1/8	3/8	37	10	17.5	22	280	-
YCPFPS	21F	1/4	3/8	34	13	13	14	310	680
()内は YCPFPSの寸法 になります。	22F	1/4	3/8	37	13	16	19	320	700
YCPFPS	23F	1/4	3/8	38.5	13	17.5	22	330	720
()内は YCPFPSの寸法 になります。	31F	3/8	1/8	37	15	13	19	340	-
YCPFPS	32F	3/8	1/4	38.5	15	16	19	350	740
()内は YCPFPSの寸法 になります。	33F	3/8	3/8	40.5	15	17.5	22	360	760
YCPFPS	34F	3/8	1/2	45	15	20	27	410	1,130
()内は YCPFPSの寸法 になります。	44F	1/2	1/2	48	18	20	27	470	1,180
YCPFPS	46F	1/2	3/4	52	18	22	32	780	2,040
()内は YCPFPSの寸法 になります。	66F	3/4	3/4	54	20	22	36	800	2,080

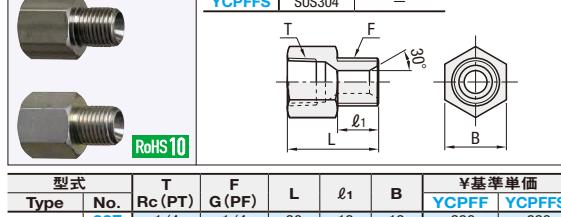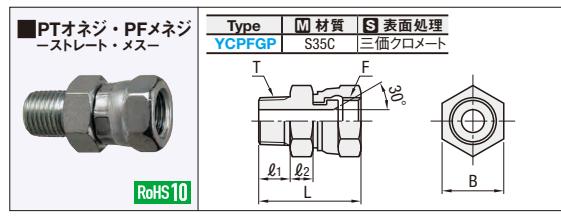

型式 Type	No.	T R(PT)	F G(PF)	L	l ₁	l ₂	B	¥基準単価	
								YCPFG	YCPFFP
YCPFG	22F	1/4	1/4	38	13	8	19	520	
YCPFG	33F	3/8	3/8	42	15	8	22	610	
()内は YCPFGの寸法 になります。	44F	1/2	1/2	50	18	10	27	830	

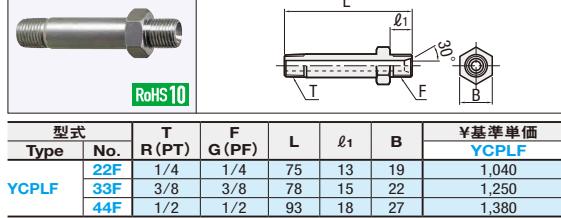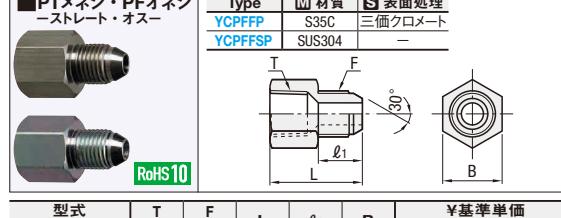

型式 Type	No.	T R(PT)	F G(PF)	L	l ₁	l ₂	B	¥基準単価	
								YCPFFP	YCPFFSP
YCPFFP	22F	1/4	1/4	33	16	19		390	930
YCPFFP	33F	3/8	3/8	37	18	22		490	970
()内は YCPFFPの寸法 になります。	44F	1/2	1/2	42	20	27		560	1,350

■仕様 使用流体 油・水
最高使用圧力 20.6MPa(210kgf/cm²以下)Order
注文例
YCPFT1
Delivery
出荷日
在庫品
翌日出荷
ご希望によりPM600迄、
当日出荷受付致します。

P133

■数量スライド価格 (①1未満切り捨て) P133
数量区分 標準対応 小口 大口
数量 1~9 10~19 20~30 31~
値引率 基準単価 5% 10% 見積り

P133

①表示数量超えはWOSにてご確認ください。

