


機械構造用シームレスパイプ

機械、自動車、機器などの機械部品に使用される鋼管です。

型式は寸法や数量により異なります。

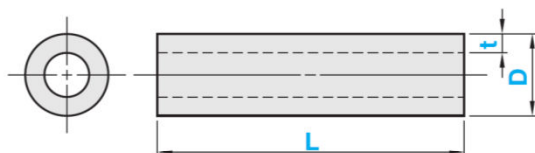

❗ 錆が付着している場合があります。

■D寸公差

区分	公差
50未満	±0.5
50以上	±1%

■L寸公差

公差
±1

■t寸公差

区分	公差
4未満	-0.5 ~ +0.6
4以上	-12.5% ~ +15%

D (外径)	t(肉厚)						L (長さ) 指定1mm単位		
34	6.4						10～2000		
38.1	6	8							
45	6								
48.6	8	9	10	12					
50.8	6								
54	8	10	12						
57	8	12							
60.5	8	10	12						
63.5	8	10	12	15					
65	10	12	15						
70	8	10	12	15	18	20			
73	8	10	12	15					
76.3	10	15	18						
80	8	10	12	15	18	20			
82.6	10	12	15	18					
85	10	12	15	20					
89.1	8	10	12	15	18	20			
95	10	12	15	18	20	25			
101.6	10	12	15	18	20	25			30
105	10	15	20						
110	15	20	25						
114.3	10	12	15	20	30				
120	12	15	18	20	25	30			
127	10	12	15	18	20	25			30
130	15	20	25	30					
135	15	20	25	30					
139.8	12	18	20	25	30	35			
146	12	20							
152.4	15	20	25	30	35				
159	15	25	30	35					
165.2	20	25	30	35					
168.3	30								
177.8	20	25	30	35	40				
318.5	20						14～2000		