

# 先端加工付ブロックコアピン

—価格—

# ブロックコアピン

—横幅ワイドタイプ—

追加加工価格も数量スライド適用 P.47



Price 価格

■数量スライド価格 (●1円未満切り捨て) P.47	
数量	1~9 10~19 20~29 30~50 表示数量超えは
値引率	基準単価 5% 10% 15% 価格・出荷日お見積り

●ORVAR® SUPREME 及び RIGOR® は ウッデホルム株式会社の登録商標です。

## ■10A形状・11A形状

型式	W	P	¥基準単価 1~9本					
			1.00~1.99	2.00~3.00	3.01~5.00	5.01~10.00	10.01~15.00	15.01~20.00
BCSH10A BCSH11A (SKH51)	1.00~1.99		11,990	12,940	13,780	14,380	—	—
	2.00~3.00		12,940	8,220	8,220	8,490	7,600	—
	3.01~5.00		13,780	8,220	8,220	8,490	7,600	7,880
	5.01~10.00		14,380	8,490	8,490	7,470	7,890	8,350
	10.01~15.00		—	7,600	7,600	7,890	8,210	8,990
15.01~20.00		—	—	7,880	8,350	8,990	9,410	
BCSR10A BCSR11A (RIGOR®)	1.00~1.99		12,550	13,550	14,420	15,060	—	—
	2.00~3.00		13,550	8,610	8,710	8,970	9,490	—
	3.01~5.00		14,420	8,710	7,460	7,370	7,500	7,680
	5.01~10.00		15,060	8,970	7,370	7,170	7,540	8,240
	10.01~15.00		—	9,490	7,500	7,540	8,240	8,540
15.01~20.00		—	—	7,680	8,240	8,540	8,960	
BCSV10A BCSA10A BCSV11A BCSA11A (ORVAR® SUPREME)	1.00~1.99		12,930	13,960	14,860	15,510	—	—
	2.00~3.00		13,960	8,860	8,610	8,850	9,090	—
	3.01~5.00		14,860	8,610	7,610	7,690	7,920	8,320
	5.01~10.00		15,510	8,850	7,690	7,510	7,780	8,550
	10.01~15.00		—	9,090	7,920	7,780	8,330	8,860
15.01~20.00		—	—	8,320	8,550	8,860	10,270	
BCSN10A BCSN11A (NAK80)	1.00~1.99		12,020	12,980	13,820	14,420	—	—
	2.00~3.00		12,980	8,250	8,250	8,090	8,100	—
	3.01~5.00		13,820	8,250	7,280	7,000	7,090	7,250
	5.01~10.00		14,420	8,090	7,000	6,770	6,840	7,420
	10.01~15.00		—	8,100	7,090	6,840	7,340	7,830
15.01~20.00		—	—	7,250	7,420	7,830	8,420	

## ■12A形状

型式	W	P	¥基準単価 1~9本					
			1.00~1.99	2.00~3.00	3.01~5.00	5.01~10.00	10.01~15.00	15.01~20.00
BCSH12A (SKH51)	1.00~1.99		12,910	13,940	14,850	15,490	—	—
	2.00~3.00		13,940	8,850	8,850	9,120	8,240	—
	3.01~5.00		14,850	8,850	8,850	9,120	8,240	8,510
	5.01~10.00		15,490	9,120	9,120	8,100	8,530	8,980
	10.01~15.00		—	8,240	8,240	8,530	8,840	9,630
15.01~20.00		—	—	8,510	8,980	9,630	10,040	
BCSR12A (RIGOR®)	1.00~1.99		13,470	14,550	15,490	16,170	—	—
	2.00~3.00		14,550	9,240	9,350	9,590	10,120	—
	3.01~5.00		15,490	9,350	8,090	8,010	8,130	8,320
	5.01~10.00		16,170	9,590	8,010	7,800	8,170	8,870
	10.01~15.00		—	10,120	8,130	8,170	8,870	9,180
15.01~20.00		—	—	8,320	8,870	9,180	9,580	
BCSV12A BCSA12A (ORVAR® SUPREME)	1.00~1.99		13,850	14,950	15,930	16,610	—	—
	2.00~3.00		14,950	9,500	9,230	9,490	9,720	—
	3.01~5.00		15,930	9,230	8,240	8,320	8,550	8,940
	5.01~10.00		16,610	9,490	8,320	8,130	8,400	9,190
	10.01~15.00		—	9,720	8,550	8,400	8,970	9,490
15.01~20.00		—	—	8,940	9,190	9,490	10,900	
BCSN12A (NAK80)	1.00~1.99		12,950	13,980	14,890	15,540	—	—
	2.00~3.00		13,980	8,880	8,880	8,710	8,740	—
	3.01~5.00		14,890	8,880	7,910	7,630	7,720	7,880
	5.01~10.00		15,540	8,710	7,630	7,390	7,470	8,040
	10.01~15.00		—	8,740	7,720	7,470	7,970	8,460
15.01~20.00		—	—	7,880	8,040	8,460	9,060	

## ■1B形状


型式	W	P	¥基準単価 1~9本					
			1.00~1.99	2.00~3.00	3.01~5.00	5.01~10.00	10.01~15.00	15.01~20.00
BCSH1B (SKH51)	1.00~1.99		11,990	12,940	13,780	14,380	—	—
	2.00~3.00		12,940	8,220	8,220	8,490	7,600	—
	3.01~5.00		13,780	8,220	8,220	8,490	7,600	7,880
	5.01~10.00		14,380	8,490	8,490	7,470	7,890	8,350
	10.01~15.00		—	7,600	7,600	7,890	8,210	8,990
15.01~20.00		—	—	7,880	8,350	8,990	9,410	
BCSR1B (RIGOR®)	1.00~1.99		12,600	13,600	14,480	15,120	—	—
	2.00~3.00		13,600	8,610	8,710	8,970	9,490	—
	3.01~5.00		14,480	8,710	7,460	7,370	7,500	7,680
	5.01~10.00		15,120	8,970	7,370	7,170	7,540	8,240
	10.01~15.00		—	9,490	7,500	7,540	8,240	8,540
15.01~20.00		—	—	7,680	8,240	8,540	8,960	
BCSV1B BCSA1B (ORVAR® SUPREME)	1.00~1.99		13,020	14,050	14,960	15,610	—	—
	2.00~3.00		14,050	8,860	8,610	8,850	9,090	—
	3.01~5.00		14,960	8,610	7,610	7,690	7,920	8,320
	5.01~10.00		15,610	8,850	7,690	7,510	7,780	8,550
	10.01~15.00		—	9,090	7,920	7,780	8,330	8,860
15.01~20.00		—	—	8,320	8,550	8,860	10,270	
BCSN1B (NAK80)	1.00~1.99		12,000	12,960	13,800	14,400	—	—
	2.00~3.00		12,960	8,250	8,250	8,090	8,100	—
	3.01~5.00		13,800	8,250	7,280	7,000	7,090	7,250
	5.01~10.00		14,400	8,090	7,000	6,770	6,840	7,420
	10.01~15.00		—	8,100	7,090	6,840	7,340	7,830
15.01~20.00		—	—	7,250	7,420	7,830	8,420	

## ■2B形状

型式	W	P	¥基準単価 1~9本					
			1.00~1.99	2.00~3.00	3.01~5.00	5.01~10.00	10.01~15.00	15.01~20.00
BCSH2B (SKH51)	1.00~1.99		13,180	14,230	15,150	15,810	—	—
	2.00~3.00		14,230	9,040	9,040	9,350	8,360	—
	3.01~5.00		15,150	9,040	9,040	9,350	8,360	8,680
	5.01~10.00		15,810	9,350	9,350	8,220	8,690	9,190
	10.01~15.00		—	8,360	8,360	8,690	9,030	9,890
15.01~20.00		—	—	8,680	9,190	9,890	10,350	
BCSR2B (RIGOR®)	1.00~1.99		13,810	14,910	15,880	16,560	—	—
	2.00~3.00		14,910	9,470	9,580	9,860	10,440	—
	3.01~5.00		15,880	9,580	8,210	8,110	8,250	8,450
	5.01~10.00		16,560	9,860	8,110	7,890	8,300	9,060
	10.01~15.00		—	10,440	8,250	8,300	9,060	9,400
15.01~20.00		—	—	8,450	9,060	9,400	9,860	
BCSV2B BCSA2B (ORVAR® SUPREME)	1.00~1.99		14,220	15,360	16,350	17,060	—	—
	2.00~3.00		15,360	9,750	9,470	9,740	10,000	—
	3.01~5.00		16,350	9,470	8,380	8,460	8,710	9,150
	5.01~10.00		17,060	9,740	8,460	8,250	8,550	9,410
	10.01~15.00		—	10,000	8,710	8,550	9,170	9,750
15.01~20.00		—	—	9,150	9,410	9,750	11,300	
BCSN2B (NAK80)	1.00~1.99		13,230	14,280	15,210	15,870	—	—
	2.00~3.00		14,280	9,070	9,070	8,900	8,910	—
	3.01~5.00		15,210	9,070	8,010	7,710	7,810	7,970
	5.01~10.00		15,870	8,900	7,710	7,440	7,520	8,160
	10.01~15.00		—	8,910	7,810	7,520	8,070	8,620
15.01~20.00		—	—	7,970	8,160	8,620	9,270	



型式	材質	硬度
BCSWH	SKH51	61~64HRC
BCSWS	STAVAX ESR®	27~35HRC
BCSWR	RIGOR®	53~55HRC
BCSW	ORVAR® SUPREME	47~49HRC
BCSWA	ORVAR® SUPREME	51~53HRC
BCSWN	NAK80	37~43HRC

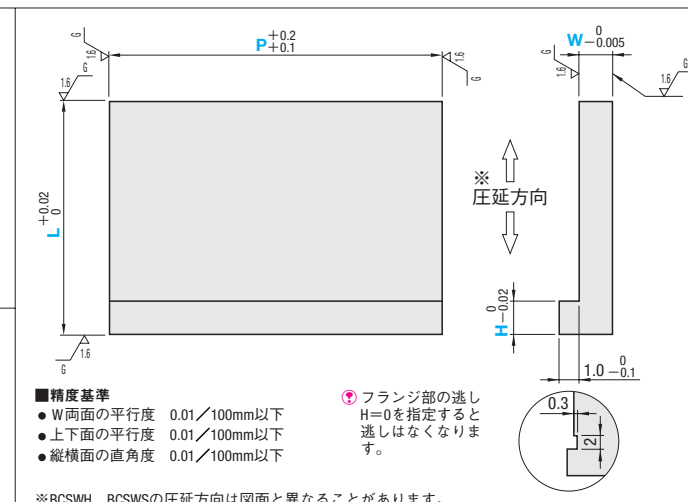

型式	L 指定0.01mm単位	P	W 指定0.01mm単位	H
BCSWH (SKH51) BCSWS (STAVAX ESR®) *BCSWR (RIGOR®) BCSW (ORVAR® SUPREME) BCSWA (ORVAR® SUPREME) BCSWN (NAK80)	10.00 ? *65.00 (100.00)	25 50  75 100	1.00~20.00  3.00~20.00	0 4 6

● STAVAX ESR® ORVAR® SUPREME 及び RIGOR® は ウッデホルム株式会社の登録商標です。  
 ● L寸の ( ) 内は、BCSWH・BCSWN (W≧7.01)、BCSWS (W≧5.01) のみの規格です。BCSWH・BCSWN (L65.01~100.00) は W≧7.01 ● \*W<2.00 → L≦50 ● \*BCSWRは、W≦3.49 → L≦50.00

Order 注文例 **型式** - **L** - **P** - **W** - **H**  
 BCSWR - 20.00 - P50 - W3.00 - H6

Delivery 出荷日 **3** 日目発送

Price 価格

■数量スライド価格 (●1円未満切り捨て) P.47	
数量	1~4 5~9 10~14 15~20 表示数量超えは
値引率	基準単価 5% 10% 15% 価格・出荷日お見積り

● ( ) 内の価格はL65.01~100.00に適用

型式	W	P	¥基準単価 1~4本																
			BCSWH				BCSWS				BCSWR				BCSWA				BCSWN
			25	50	75	100	25	50	75	100	25								