

# 溝無しガイドレール

—フリー指定タイプ(油溝なし・油溝付)—

追加加工価格も数量スライド適用 P.49

RoHS

■取付ボルト穴2ヶ所 2H

■取付ボルト穴3ヶ所 3H

■取付ボルト穴4ヶ所 4H

■ボルト穴サイズ表

W	T	d1	d2	t1	ω1
10	10~20				4.5
12.5	10~30	8	4.5	5	5
15	10~40	9.5	5.5	6	6
20	15~24	11	6.5	7	
	25~50	14	9	9	9
25	20~50				10
30	25~50				
35	30~35	17	11.5	11	11
40	30~50	19	12.5	13	13

■油溝詳細 (FGRSM-□H・FGRMM-□H)

☝ 指示のない角部はC≦1となります。


型式	材質	硬度
油溝なし FGRS-□H FGRM-□H	SKS3	53~56HRC
油溝付 FGRSM-□H FGRMM-□H	HPM2T相当	37~41HRC

■油溝ピッチ早見表

T	P
10~12	8
13~14	13
15~19	18
20~24	28
25~29	38
30~34	48
35~39	58
40~50	68

☝ L≦P+10の時、油溝が1サイクル(1ピッチ)分、切れない場合がありますのでご注意ください。

■油溝ピッチ算出方法

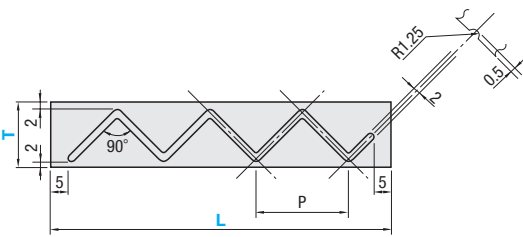

型式 Type	No. (ボルト)	W	T		L		ボルト穴ピッチ 指定0.5mm単位								
			指定1mm単位		指定5mm単位		A		B		C		D		
			min.	max.	min.	max.	min.	max.	min.	max.	min.	max.			
油溝なし FGRS (SKS3) FGRM (HPM2T相当)  油溝付 FGRSM (SKS3) FGRMM (HPM2T相当)	2H	10	10~20	*35~100	6	B-10	A+10	2H	L-6	B+10	3H	L-6	C+10	4H	L-6
								3H	C-10		4H	D-10			
		12.5	10~30	7	B-11.5	A+11.5	2H	L-7	B+11.5	3H	L-7	C+11.5	4H	L-7	
							3H	C-11.5		4H	D-11.5				
		15	10~40	7.5	B-13	A+13	2H	L-7.5	B+13	3H	L-7.5	C+13	4H	L-7.5	
							3H	C-13		4H	D-13				
	3H	20	15~24	40~200	9	B-16	A+16	2H	L-9	B+16	3H	L-9	C+16	4H	L-9
								3H	C-16		4H	D-16			
		25	20~50	9	B-19	A+19	2H	L-10.5	B+19	3H	L-10.5	C+19	4H	L-10.5	
							3H	C-19		4H	D-19				
		30	25~50	10.5	B-21	A+21	2H	L-10.5	B+21	3H	L-10.5	C+21	4H	L-10.5	
							3H	C-21		4H	D-21				
35	30~35	10.5	B-21	A+21	2H	L-10.5	B+21	3H	L-10.5	C+21	4H	L-10.5			
					3H	C-21		4H	D-21						
40	30~50	10.5	B-21	A+21	2H	L-10.5	B+21	3H	L-10.5	C+21	4H	L-10.5			
					3H	C-21		4H	D-21						

☝ \*印のL35は油溝なし (FGRS・FGRM) のみ適用

Order 注文例

型式	T	L	A	B	C	D
2H FGRS-2H12.5	10	100	A13.0	B33.5		
3H FGRS-3H12.5	10	100	A13.0	B33.5	C54.5	
4H FGRS-4H12.5	10	100	A13.0	B33.5	C54.5	D78.5

Delivery 出荷日

- FGRS-□H 5 日目発送
- FGRSM-□H 5 日目発送
- FGRM-□H 5 日目発送
- FGRMM-□H 5 日目発送

☝ 同一サイズ3本以上は一律810円

Alterations 追加加工

型式	T	L	A	B	(BP・KP・MC・CC)
FGRM-2H12.5	10	100	A13.0	B33.5	MC

☝ 5 日目発送

Price 価格

■数量スライド価格 (☝1円未満切り捨て) P.47

数量	1~9	10~19	20~30	表示数量超えは
値引率	基準単価	5%	10%	価格・出荷日お見積り

油溝なし

W	T	¥基準単価 1~9本									
		L35~65		L70~95		L100~135		L140~165		L170~200	
		FGRS	FGRM	FGRS	FGRM	FGRS	FGRM	FGRS	FGRM	FGRS	FGRM
10	10~14	3,790	4,240	3,820	4,280						
	15~20	3,980	4,460	4,010	4,490						
12.5	10~14	4,080	4,570	4,120	4,610						
	15~20	4,280	4,790	4,310	4,830						
15	10~14	4,230	4,720	4,250	4,760	5,930	5,350				
	15~20	4,430	4,920	4,470	5,010	6,240	5,610				
20	10~14	4,660	5,220	4,710	5,270	6,550	5,900	7,470	6,730		
	15~20	4,860	5,440	4,890	5,490	6,830	6,150				
25	10~14	4,880	5,470	4,920	5,460	6,860	6,180	7,820	7,050		
	15~20	5,130	5,750	5,180	5,810	7,210	6,490	8,220	7,410		
30	10~14	5,390	6,040	5,440	6,090	7,580	6,830	8,650	7,790		
	15~20	5,510	6,170	5,560	6,230	7,750	6,980	8,840	7,960		
35	10~14	5,880	6,590	5,930	6,480	8,270	7,440	9,430	8,490		
	15~20	6,360	7,130	6,410	7,090	8,950	8,050	10,200	9,180		
40	10~14	6,700	7,510	6,760	7,580	9,420	8,490	10,740	9,670		
	15~20	7,000	7,840	7,050	7,880	9,930	8,860	11,210	10,090		
45	10~14	7,270	8,150	7,330	8,210	10,220	9,190	11,650	10,480		
	15~20	7,570	8,490	7,630	8,510	10,730	9,690	12,110	10,930		

油溝付

W	T	¥基準単価 1~9本									
		L40~65		L70~95		L100~135		L140~165		L170~200	
		FGRSM	FGRMM	FGRSM	FGRMM	FGRSM	FGRMM	FGRSM	FGRMM	FGRSM	FGRMM
10	10~14	4,200	4,760	4,330	4,890						
	15~20	4,390	4,970	4,520	5,100						
12.5	10~14	4,500	5,080	4,630	5,220						
	15~20	4,690	5,300	4,820	5,440						
15	10~14	4,630	5,240	4,760	5,380	6,640	6,050				
	15~20	4,840	5,480	4,980	5,620	6,950	6,320				
20	10~14	5,070	5,730	5,210	5,870	7,260	6,610	8,280	7,540		
	15~20	5,260	5,950	5,400	6,100	7,540	6,850				
25	10~14	5,300	5,980	5,440	6,140	7,920	7,200	9,030	8,220		
	15~20	5,540	6,260	5,680	6,410	8,290	7,540	9,460	8,600		
30	10~14	5,920	6,600	6,070	6,750	8,640	7,890	9,650	8,770		
	15~20	6,300	7,100	6,440	7,260	9,260	8,410	10,240	9,300		
35	10~14	6,780	7,640	6,920	7,790	9,660	8,760	11,020	9,980		
	15~20	7,110	8,020	7,270	8,180	10,130	9,200	11,550	10,490		
40	10~14	7,410	8,350	7,560	8,510	10,550	9,560	12,020	10,900		
	15~20	7,690	8,660	7,840	8,740	10,930	9,910	12,460	11,300		
45	10~14	8,120	9,100	8,250	9,290	11,540	10,450	13,160	11,900		
	15~20	8,500	9,580	8,680	9,760	12,030	10,870	13,680	12,400		

Alterations	Code	Spec.	¥/1Code
タップ穴加工 詳細 P.803	BP	BP4 BP5 BP6 BP8	600
タップ穴加工 ☝ W10~25に適用 詳細 P.803	KP	T10~35 T36~50	900
タップ穴変更 ☝ W10~25に適用 詳細 P.804	MC		500
C面取り 詳細 P.804	CC	CC5~9 CC11 CC13	900