


位置決め付ロッキングブロック

ー幅(A)・角度(G)指定タイプ(インロー部4mm/8・10mm)ー



RoHS

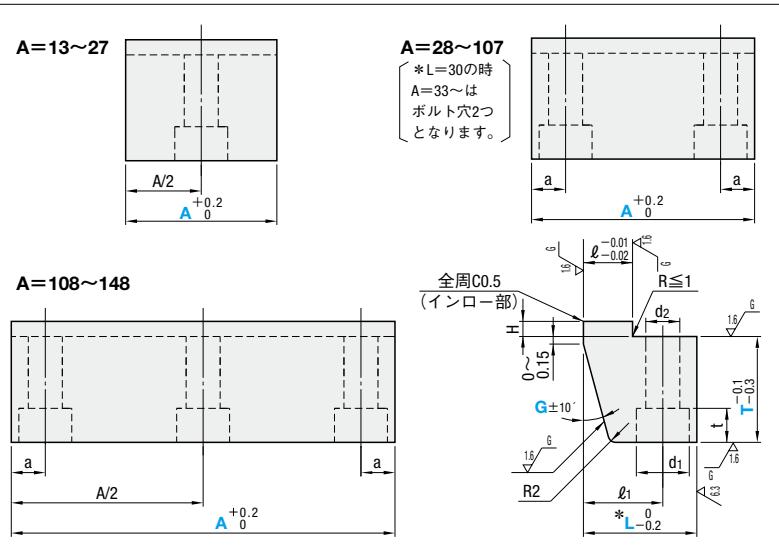

■インロー部 H=4mm

H	a	ℓ	ℓ_1	d ₁	d ₂	t	型式		T	指定1mm単位	G°単位		
							Type	L					
4	6	6	13	9.5	5.5	6	LBCSF (SKS3)		20	10 13~48	5~33		
									15	13~58	5~24		
									20	13~68	5~18		
									10	18~98	5~33		
	7	10	17	11	6.5	7			25	18~108	5~33		
									15	18~108	5~26		
									20	18~108	5~21		
									25	18~128	5~33		
	8	13	21	14	9	9	LBCMF (HPM2T相当)		30	23~128	5~31		
									20	(23~32:ボルト穴1つ) (33~36:ボルト穴2つ)	5~26		
									25	23~128	5~22		
									30	23~128	5~28		
									35	23~128	5~24		
									40	23~128	5~21		

①一部のサイズは定尺タイプ(LBCSK・LBCMK P.727)、角度(G)指定タイプ(LBCS・LBCM P.729)でもお選び頂けます。ご確認のうえご利用ください。

インロー部の強度計算 P.1508



型式 - T - A - G
LBCSF30 - 25 - A58 - G18

• LBCSF 5 日目出荷

• LBCMF 5 日目出荷 3日目出荷 800円/1本 PM 8:00迄 P.48

③3本以上で1明細行当たり一律2,160円

■数量スライド価格 (③1円未満切り捨て) P.47

数量区分	標準対応	個別対応 大口
数量 基準単価	1~9 5%	10~19 10% 30~お見積り
値引率 基準単価	5% 10% 10% お見積り	

③表示数量超えはWOSにてご確認ください。

■インロー部 H=4mm

Type	L	T	¥基準単価 1~9本						
			A13~27	A28~48	A49~68	A69~88	A89~107	A108~128	A129~148
LBCSF (SKS3)	20	10 15 20	4,730	5,340	5,710	—	—	—	—
		10 15	5,830	6,430	6,870	7,310	7,700	8,270	—
		20 25	5,830	6,590	7,050	7,490	7,880	8,460	—
	30	15 20	5,980	7,770	8,320	8,580	8,990	9,650	—
		25 30	5,980	7,840	8,320	8,580	8,990	9,650	—
		35 40	—	8,790	9,300	9,580	9,970	10,650	12,020
LBCMF (HPM2T相当)	20	10 15 20	4,280	4,840	5,200	—	—	—	—
		10 15	5,190	5,740	6,160	6,560	6,940	7,500	—
		20 25	5,190	5,880	6,330	6,750	7,150	7,730	—
	30	15 20	5,320	6,940	7,460	7,740	8,060	8,710	—
		25 30	5,320	7,030	7,460	7,740	8,060	8,710	—
		35 40	—	7,870	8,350	8,650	8,930	9,610	10,910



Example
使用例

