


溝付ガイドレール

ーL寸指定タイプ／油溝なし・油溝付(ガイド溝高さ5mm・8mm)ー


追加工価格も数量スライド適用 ㊦ P.49

型 式		材 質	硬 度	S ガイド 溝高さ	U	R
油溝なし	油溝付					
GR5SFC-□H	GR5SFCM-□H	SKS3	53～56HRC	5	2.5	R≤0.3
GR5MFC-□H	GR5MFCM-□H	HPM2T相当	37～41HRC			
GR5SF-□H	GR5SFM-□H	SKS3	53～56HRC	5	3.5	
GR5MF-□H	GR5MFM-□H	HPM2T相当	37～41HRC			R≤0.8
GR8SF-□H	GR8SFM-□H	SKS3	53～56HRC	8	4.5	
GR8MF-□H	GR8MFM-□H	HPM2T相当	37～41HRC			



■取付ボルト穴2ヶ所 2H

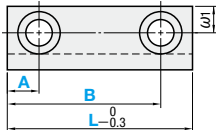

■取付ボルト穴3ヶ所 3H

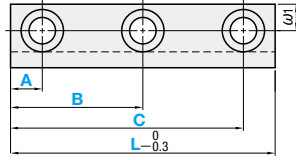

■取付ボルト穴4ヶ所 4H

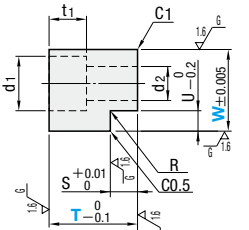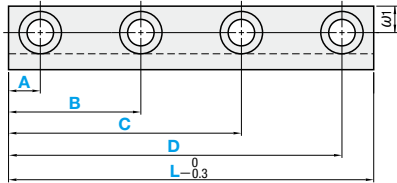


■ボルト穴サイズ表 ㊦ 指示のない角部はC≤1となります。

W	T	d1	d2	t1	ω1
10	12.5・15				4.5
12.5	12.5・15・20	8	4.5	5	5
15	12.5・15・20・25	9.5	5.5	6	6
20	15・20	11	6.5	7	9
25	20・25・30	14	9	9	10
30	25・30・35	17	11.5	11	11
40	30・40	19	12.5	13	13

■油溝詳細

(GR5SFCM-□H・GR5MFCM-□H)
 (GR5SFM-□H・GR5MFM-□H)
 (GR8SFM-□H・GR8MFM-□H)

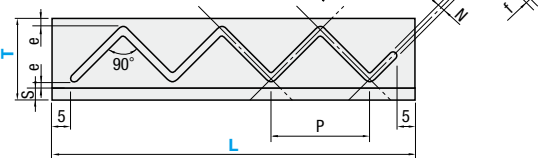■油溝ピッチ算出方法
 $P = (T - S - 2e - N) \times 2$

■油溝詳細寸法

T-S	e	N	f	R
T-S≤7.5	1.5	1.5	0.3	1.0
T-S≥10	2.0	2.0	0.5	1.25

㊦ L≤P+10の時、油溝が1サイクル(1ピッチ)分、切れない場合がありますのでご注意ください。

■油溝ピッチ早見表

T-S	P
7	2
7.5	3
10	8
12	12
15	18
17	22
20	28
22	32
25	38



■数量スライド価格 (㊦ 1円未満切り捨て) P.47

数量区分	標準対応	個別対応大口
数量	1～9	10～19
値引率	基準単価	5% 10% 31～ お見積り

㊦ 表示数量超えはWOSにてご確認ください。

油溝なし

		¥基準単価 1～9本															
W	T	L35～55				L60～75				L80～95				L100～115			
		GR5SF GR8SF GR5SFC	GR5MF GR8MF GR5MFC	GR5SF GR8SF GR5SFC	GR5MF GR8MF GR5MFC	GR5SF GR8SF GR5SFC	GR5MF GR8MF GR5MFC	GR5SF GR8SF GR5SFC	GR5MF GR8MF GR5MFC	GR5SF GR8SF GR5SFC	GR5MF GR8MF GR5MFC	GR5SF GR8SF GR5SFC	GR5MF GR8MF GR5MFC	GR5SF GR8SF GR5SFC	GR5MF GR8MF GR5MFC	GR5SF GR8SF GR5SFC	GR5MF GR8MF GR5MFC
10	12.5	3.960	3.570	4.320	3.880	4.670	4.210	4.670	4.210								
	15	4.080	3.670	4.440	3.990	4.790	4.310	4.790	4.310								
	12.5	3.510	3.160	3.860	3.480	4.240	3.820	4.630	4.170								
	20	3.590	3.230	3.950	3.560	4.310	3.880	4.670	4.210								
15	12.5	3.670	3.300	4.040	3.630	4.440	4.000	4.850	4.360								
	15	3.590	3.230	3.950	3.560	4.310	3.880	4.670	4.210	4.900	4.410	5.150	4.640				
	20	3.710	3.340	4.070	3.660	4.430	3.990	4.790	4.310	5.030	4.530	5.290	4.750				
	25	3.950	3.560	4.310	3.880	4.670	4.210	5.030	4.530	5.290	4.750	5.550	4.990				
20	12.5	4.230	3.800	4.650	4.190	5.120	4.610	5.630	5.080	5.910	5.340	6.200	5.600				
	15	4.070	3.660	4.430	3.990	4.790	4.310	5.150	4.640	5.750	5.180	6.120	5.510	6.410	5.770	6.730	6.060
	20	4.430	3.990	4.790	4.310	5.150	4.640	5.510	4.960	6.110	5.510	6.470	5.830	6.790	6.110	7.140	6.410
	25	4.910	4.420	5.270	4.740	5.630	5.070	5.990	5.390	6.590	5.930	6.950	6.250	7.300	6.570	7.670	6.890
25	12.5	5.040	4.970	5.580	5.470	5.770	5.650	6.250	6.150	6.790	6.720	6.950	6.880	7.300	7.220	7.670	7.580
	15	5.140	5.040	5.670	5.530	5.830	5.700	6.310	6.200	6.870	6.750	7.080	6.900	7.430	7.250	7.820	7.620
	20	5.240	5.180	5.800	5.690	5.990	5.880	6.500	6.400	7.050	6.970	7.480	7.140	7.850	7.500	8.240	7.870
	25	5.400	5.330	5.970	5.850	6.220	6.050	6.680	6.500	7.260	7.080	7.820	7.460	8.200	7.750	8.420	8.150

		¥基準単価 1～9本															
W	T	L50～65				L70～85				L90～105				L110～125			
		GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM	GR5SFM GR8SFM GR5MFM
30	25	5.990	5.390	6.350	5.720	6.710	6.040	7.070	6.360	7.550	6.790	8.020	7.220	9.700	8.300	11.260	10.140
	30	6.470	5.830	6.830	6.150	7.190	6.470	7.550	6.790	8.310	7.220	8.500	7.650	10.180	9.170	11.740	10.570
	35	7.110	6.710	7.720	6.940	8.230	7.380	8.470	7.520	9.020	7.940	9.510	8.420	10.820	9.590	12.490	11.140
	40	7.550	6.790	7.910	7.110	8.260	7.430	8.620	7.750	9.100	8.190	9.520	8.620	11.260	10.120	12.820	11.540
40	40	8.140	7.320	8.500	7.650	8.860	7.970	9.220	8.310	9.700	8.730	10.180	9.170	11.870	10.670	13.420	12.070

型 式		W	T 選択	L 指定5mm単位	ボルト穴ピッチ 指定0.5mm単位							
Type	No. (ボルト穴)				A		B		C		D	
					min.	max.	min.	max.	min.	max.	min.	max.
油溝なし GR5SFC (SKS3) GR5MFC (HPM2T相当)		10	12.5 15	2H 35 ^(*) ・40～75 3H 60～100 4H 100	6	B-10	A+10		2H L-6 3H C-10 4H C-10	B+10	3H L-6 4H D-10	C+10 4H L-6
油溝なし GR5SF (SKS3) GR5MF (HPM2T相当) GR8SF (SKS3) GR8MF (HPM2T相当)		2H 3H 4H	12.5 15 20	12.5 ^(*) ・40～75 15 20 25 20 15 ^(*) 20 25 20 25 30 25 30 30 35 30 40	7 7.5 9 10.5	B-11.5 B-13 B-16 B-19 B-21	A+11.5 A+13 A+16 A+19 A+21		2H L-7 3H C-11.5 4H C-11.5 2H L-7.5 3H C-13 4H C-13 2H L-9 3H C-16 4H C-16 2H L-10.5 3H C-19 4H C-19 2H L-10.5 3H C-21 4H C-21	B+11.5 B+13 B+16 B+19 B+21	3H L-7 4H D-11.5 3H L-7.5 4H D-13 3H L-9 4H D-16 3H L-10.5 4H D-19 3H L-10.5 4H D-21	C+11.5 C+13 C+16 C+19 C+21 4H L-7 4H L-7.5 4H L-9 4H L-10.5 4H L-10.5

㊦ (*1)のL35は油溝なしタイプのみ適用 ㊦ (*2)はGR5SF・GR5SFM・GR5MF・GR5MFMのみ適用



Order 注文例	型 式	T	L	A	B	C	D
	2H GR5SF-2H12.5	15	70	A13.0	B29.0		
	3H GR5SF-3H12.5	15	70	A13.0	B29.0	C39.0	
	4H GR5SF-4H12.5	15	100	A13.0	B29.0	C39.0	D49.0



Delivery 出荷日	材 質 (SKS3)	目日出荷	材 質 (HPM2T相当)	目日出荷	ス tock B	3日目出荷	300円/1本	PM 8:00迄	㊦ P.48
	5	目日出荷	5	目日出荷					

㊦ 3本以上で1明細行当たり一律810円



Alterations 追加加工	型 式	T	L	A	B	(BP・KP・MC・CC)	目日出荷
	GR5MF-2H12.5	15	70	A13.0	B29.0	MC	5

Alterations	Code	Spec.	¥/1Code
BP	タップ穴加工 詳細 ㊦ P.801	BP4 BP5	600
		BP6 BP8	800
KP	ノック穴加工 ㊦ 材質HPM2T相当に適用 詳細 ㊦ P.801	T12.5～35 T40	900 1,200

Alterations	Code	Spec.	¥/1Code
MC	タップ穴に変更 ㊦ W10～25に適用 詳細 ㊦ P.802		500
CC	C面取り 詳細 ㊦ P.802	CC5～9 CC11 CC13	900 1,000

油溝付		¥基準単価 1～9本																							
W	T	L40～55				L60～75				L80～95				L100～115				L120～135		L140～150		L155～180		L185～200	
		GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM	GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM	GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM	GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM	GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM	GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM	GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM	GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM	GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM	GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM	GR5SFM GR8SFM GR5MFM	GR5MFM GR8MFM		
10	12.5	4.360	3.970	4.820	4.390	5.280	4.820	5.280	4.820																
	15	4.480	4.070	4.940	4.500	5.400	4.920	5.400	4.920																
12.5	12.5	3.920	3.570	4.370	3.990	4.860	4.430	5.340	4.880																
	15	4.000	3.640	4.460	4.070	4.920	4.490	5.380	4.920																
15	20	4.080	3.710	4.550	4.140	5.060	4.610	5.560	5.070																
	12.5	4.000	3.640	4.460	4.070	4.920	4.490	5.380	4.920	5.710	5.220	5.960	5.450												
	15	4.120	3.750	4.580	4.170	5.040	4.600	5.500	5.020	5.840	5.340	6.100	5.560												
	20	4.360	3.970	4.820	4.390	5.280	4.820	5.740	5.240	6.100	5.560	6.360	5.800												
20	25	4.640	4.220	5.160	4.700	5.730	5.220	6.340	5.790	6.720	6.140	7.020	6.410												
	15	4.480	4.070	4.940	4.500	5.400	4.920	5.860	5.350	6.560	5.980	6.920	6.310												
	20	4.840	4.400	5.300	4.830	5.760	5.250	6.220	5.690	6.920	6.310	7.280	6.630												
	25	5.320	4.830	5.780	5.250	6.240	5.680	6.700	6.100	7.400	6.740	7.760	7.060												
25	30	5.460	5.380	6.090	5.980	6.380	6.260	6.960	6.870	7.610	7.530	7.760	7.690												
	20	5.550	5.460	6.170	6.040	6.440	6.310	7.030	6.910	7.680	7.580	7.890	7.710												
	25	5.650	5.580	6.310	6.200	6.600	6.490	7.210	7.110	7.860	7.780	8.290	7.950												
	30	5.820	5.740	6.480	6.360	6.830	6.660	7.540	7.320	8.270	8.020	8.450	8.200												

W	T	¥基準単価 1～9本																													
		L50～65				L70～85				L90～105				L110～125				L130～145				L150～165				L170～185				L190～200	
30	25	6.400	5.800	6.860	6.230	7.320	6.650	7.780	7.080	8.360	7.610	8.830	8.030	10.510	9.110	12.070	10.940														
	30	6.880	6.230	7.340	6.660	7.800	7.080	8.260	7.510	9.120	8.030	9.310	8.460	10.990	9.980	12.550	11.360														
	35	7.520	7.120	8.240	7.540	8.740	7.950	9.190	8.270	10.820	8.750	10.320	9.230	11.630	10.400	13.300	12.180														
	40	7.960	7.210	8.420	7.630	8.870	8.050	9.330	8.470	10.910	9.000	10.320	9.430	12.070	10.940	13.630	12.350														
40	40	8.550	7.740	9.010	8.160	9.470	8.580	9.930	9.010	10.510	9.540	10.990	9.980	12.670	11.490	14.230	12.890														