


SPACERS FOR TAPERED PIN SETS
 テーパーピンセット用スペーサ

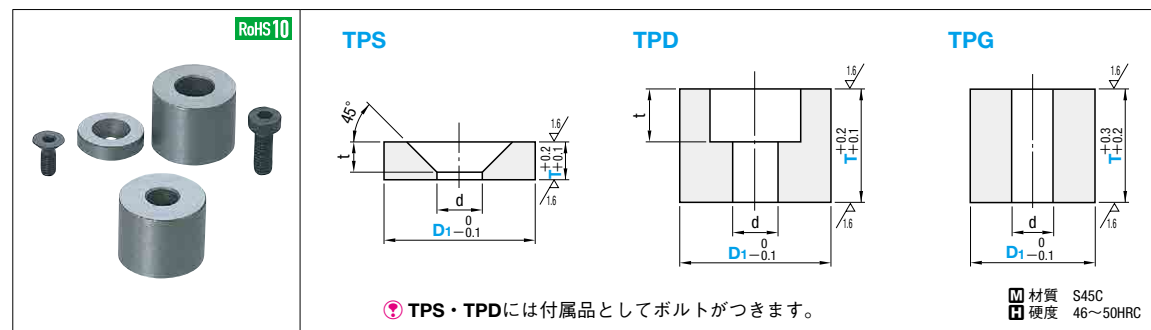


適用テーパピン D	型板厚	d	t	付属ボルト	型 式 Type	D ₁	T
13	20	4.5	3.0	FB 4-10	TPS	16	5
	25			FB 4-15			10
16	20	5.5		FB 5-12		20	5
	25			FB 5-16			10
20	25	6.5	4.0	FB 6-12		25	5
	30			FB 6-16			10
25	30	8.5	4.5	FB 8-15		32	5
	35			FB 8-20			10
30	40	10.5	7.5	FB 10-20		35	10
32				FB 10-20		38	10
10	25	4.5	6	CB 4-10	TPD	13	10
	30			CB 4-15			15
	35			CB 4-20			20
	40			CB 4-25			25
13	25			CB 4-10		16	10
	30			CB 4-15			15
	35			CB 4-20			20
	40			CB 4-25			25
16	25	5.5	7	CB 5-10		20	10
	30			CB 5-15			15
	35			CB 5-20			20
	40			CB 5-25			25
20	30	6.5	9	CB 6-16		25	10
	35			CB 6-15			15
	40			CB 6-20			20
	45			CB 6-25			25
25	50	8.5	10	CB 6-30		32	10
	60			CB 6-40			15
	70			CB 6-50			20
	80			CB 8-15			25
30	50	10.5	12	CB 8-20		35	10
	60			CB 8-25			15
	70			CB 8-35			20
	80			CB 8-45			25
32	50	12.5	14	CB 8-55		38	10
	60			CB 10-20			15
	70			CB 10-30			20
	80			CB 10-40			25
35	50	12.5	14	CB 10-50		42	10
	60			CB 10-20			15
	70			CB 10-30			20
	80			CB 12-25			25
42	50	12.5	14	CB 12-30		48	10
	60			CB 12-25			15
	70			CB 12-35			20
	80			CB 12-35			25

Order 注文例
 型 式 - T
 TPS20 - 10

Delivery 出荷日
 在庫品

SPACERS FOR TAPERED PIN SETS
 テーパーピンセット用スペーサ
 - 厚み指定タイプ -

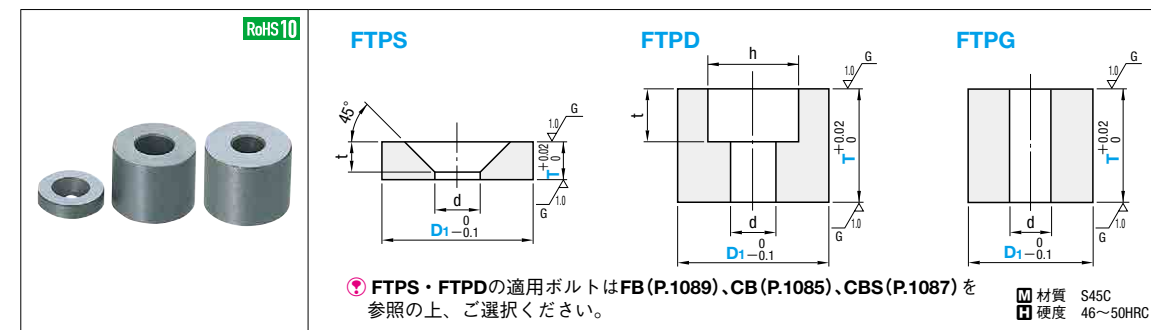

適用テーパピン D	h	d	t	適用ボルト	型 式 Type	D ₁	T 指定0.1mm単位
13	-	4.5	3.0	FB4	FTPS	16	5.0~10.0
16		5.5		FB5		20	
20		6.5	4.0	FB6		25	6.0~10.0
25		8.5	4.5	FB8		32	6.5~10.0
10	8	4.5	6	CB4	FTPD	13	10.0~25.0
13						16	
16	9.5	5.5	7	CB5		20	10.0~35.0
20						25	10.0~14.9
25	14	8.5	10	CB8		32	15.0~55.0
30						35	20.0~50.0
32	17.5	10.5	12	CB10		38	
35						42	15.0~24.9
42	20	12.5	14	CB12		48	25.0~45.0
							20.0~40.0

Order 注文例
 型 式 - T
 FTPS20 - 9.8

Delivery 出荷日
 3 日目出荷 急 ストック A