

入れ子止め


-テーパタイプ-




RoHS10

型式	材質	硬度
ICS	SKS3	53~56HRC
ICH	HPM2T相当	37~41HRC


L ≤ 100

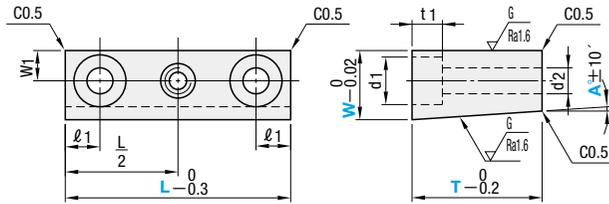

W	l ₁
10	7.5
15	
20	
25	10
30	

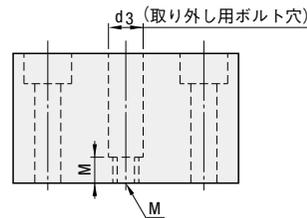

L ≥ 110

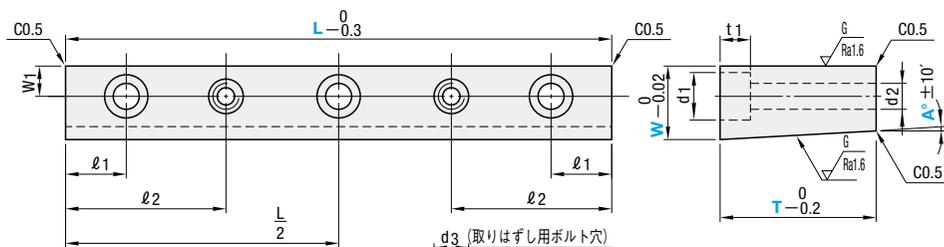

W	l ₁
10	10
15	
20	
25	15
30	

L	l ₂	
	W=10・15・20	W=25・30
110	32.5	35
120	35	37.5
130	37.5	40
140	40	42.5
150	42.5	45
160	45	47.5
170	47.5	50
180	50	52.5

d1	d2	d3	t1	M	W1	型式		T	L 指定10mm単位	A	
						Type	W				
8	4.5	5	5	4	5	ICS (SKS3) ICH (HPM2T相当)	10	15	30~100	1	
								*25			
								*30			
11	6.5	7	7	6	6.5		15	20	40~180		3
								25			
								30			
							20	*45			
								*50			
								20			
14	9	9	9	8	9		25	25	50~180		5
								30			
								35			
						30	*45				
							*50				
							40				

*W10-T25/30・W15-T45/50の場合は、A1・3のみ選択可能



Order
注文例

型式 - T - L - A
ICS15 - 20 - L120 - A5



Delivery
出荷日


5 日日出荷




ストック B



Example
使用例

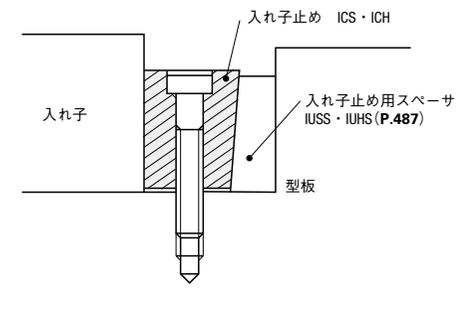

●入れ子止めを取りはずす場合

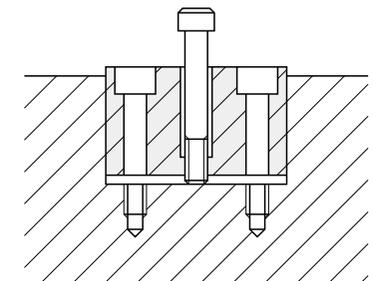

取りはずし用ボルト穴にボルトを入れます。ボルトを回すと入れ子止めが少しずつ型板から出てきます。

入れ子
フロントロッド