


CARBIDE BLOCK MATERIALS
超硬ブロック材

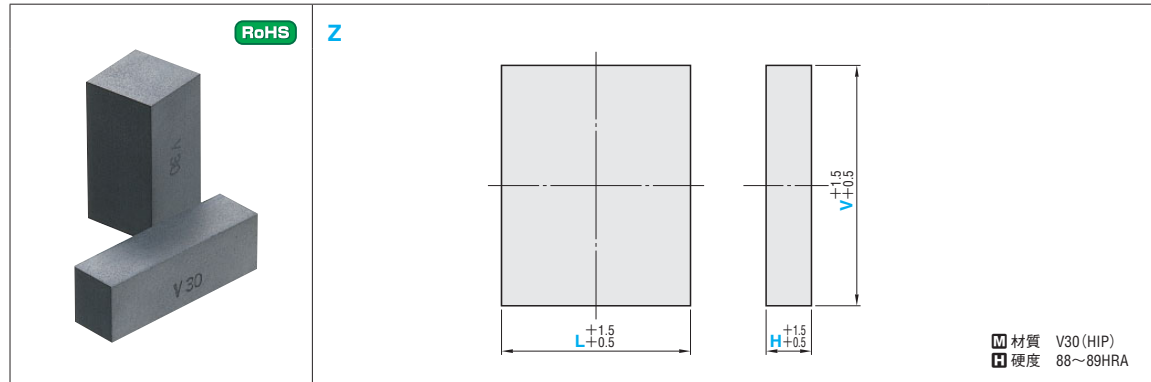


| 型式 | H | V | L | | | | | | | | | | |
|----|----|---|---|---|---|---|---|----|----|----|----|-----|----------------------|
| | | | 3 | 4 | 5 | 6 | 8 | 10 | 13 | 16 | 20 | 100 | |
| Z | 3 | ○ | ○ | ○ | ○ | ○ | ○ | ○ | ○ | ○ | ○ | ○ | 40 50 60 70 |
| | 4 | | ○ | ○ | ○ | ○ | ○ | ○ | ○ | ○ | ○ | ○ | |
| | 5 | | | ○ | ○ | ○ | ○ | ○ | ○ | ○ | ○ | ○ | |
| | 6 | | | | ○ | ○ | ○ | ○ | ○ | ○ | ○ | ○ | |
| | 8 | | | | | ○ | ○ | ○ | ○ | ○ | ○ | ○ | |
| | 10 | | | | | | ○ | ○ | ○ | ○ | ○ | ○ | |
| | 13 | | | | | | | ○ | ○ | ○ | ○ | ○ | |
| | 16 | | | | | | | | ○ | ○ | ○ | ○ | |
| | 20 | | | | | | | | | ○ | ○ | ○ | |
| | 22 | | | | | | | | | | ○ | ○ | |
| 25 | | | | | | | | | | | ○ | | |


Order 注文例
型式 V H - L
Z 20 08 - 70

Delivery 出荷日
在庫品 翌日出荷 P.37
ご希望によりPM5:00迄、当日出荷受付致します。

■超硬ブロック材 ミスミは、超硬ブロック材として焼結材を標準化。超硬型の短納期とコストダウンを実現します。

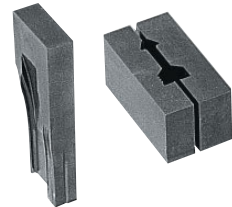

●V寸法20mm迄は標準化されたV・H寸法のままパンチ、ダイにご利用できます。

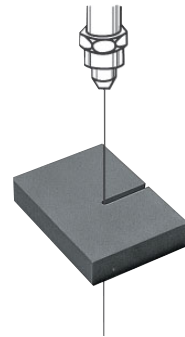

●V寸法100mmはワイヤカット切断用としてご利用ください。



■数量スライド価格 (1円単位切り捨て) P.37

| 数量 | 1~4 | 5~9 | 10~14 | 15~20 | 表示数量超えは |
|-----|------|-----|-------|-------|------------|
| 値引率 | 標準単価 | 5% | 10% | 15% | 価格・出荷日お見積り |

| 材質 | 型式 | V | H | ¥標準単価 1~4本 | | | |
|-----|--------|--------|--------|------------|--------|--------|--------|
| | | | | L | | | |
| | | | | 40 | 50 | 60 | 70 |
| V30 | Z | 3 | 3 | 380 | 380 | 380 | 470 |
| | | | 4 | 380 | 380 | 500 | 580 |
| | | 4 | 3 | 420 | 530 | 620 | 740 |
| | | | 4 | 410 | 500 | 600 | 720 |
| | | 5 | 3 | 530 | 620 | 740 | 880 |
| | | | 4 | 600 | 770 | 910 | 1,050 |
| | | | 5 | 470 | 580 | 720 | 830 |
| | | 6 | 3 | 600 | 740 | 880 | 1,020 |
| | | | 4 | 720 | 880 | 1,050 | 1,240 |
| | | | 5 | 830 | 1,050 | 1,240 | 1,430 |
| | | 8 | 3 | 570 | 720 | 860 | 980 |
| | | | 4 | 720 | 880 | 1,060 | 1,240 |
| | | | 5 | 860 | 1,060 | 1,260 | 1,500 |
| | | | 6 | 1,010 | 1,240 | 1,500 | 1,730 |
| | | 10 | 3 | 1,300 | 1,600 | 1,910 | 2,220 |
| | | | 4 | 670 | 850 | 1,000 | 1,180 |
| | | | 5 | 850 | 1,050 | 1,260 | 1,470 |
| | | | 6 | 1,020 | 1,280 | 1,500 | 1,750 |
| | | 13 | 3 | 1,180 | 1,470 | 1,750 | 2,040 |
| | | | 4 | 1,520 | 1,890 | 2,250 | 2,620 |
| | | | 5 | 1,850 | 2,320 | 2,780 | 3,220 |
| | | | 6 | 850 | 1,060 | 1,280 | 1,500 |
| | | 16 | 3 | 1,070 | 1,340 | 1,600 | 1,870 |
| | | | 4 | 1,300 | 1,600 | 1,930 | 2,220 |
| | | | 5 | 1,500 | 1,870 | 2,250 | 2,600 |
| | | | 6 | 1,950 | 2,390 | 2,860 | 3,340 |
| | | 20 | 3 | 2,370 | 2,940 | 3,510 | 4,100 |
| | | | 4 | 3,020 | 3,740 | 4,460 | 5,210 |
| | | | 5 | 1,210 | 1,490 | 1,790 | 2,060 |
| | | | 6 | 1,510 | 1,860 | 2,220 | 2,600 |
| | | 25 | 3 | 1,820 | 2,220 | 2,660 | 3,110 |
| | | | 4 | 2,100 | 2,600 | 3,110 | 3,650 |
| | | | 5 | 2,690 | 3,350 | 4,020 | 4,660 |
| | | | 6 | 3,300 | 4,110 | 4,900 | 5,710 |
| | | 100 | 3 | 4,200 | 5,220 | 6,240 | 7,270 |
| | | | 4 | 5,110 | 6,340 | 7,590 | 8,820 |
| | | | 5 | 6,300 | 7,830 | 9,380 | 10,920 |
| | | | 6 | 5,780 | 7,170 | 8,600 | 9,990 |
| | | | 7 | 7,220 | 8,970 | 10,730 | 12,500 |
| | | | 8 | 8,660 | 10,780 | 12,890 | 14,980 |
| 9 | 10,100 | | 12,560 | 15,020 | 17,490 | | |
| 10 | 12,980 | | 16,140 | 19,320 | 22,470 | | |
| 11 | 15,260 | | 19,010 | 22,740 | 24,610 | | |
| 12 | 19,460 | | 24,190 | 28,940 | 31,330 | | |
| 13 | 23,610 | 29,380 | 35,130 | 38,040 | | | |
| 14 | 29,160 | 36,290 | 43,400 | 46,980 | | | |
| 15 | 31,950 | 39,740 | 47,540 | 51,460 | | | |
| 16 | 36,110 | 44,920 | 53,730 | 58,180 | | | |

超硬ブロック材