



仕上げプレート

—標準タイプ・フリーサイズタイプ・エコノミータイプ—

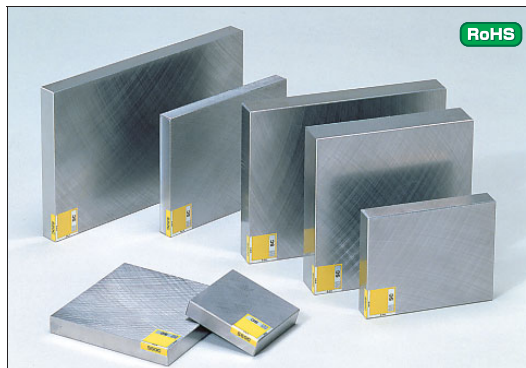

RoHS

SC (標準タイプ)
S-SC (フリーサイズタイプ)
E-SC (エコノミータイプ)

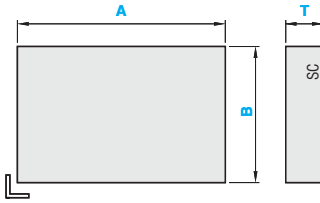

精度基準は P.1158

Type	寸法公差	
	A・B	T
標準タイプ フリーサイズ	99mm以下	+0.4 0
	100~250mm	+0.5 0
	251mm以上	+0.8 0
エコノミータイプ	99mm以下	+0.4 0
	100~250mm	+0.5 0
	251mm以上	+0.8 0

材質 S50C (生材)



Order
注文例

型式	A	B	T
SC	100	100	8
S-SC	380	200	30
E-SC	210	150	22



Delivery
出荷日

3 日目発送
ストックA 800円/1本 P.38
①同一サイズ3本以上は一律 2,160円



Price
価格

数量スライド価格 (①1円未満切り捨て) P.37
数量 1~9 10~30 表示数量超えは
値引率 基準単価 5% 価格・出荷日お見積り
価格計算式 A(寸法)×価格係数=基準単価
(ex) S-SC-300-200-30
300 × 25 = ¥7,500 (1円単位切り捨て)



Alterations
追加加工

詳細 P.1174 (B・T寸法も自由に変更できます。)
②フリーサイズタイプ・エコノミータイプは追加加工がご利用できます。

		¥基準単価 (標準タイプ)											
A	T	8	10	13	15	16	20	22	25	30	35	40	50
60	60	930	970	840	840	840	970						
80	60	1,020	1,020	880	880	880	1,060						
500	60	3,960	4,100	3,610	3,790	3,790	4,320						
80	80	1,020	1,100	930	930	930	1,100	1,150	1,280	1,500	1,850		
100	80	1,060	1,100	1,020	1,150	1,150	1,320	1,410	1,460	1,680	2,030		
125	80	1,150	1,190	1,100	1,190	1,190	1,370	1,460	1,500	1,760	2,200		
150	80	1,280	1,370	1,240	1,320	1,320	1,410	1,500	1,590	1,850	2,290		
160	80	1,320	1,410	1,280	1,410	1,410	1,460	1,540	1,630	1,940	2,380		
200	80	1,590	1,680	1,460	1,590	1,590	1,720	1,940	2,120	2,380	2,820		
250	80	2,030	2,160	1,940	2,030	2,030	2,290	2,420	2,560	2,820	3,260		
500	80	4,010	4,180	3,700	3,880	3,880	4,360	4,620	4,980	5,460	6,250		
100	100	1,150	1,190	1,100	1,190	1,190	1,320	1,370	1,500	1,760	1,940	2,040	2,390
125	100	1,280	1,320	1,150	1,240	1,240	1,370	1,410	1,540	1,850	2,290	2,420	2,840
150	100	1,370	1,410	1,240	1,320	1,320	1,410	1,500	1,590	1,900	2,340	2,830	3,320
160	100	1,500	1,540	1,370	1,460	1,460	1,540	1,630	1,720	2,030	2,470	2,970	3,470
180	100	1,590	1,680	1,460	1,540	1,540	1,630	1,720	1,900	2,200	2,640	3,300	3,860
200	100	1,680	1,760	1,590	1,680	1,680	1,850	1,980	2,070	2,380	2,820	3,620	4,240
210	100	1,760	1,850	1,630	1,760	1,760	1,940	2,070	2,380	2,730	3,300	3,760	4,390
250	100	2,160	2,290	2,030	2,160	2,160	2,420	2,510	2,640	3,000	3,570	4,380	5,130
300	100	2,510	2,640	2,290	2,560	2,560	2,690	3,000	3,080	3,480	4,050	4,780	5,920
350	100	2,950	3,130	2,690	2,950	2,950	3,300	3,440	3,740	4,180	4,840	5,590	6,820
400	100	3,390	3,610	3,080	3,350	3,350	3,700	3,920	4,140	4,580	5,240	5,940	7,100
450	100	3,830	4,100	3,520	3,740	3,740	4,180	4,400	4,760	5,240	5,940	6,510	7,950
500	100	4,230	4,450	3,880	4,100	4,100	4,620	4,800	5,240	5,770	6,520	7,420	8,810
125	125	1,370	1,410	1,280	1,370	1,370	1,410	1,500	1,590	1,980	2,470	3,040	4,010
150	125	1,460	1,680	1,320	1,410	1,410	1,590	1,680	1,760	2,160	2,640	3,220	4,180
160	125	1,590	1,810	1,460	1,540	1,540	1,680	1,760	1,940	2,340	2,820	3,390	4,360
180	125	1,630	1,850	1,500	1,590	1,590	1,720	1,810	1,980	2,420	2,910	3,480	4,450
200	125	1,760	1,900	1,680	1,810	1,810	1,900	2,030	2,250	2,690	3,220	3,830	4,890
210	125	1,850	1,940	1,720	1,900	1,900	2,030	2,200	2,380	2,820	3,350	3,960	5,020
250	125	2,290	2,380	2,120	2,200	2,200	2,380	2,470	2,640	3,130	3,700	4,360	5,500
300	125	2,640	2,730	2,380	2,640	2,640	2,780	3,040	3,170	3,660	4,230	4,890	6,030
350	125	3,130	3,220	2,860	3,130	3,130	3,350	3,520	3,830	4,360	4,980	5,680	6,910
400	125	3,610	3,700	3,350	3,520	3,520	3,790	4,050	4,230	4,760	5,370	6,080	7,310
450	125	4,100	4,180	3,830	4,010	4,010	4,230	4,540	4,800	5,370	6,030	6,780	8,100
500	125	4,580	4,670	4,180	4,450	4,450	4,670	5,020	5,460	6,080	6,780	7,570	8,980

		¥基準単価 (標準タイプ)											
A	T	8	10	13	15	16	20	22	25	30	35	40	50
150	150	1,900	1,940	1,720	1,810	1,810	1,980	2,070	2,200	2,470	3,040	3,780	4,890
180	150	2,160	2,200	1,980	2,120	2,120	2,380	2,560	2,730	3,170	3,740	4,150	4,990
200	150	2,290	2,380	2,160	2,290	2,290	2,600	2,820	3,040	3,520	4,140	4,520	5,290
210	150	2,420	2,510	2,290	2,420	2,420	2,690	2,910	3,130	3,660	4,270	4,920	5,780
250	150	2,910	3,040	2,730	2,950	2,950	3,000	3,170	3,350	3,960	4,620	5,760	6,520
300	150	3,480	3,610	3,220	3,440	3,440	3,520	3,660	3,960	4,670	5,330	6,270	7,380
350	150	4,050	4,180	3,700	3,920	3,920	4,010	4,180	4,490	5,330	6,030	6,790	8,260
400	150	4,710	4,840	4,270	4,490	4,490	4,580	4,800	5,150	6,120	6,820	7,410	8,810
450	150	5,240	5,420	4,760	4,980	4,980	5,110	5,330	5,770	6,820	7,570	8,230	9,750
500	150	5,460	5,810	5,110	5,420	5,420	5,590	5,860	6,300	7,530	8,320	9,080	10,730
160	160	1,810	1,850	1,630	1,720	1,720	1,900	1,980	2,120	2,380	2,950	3,610	4,760
200	160	2,030	2,120	1,900	2,030	2,030	2,340	2,560	2,780	3,260	3,890	4,230	5,020
250	160	2,560	2,690	2,380	2,600	2,600	2,820	3,000	3,160	3,740	4,270	5,020	5,990
300	160	3,130	3,260	2,860	3,080	3,080	3,170	3,300	3,610	4,320	4,980	5,720	7,040
350	160	3,700	3,830	3,350	3,570	3,570	3,660	3,830	4,140	4,980	5,680	6,470	7,880
400	160	4,270	4,400	3,830	4,050	4,050	4,140	4,360	4,710	5,680	6,380	7,180	8,580
450	160	4,800	4,980	4,320	4,540	4,540	4,670	4,890	5,330	6,380	7,130	7,970	9,460
500	160	5,020	5,370	4,670	4,980	4,980	5,150	5,420	5,860	7,090	7,880	8,760	10,340
200	200	2,640	2,780	2,510	2,690	2,690	2,910	3,040	3,260	3,700	4,050	4,400	5,200
250	200	3,170	3,350	3,000	3,170	3,170	3,440	3,610	3,920	4,360	4,840	5,370	6,300
300	200	3,610	3,830	3,440	3,700	3,700	4,010	4,230	4,540	5,280	5,680	6,250	7,400
350	200	4,140	4,400	3,920	4,230	4,230	4,580	4,800	5,200	6,170	6,520	7,180	8,450
400	200	4,670	4,980	4,400	4,980	4,980	5,420	5,720	6,160	7,180	7,620	8,360	10,170
450	200	5,200	5,590	4,980	5,680	5,680	6,030	6,520	6,740	7,790	8,360	9,600	11,180
500	200	5,680	6,120	5,330	5,770	5,770	6,300	6,870	7,350	8,410	9,240	10,700	12,150
250	250	4,230	4,540	4,010	4,580	4,580	4,840	5,280	5,590	6,440	6,990	7,760	9,200
300	250	4,930	5,060	4,710	4,930	4,930	5,420	5,720	6,210	7,180	7,660	8,400	10,000
350	250	5,500	5,720	5,240	5,500	5,500	6,120	6,470	7,000	7,970	8,400	9,200	10,700
400	250	6,080	6,380	5,770	6,340	6,340	7,090	7,530	8,100	8,320	9,240	10,520	12,280
450	250	6,650	7,040	6,300	7,040	7,040	8,140	8,580	9,240	9,730	10,390	11,530	13,600
500	250	7,090	7,530	6,780	7,480	7,480	8,410	8,890	9,600	10,300	11,140	12,720	14,300
300	300	4,890	5,200	4,710	5,420	5,420	6,380	6,740	7,260	7,840	8,230	9,360	10,750
350	300	5,640	5,940	5,420	6,210	6,210	7,180	7,570	8,230	9,290	10,040	11,540	13,170
400	300	6,380	6,690	6,120	7,130	7,130	8,140	8,630	9,330	10,520	11,180	12,720	14,500
450	300	7,130	7,440	6,820	7,840	7,840	8,980	9,510	10,300	11,800	12,410	14,280	16,290
500	300	7,700	8,100	7,480	8,010	8,010	9,240	9,950	10,830	12,590	13,640	15,280	17,580

		価格計算式 (A×価格係数)											
A	T	8	10	13	15	16	20	22	25	30	35	40	50
30~60	60	Ax18	Ax19	Ax15	Ax17	Ax17	Ax19						
61~80	60	Ax17	Ax18	Ax14	Ax16	Ax16	Ax18						
81~100	60	Ax17	Ax18	Ax14	Ax16	Ax16	Ax18						
101~200	60	A											