



# 曲げ・面打ちパンチ&ダイ

ー外形固定タイプー

追加工価格も数量スライド適用 P.43

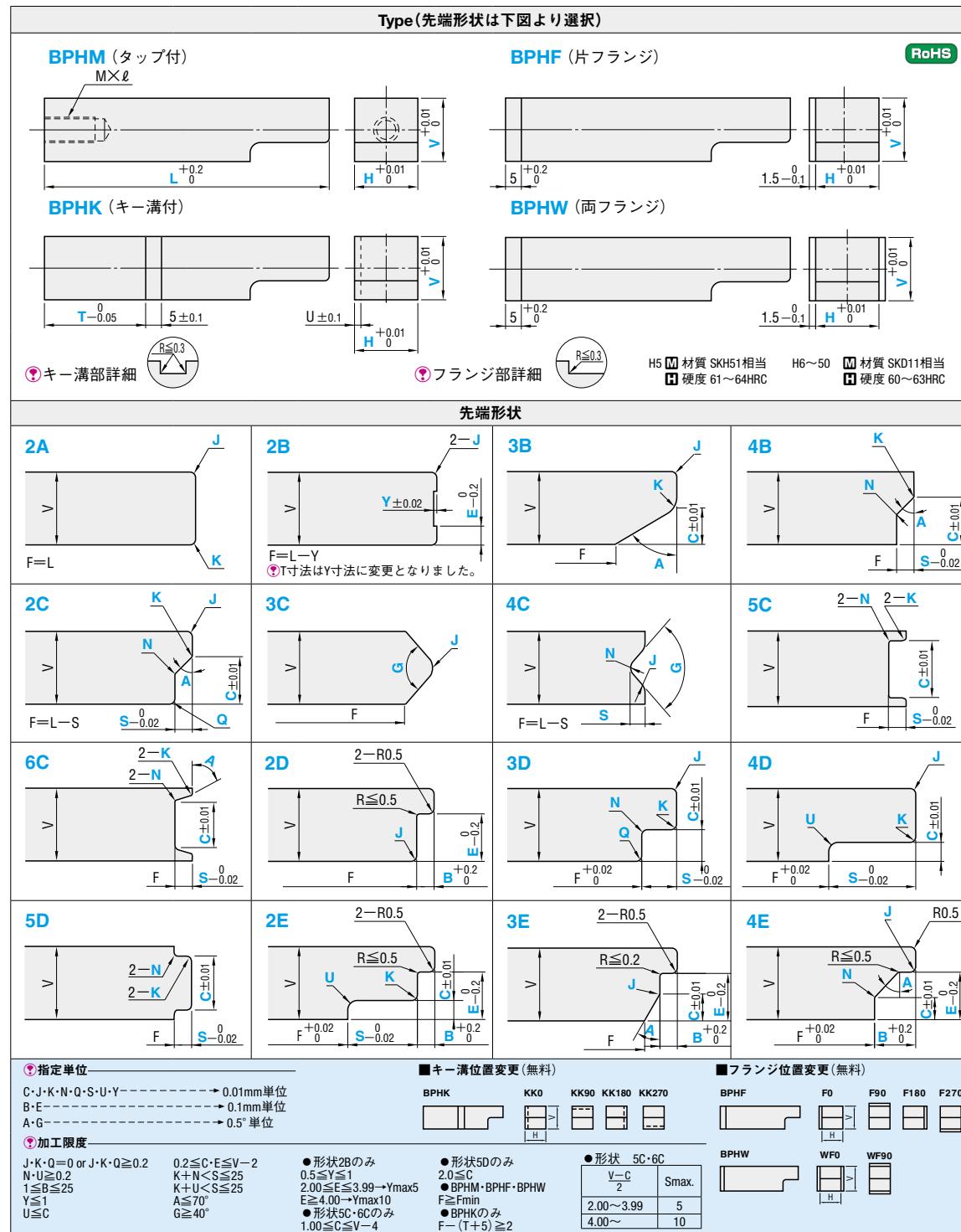

Example 使用例

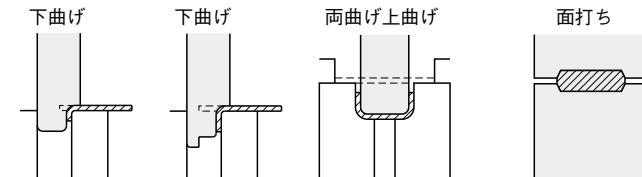

Type	Shape形状	型式										指定0.1mm単位					F min.	U
		V	5	6	8	10	13	16	20	22	25	28	30	40	50	L	T	
タップ付	BPHM	2A	5	◇	◇	◇	◇	◇	◇	◇	◇	◇	◇	◇	◇	15	1.0	
		2B	6	◇	○	○	○	○	○	○	○	○	○	○	○	20		
		3B	8	◇	○	△	△	△	△	△	△	△	△	△	△			
		4B	10	◇	○	△	□	□	□	□	□	□	□	□	□			
キー溝付	BPHK	13	◇	○	△	□	●	●	●	●	●	●	●	●	●			
		16	◇	○	△	□	●	●	●	●	●	●	●	●	●			
		20	◇	○	△	□	●	●	●	●	●	●	●	●	●			
		22	◇	○	△	□	●	●	●	●	●	●	●	●	●			
		25	◇	○	△	□	●	●	●	●	●	●	●	●	●			
		28	◇	○	△	□	●	●	●	●	●	●	●	●	●			
		30	◇	○	△	□	●	●	●	●	●	●	●	●	●			
		40	◇	○	△	□	●	●	●	●	●	●	●	●	●			
		50	◇	○	△	□	●	●	●	●	●	●	●	●	●			
片フランジ	BPHF	2C 3C 4C 5C 6C	20.0 ~ 100.0										タップ付(BPHK)のみ					1.5
		2D 3D 4D 5D	T≥20 (H5~H8 H10 H13~H50)										タップ付(BPHK)のみ					25
両フランジ	BPHW	2E 3E 4E	L20.0~ L24.0~ L28.0~										タップ付(BPHK)のみ					

④タップ付BPHMはLmin.がH寸法によって異なりますのでご注意ください。ただしH>Vの場合は、V寸法が適用されます。  
⑤キー溝付BPHKでキー溝不要の場合、T寸法指示は全長Lと同じ寸法でご指定ください。T=L

⑥V-H=40~50~2-M  
V-H 40 50  
l1 20 24

⑦表中の印とタップM×ℓの関係  
◇: M3×6 ○: M4×8 ●: M8×16 △: M5×10

Order 注文例

タップ付	型式	V	H	-	L	-	B·C·E·J·K·N·Q·S·Y·U·A·G
	BPHM 2A	06	06	-	60.5	-	J3.00 - K2.00

キー溝付	型式	V	H	-	L	-	T	-	B·C·E·J·K·N·Q·S·Y·U·A·G	-	KK
	BPHK 2B	08	16	-	60.5	-	T23.5	-	E2.0-J1.50-Y0.5	-	KKO

フランジ付	型式	V	H	-	L	-	B·C·E·J·K·N·Q·S·Y·U·A·G	-	F·WF
	BPHF 2B	08	16	-	60.5	-	E2.0-J1.50-Y0.5	-	F0
	BPHW 3D	16	13	-	72.3	-	C6.00-J0.50-K0.5-N1.30-Q0.50-S19.27	-	WF90

Delivery 出荷日

5	日目出荷
---	------

Alterations 追加工

型式	V	H	-	L	-	B·C·E·J·K·N·Q·S·Y·U·A·G	-	F·WF	-	(HC-TC...etc.)
BPHF 2A	06	06	-	60.5	-	J3.00-K2.00	-	F0	-	HC1.0-TKC

Alterations	Code	Spec.	¥/1Code
	HC	フランジ幅変更 指定0.1mm単位	200
	TC	フランジ厚変更 指定0.1mm単位	200
	TKC	キー溝位置 公差変更 T-0.05 → -0.02	200
		フランジ厚公差 5+0.2 → +0.02 変更	200

Alterations	Code	Spec.	¥/1Code
LKC		全長公差変更 L+0.2 → +0.02 3E-4E適用不可	800
MC	M	タップ径変更 H 6 8 10 13 16 20 22 25 30 M4 → M3 M5 → M4 M6 → M5 M8 → M6	0
RTC		キー溝位置 公差変更 T-0.05 → +0.05	0

Price 価格

数量区分	標準対応					個別対応 大口
数量	1~9	10~29	30~49	50~100	101~	お見積り
基準単価	5%	5%	10%	15%	101~	

⑧表示数量超えはWOSにてご確認ください。

■H>Vの場合

Type	形状	¥ 基準単価	1~9本
BPHM	A	4,040	4,360 8,050 8,990 9,930
	B	4,440	4,800 8,870 9,890 10,910
	C	5,250	5,650 10,020 11,190 12,350
	D	5,760	6,210 11,020 12,320 13,580
	E	6,080	6,560 11,410 12,730 14,030
BPHK	A	6,380	7,220 12,550 14,000 15,440
	B	7,010	7,940 13,800 15,410 17,000
	C	7,370	8,330 14,490 16,160 17,840
	D	7,750	8,710 9,720 10,740 11,830
	E	5,580	6,050 10,850 12,150 13,410
BPHF	A	6,160	6,660 11,960 13,360 14,780
	B	6,840	7,730 13,630 15,240 16,830
	C	7,550	8,510 15,020 16,780 18,530
	D	7,920	8,950 15,780 17,630 19,470
	E	8,440	9,400 10,870 11,420 12,910
BPHW	A	4,880	5,270 9,760 12,690 12,000
	B	5,750	6,210 11,020 12,340 13,580
	C	6,330	6,830 12,130 15,780 14,940
	D	7,010	7,900 13,800 17,950 17,000
	E	8,090	9,120 15,950 20,740 19,640