


BALL-LOCK RETAINERS -LIGHT LOAD-
ボールロックリテナー
-ライト級・トライアングルタイプ-

2日目納短縮

P.804の注意事項をご確認ください。

適用	型式	①	②	③	④	⑤	⑥	⑦	D
パンチ用	CRN-P	○	○	○	○	○	○	○	10~32
ダイ用	CRN-D	○	○	○	○	○	○	○	13~38
パンチ用本体 +プラグ	CRN-PP	○	○						10~32
ダイ用本体 +プラグ	CRN-DN	○	○						13~38

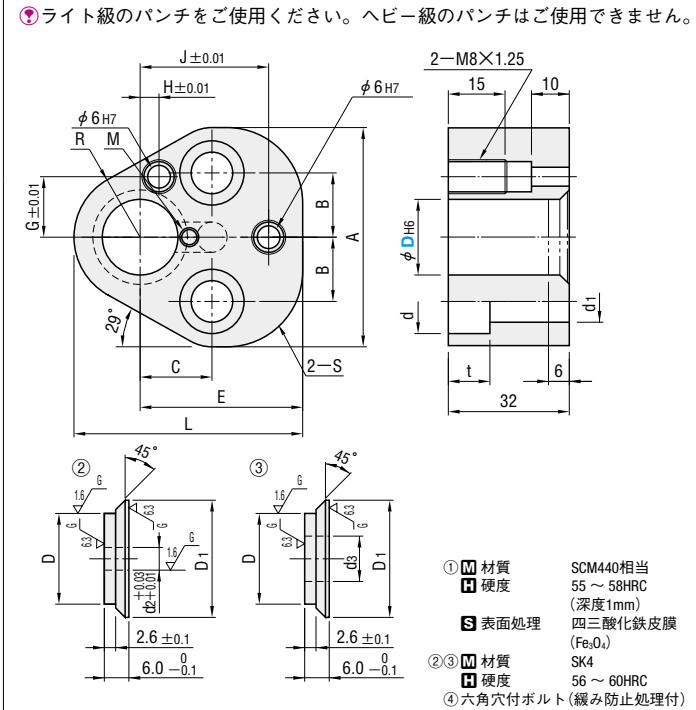

型式		D	D _{H6}	A	B	C	E	G	H	J	L	R	S	D ₁	d	d ₁	t	d ₂	d ₃	M	A 付属品		
Type		D																					
(パンチ用)	①②④⑤⑥⑦	(10)	+0.009 0	43.7	11.12	19.05	35.0	9.0	7.5	26.925	44.5	9.5	12.0	16	6	4	④M8-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-40 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20	—	—	—	—	—	—
		13	+0.011 0	50.0	14.27		38.1	12.0	6.5	29.970	50.8	12.7	15.2	19				6.2	④M8-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-40 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				
		16	+0.011 0	53.2	15.87		39.7	13.5	6.0	31.750	54.0	14.3	16.8	22				9	④M8-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-40 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				
		20	+0.013 0	59.5	17.47		42.8	16.5	5.0	33.530	60.3	17.5	20.0	26				12	④M8-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-40 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				
		25	+0.013 0	69.1	19.84		47.7	22.0	7.0	40.640	69.9	22.2	24.7	31				17	④M8-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-40 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				
		32	+0.016 0	69.1	19.84		47.7	22.0	7.0	40.640	69.9	22.2	24.7	38				21	④M8-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-40 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				
		(38)	+0.016 0	76.6	24.00	27.00	51.4	26.0	10.0	43.993	77.4	26.0	28.5	44				—	④M8-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-40 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-40 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				

D10はパンチ用のみ適用、D38はダイ用のみ適用。

Order
注文例
CRN-P 16

Delivery
出荷日
2 日目出荷
ストーク A 翌日出荷 200円/1本 PM 6:00迄 P40

③本以上で1明細行当たり一律540円

■数量スライド価格 (③円未満切り捨て) P39
数量区分 標準対応 個別対応 大口
数量 1~9セット 10~29セット 30~49セット 50~100セット 101セット~
値引率 基準単価 5% 10% 15% お見積り

③表示数量超えはWOSにてご確認ください。

■基準単価


D	CRN-P	CRN-PP	CRN-D	CRN-DN
10	2,900	2,790	—	—
13	2,900	2,790	2,900	2,790
16	3,050	2,930	3,050	2,930
20	3,280	3,160	3,280	3,160
25	3,640	3,520	3,640	3,520
32	4,320	4,180	4,320	4,180
38	—	—	4,320	4,180

BALL-LOCK RETAINERS -HEAVY LOAD-
ボールロックリテナー
-ヘビー級・トライアングルタイプ-

2日目納短縮

P.804の注意事項をご確認ください。

適用	型式	①	②	③	④	⑤	⑥	⑦	D
パンチ用	BRN-P	○	○	○	○	○	○	○	10~32
BRN-PN	○	○	○	○	○	○	○	○	10~32
BRN-PP	○	○							10~32

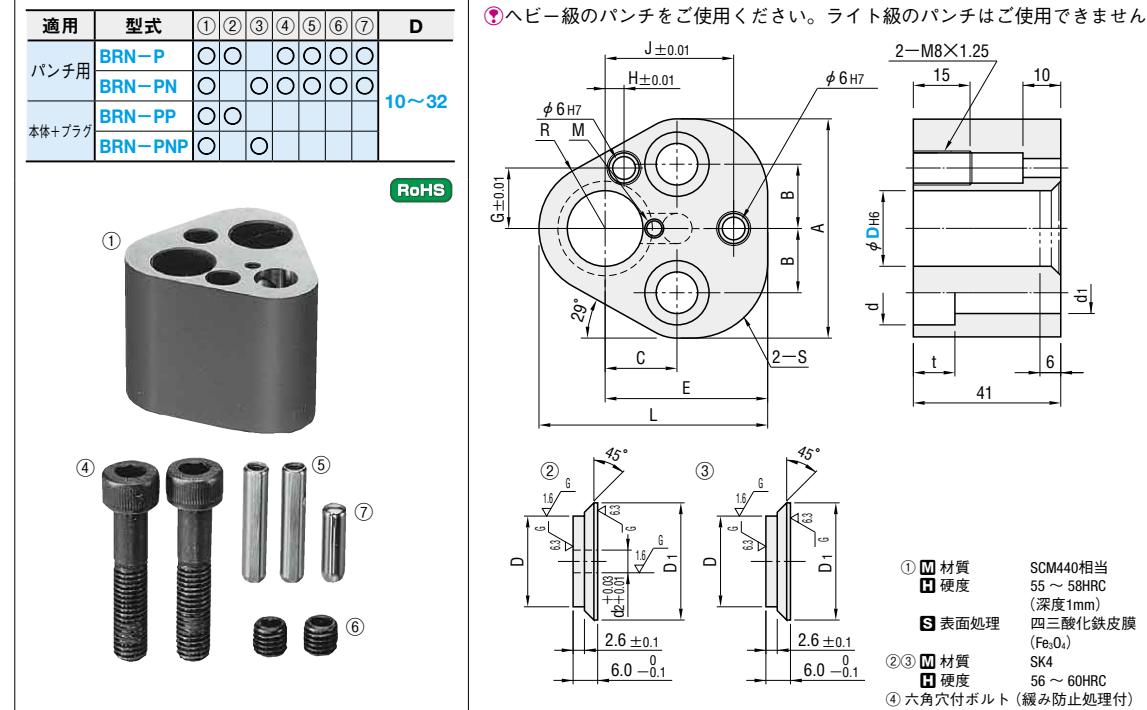

型式		D	D _{H6}	A	B	C	E	G	H	J	L	R	S	D ₁	d	d ₁	t	d ₂	d ₃	M	A 付属品		
Type		D																					
(パンチ用)	①②④⑤⑥⑦	(10)	+0.009 0	43.7	11.12	19.05	35.0	9.0	7.5	26.925	44.5	9.5	12.0	16	6	4	④M8-45 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-50 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-50 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20	—	—	—	—	—	—
		13	+0.011 0	50.0	14.27		38.1	12.0	6.5	29.970	50.8	12.7	15.2	19				6.2	④M8-45 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-50 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-50 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				
		16	+0.011 0	53.2	15.87		39.7	13.5	6.0	31.750	54.0	14.3	16.8	22				9	④M8-45 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-50 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-50 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				
		20	+0.013 0	59.5	17.47		42.8	16.5	5.0	33.530	60.3	17.5	20.0	26				12	④M8-45 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-50 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-50 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				
		25	+0.013 0	69.1	19.84		47.7	22.0	7.0	40.640	69.9	22.2	24.7	31				17	④M8-45 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-50 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-50 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				
		32	+0.016 0	69.1	19.84		47.7	22.0	7.0	40.640	69.9	22.2	24.7	38				21	④M8-45 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20 ④M10-50 ⑥MSW8 ⑤MSTM6-30 ⑦MS6-20 ④M12-50 ⑤MSTM6-30 ⑥MSW8 ⑦MS6-20				
		(38)	+0.016 0	76.6	24.00	27.00	51.4	26.0	10.0	43.993	77.4	26.0	28.5	44				—	④M8-45 ⑤MSTM6-30 ⑥MSW				