




追加工価格も数量スライド適用 P.43

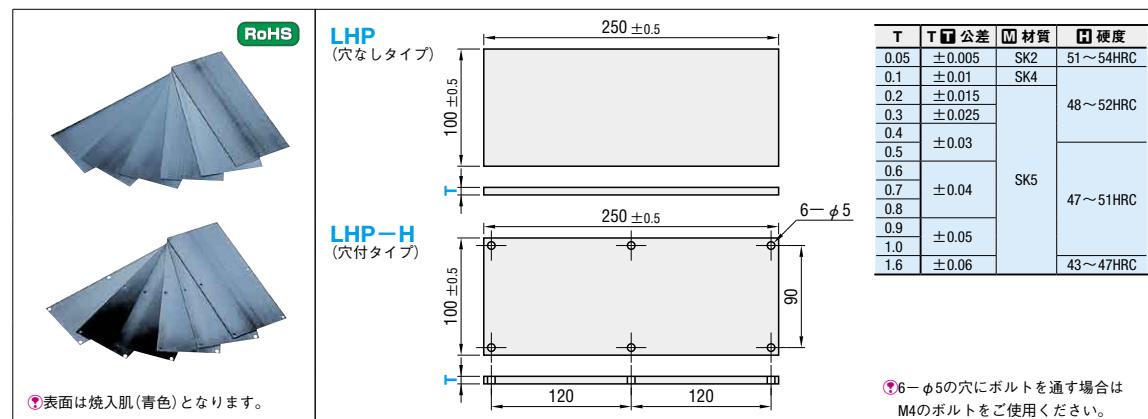



型式		LHP			LHP-H			型式	
Type	T(厚み)	1~4枚	5~19	20~50	1~4枚	5~19	20~50	LHP 0.7	LHP-H 1.0
LHP (穴なしタイプ)	0.05	1,100	1,000	950	1,500	1,450	1,377	 Order 注文例	LHP 0.7 LHP-H 1.0
	0.1	650	550	522	1,050	1,000	950		
	0.2	600	400	380	1,000	850	807	 Delivery 出荷日	2 日目出荷
	0.3	600	400	380	1,000	850	807		
	0.4	600	400	380	1,000	850	807		
	0.5	600	400	380	1,000	850	807	 Stock ストーク A	翌日出荷 500円/1本 PM 6:00迄 P40
	0.6	600	400	380	1,000	850	807		
	0.7	650	450	427	1,050	900	855	 Price 価格	④3本以上で1明細行当たり一律1,350円
	0.8	700	500	475	1,100	950	902		
	0.9	750	550	522	1,150	1,000	950		
LHP-H (穴付タイプ)	1.0	750	550	522	1,150	1,000	950	 Price 価格	⑤表示数量超えは WOSにてご確認ください。
	1.6	1,100	1,000	950	1,500	1,450	1,377		

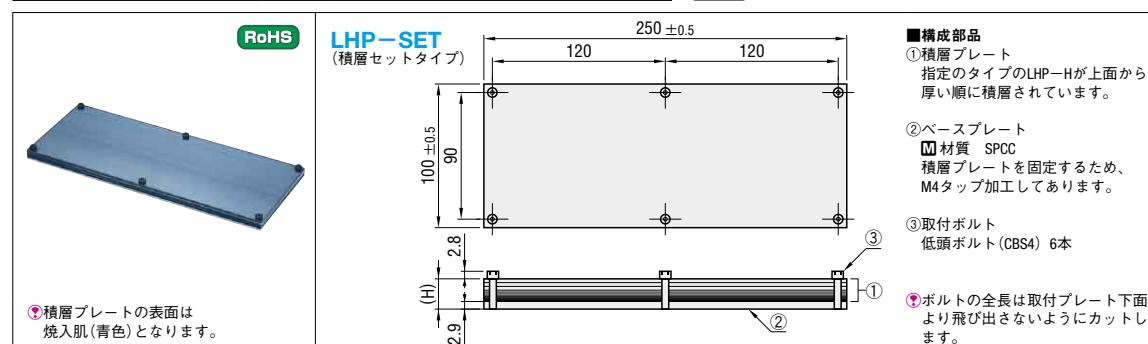

(H)	型式	①積層プレート厚みTの組合せ内容												￥基準単価 1~9セット	Order 注文例	型式 LHP-SET10
		0.05	0.1	0.2	0.3	0.4	0.5	0.6	0.7	0.8	0.9	1.0	1.6			
4.4	LHP-SET5	—	○	○	○	○	○	—	—	—	—	—	—	5,550		
8.4	LHP-SET10	—	○	○	○	○	○	○	○	○	○	○	—	8,000		
10.1	LHP-SET12	○	○	○	○	○	○	○	○	○	○	○	○	10,000		

 

Alteration	Code	T(厚み)	Spec.	¥/1Code
	PPA	0.05	指定のLHP-Hを追加して積層させます。	1,000
	PPB	0.6		400
	PPC	0.7	①LHP-SET5…PPA～PPG指定可 LHP-SET10…PPA～PPGのみ指定可	450
	PPD	0.8	②LHP-SET12…適用不可	500
	PPE	0.9	③複数指定は可能ですが、同じプレートを2枚以上追加できません。	550
	PPF	1.0		550
	PPG	1.6		1,000

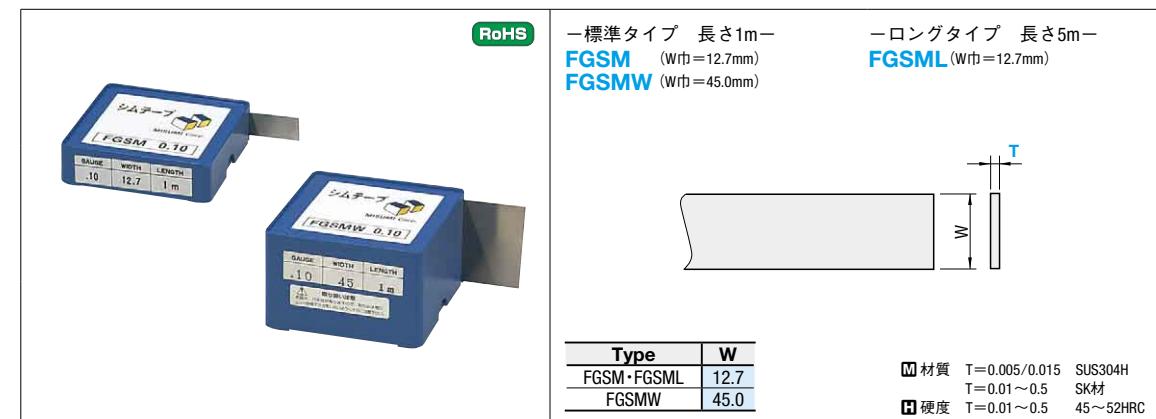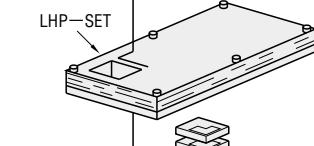

■標準タイプ(長さ1m)					■ロングタイプ(長さ5m)						
長さ	型式		公差	¥基準単価 1~5本		長さ	型式		公差	¥基準単価	
	Type	T(厚み)		FGSM	FGSMW		Type	T(厚み)		1~5本	
1m	FGSM (W=12.7mm)	0.005	±0.0005	3,970	9,480	5m FGSML (W=12.7mm)	0.005	±0.0005	20,800		
		0.01		1,550	6,050		0.01		5,800		
		0.015	±0.003	2,170	7,580		0.015	±0.003	10,500		
		0.02		1,270	4,830		0.02		4,130		
		0.03		1,170	4,430		0.03		4,000		
		0.04		1,080	3,830		0.04		2,980		
		0.05		1,080	3,630		0.05		2,980		
		0.06		1,040	3,230		0.06		2,980		
		0.07	±0.005	1,040	3,230		0.07	±0.005	2,780		
		0.08		1,040	3,030		0.08		2,780		
1m	FGSMW (W=45.0mm)	0.09		1,040	3,030		0.09		2,780		
		0.1		1,000	2,620		0.1		2,600		
		0.15		1,000	2,230		0.15		2,600		
		0.2		1,000	2,230		0.2	±0.015	2,600		
		0.25		1,000	2,230		②ロングタイプは約1m分お得罪です。				
		0.3		1,000	2,420						
		0.35		1,140	2,420						
		0.4		1,140	2,820						
		0.45		1,140	2,820						
		0.5		1,140	2,820						

