



L	型式	A ローラ個数	¥基準単価 1~9本
(105)	CORO	3	790
(140)		4	1,040
(175)		5	1,300
(210)		6	1,570
(245)		7	1,830
(280)		8	2,100
(315)		9	2,350
(350)		10	2,620
(385)		11	2,870
(420)		12	3,120
(455)		13	3,390
(490)		14	3,650
(525)		15	3,920

L	型式	A ローラ個数	¥基準単価 1~9本
(560)	CORO	16	4,180
(595)		17	4,430
(630)		18	4,690
(665)		19	4,960
(700)		20	5,220
(735)		21	5,490
(770)		22	5,740
(805)		23	6,010
(840)		24	6,260
(875)		25	6,510
(910)		26	6,780
(945)		27	7,040
(980)		28	7,310

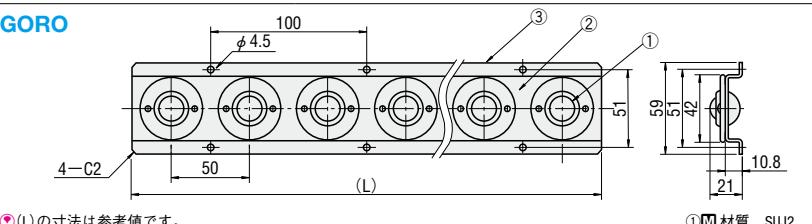


L	型式	A ボール個数	¥基準単価 1~9本
(200)	GORO	4	2,900
(300)		6	4,350
(400)		8	5,650
(500)		10	6,950
(600)		12	8,250
(700)		14	9,550
(800)		16	10,850
(900)		18	12,150
(1000)		20	13,450
(1100)		22	14,750
(1200)		24	16,050

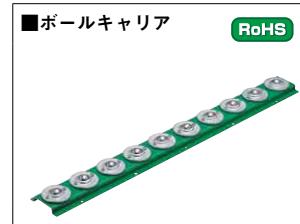


数量スライド価格 (1円未満切り捨て) P39				
数量区分	標準対応	個別対応	大口	
数量	1~9	10~19	20~29	30~50
値引率	基準単価	5%	10%	15%



表示数量超えはWOSにてご確認ください。

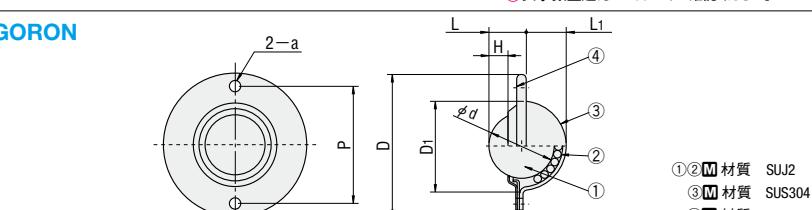


型式	D	D ₁	L	L ₁	H	P	a	d	耐荷重 N(kgf)	自重(g)	¥基準単価 1~9口
GORON	41.3	24	10.2	(9.1)	4	30	3.5	15.875	78.4(8)	45	410

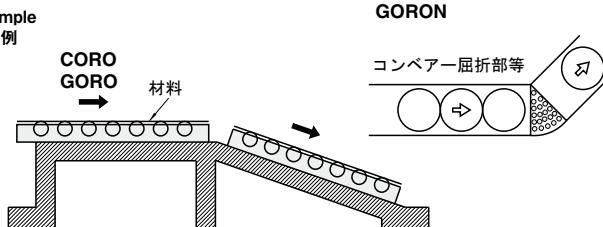

■表面形状

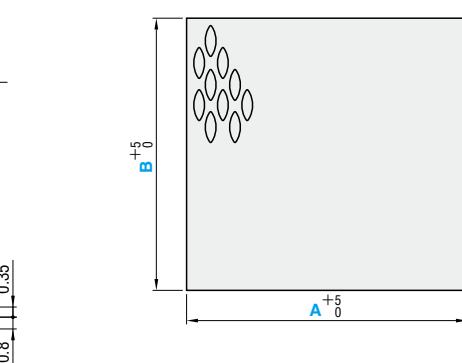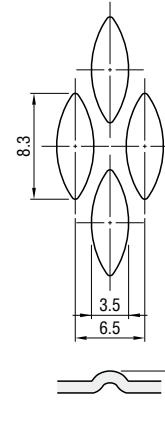

型式	A	B	¥基準単価
EBSP	500	1000	4,700
	1000		8,000
	2000		15,000

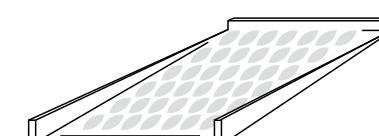

必要寸法にカット後、スクラップシュータ等に溶接等で取付けてください。

■特長



(1) スクラップとの接触面積が少ないため、角度のとれない(12°まで有効)スクラップシュータ等に効果を発揮します。

(2) 潤滑油等における吸着を防ぎます。