



d	型式		型式		¥ 基準単価 1 ~ 19本
	Type	D-L	Type	D-L	
—	—	—	C	8-200	280
—	—	—	C	10-200	280
7	LA	15-200	C	15-200	280
8.5	LA	20-200	C	20-200	410
11	LA	25-200	C	25-200	660
14	LA	30-500	C	30-500	2,350
	LA	40-500	C	40-500	4,200
	LA	50-500	C	50-500	6,440
	LA	60-500	C	60-500	9,300
22	LA	80-500	C	80-500	15,620
	LA	100-500	C	100-500	24,370

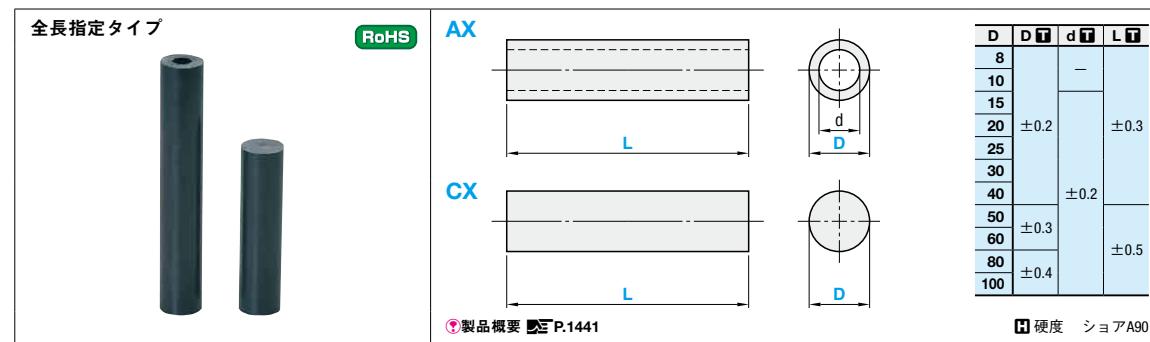

d	型式	D	L 指定1mm単位	¥基準単価 1~19本						
				L10~20	L21~40	L41~60	L61~80	L81~100	L101~150	L151~
—	CX	8		90	95	110	145	180	270	350
—		10		90	95	110	145	180	270	350
7	AX	15		90	90	100	140	180	275	360
8.5		20		90	95	130	190	245	370	490
11	CX	25		130	150	195	275	330	490	650
14		30		160	205	300	385	480	720	950
	CX	40		215	360	540	720	900	1,355	1,800
		50		360	635	900	1,175	1,440	2,165	2,880
	CX	60		540	900	1,260	1,620	1,985	2,980	3,970
22		80		860	1,490	2,165	2,885	3,610	5,415	7,220

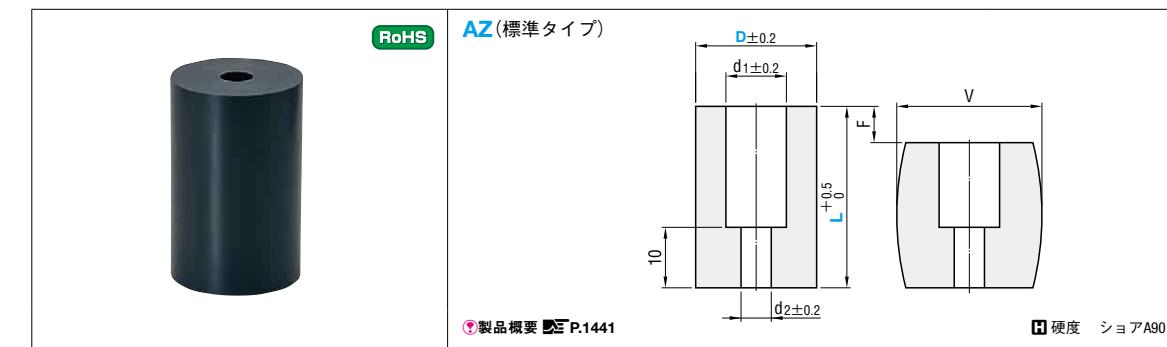

F=L×10%		F=L×15%		F=L×20%		D	d1	d2	M	L	型式		基準単価 1~19本
F mm	荷重 N(kgf)	F mm	荷重 N(kgf)	F mm	荷重 N(kgf)						Type	D-L	
2.5		3.7		5.0						25	AZ 20-	25	
3.0	883	4.5	1079	6.0	1275	24	20	11	7	30		30	
3.5	{90}	5.2	{110}	7.0	{130}					35		35	285
4.0		6.0		8.0						40		40	
2.5		3.7		5.0						25	AZ 25-	25	
3.0	1177	4.5	1569	6.0	1765	29	25	11	7	30		30	
3.5	{120}	5.2	{160}	7.0	{180}					35		35	380
4.0		6.0		8.0						40		40	
3.0	2550	4.5	3040	6.0	3530	35	30	14	9	30	AZ 30-	30	
3.5	{260}	5.2	{310}	7.0	{360}					35		35	570
4.0		6.0		8.0						40		40	
3.0	4119	4.5	5099	6.0	5884	46	40	18	11	M10	AZ 40-	30	
3.5	{420}	5.2	{520}	7.0	{600}					35		35	710
4.0		6.0		8.0						40		40	

