




EST・ESBT		D1	d	t	W	型式		L	Color 保安色	￥基準単価
D	L1					Type	D			1～9本
40	80	60.5	52.9	3.8	91	PH	40	60	R (Red)	980
50	110	89.1	80.7	4.2	119		50	85		1,230
70	140	101.6	93.2	4.2	132		70	90・100		1,300
90	140	139.8	130.8	4.5	170		90	110		1,340
100	140	165.2	155.2	5	195		90	90・100	Y (Yellow)	1,500
							100	110		1,540
							100	90・100		1,810
							100	110		1,900

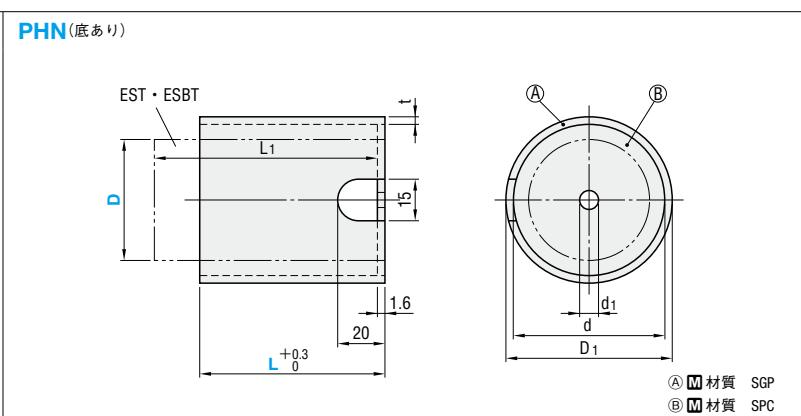

EST・ESBT		D1	d	d1	t	型式		L	Color 保安色	￥基準単価 1～9本
D	L1					Type	No.			
40	80	60.5	52.9	13	3.8	PHN	40	60	R (Red)	1,200
50	110	89.1	80.7		4.2		50	85		1,390
70	110	101.6	93.2		4.2		70	85		1,520
70	140	101.6	93.2		4.2		70	110		1,580
70	140	101.6	93.2		4.2		7022	110	Y (Yellow)	1,620
90	140	139.8	130.8		4.5		90	110		1,800
100	140	152.5	142.5		5		100	110		2,010

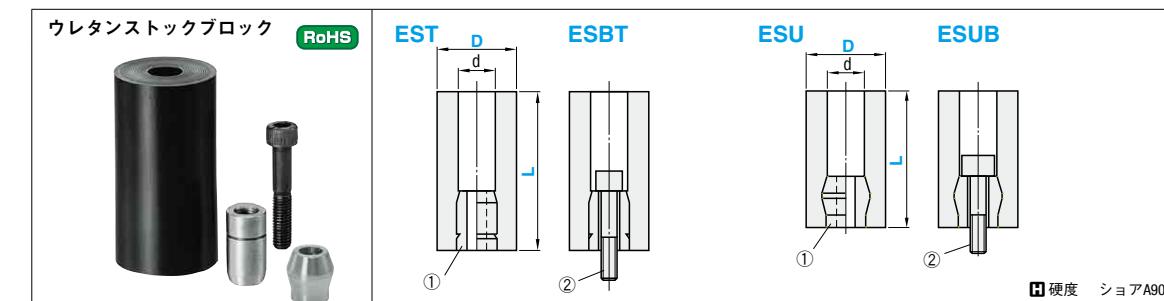

d	ウレタン	①		②	型式		¥基準単価	1~9本	Order 注文例	型式
		EST-ESBT	ESU-ESUB		Type	D-L	EST-ESU	ESBT-ESUB		
14	E40-80	S14	SU14	CB8-45 (1本)	EST ESBT *ESU *ESUB	*40-80	710	720	EST 40-80	EST 40-80
	E50-110					50-110	1,350	1,360		
	E70-140					70-140	2,890	2,900		
22	E7022110	S22	SU22	CB12-55 (1本)	EST ESBT *ESU *ESUB	*7022110	2,390	2,420	在庫品 翌日出荷 P.39	在庫品 翌日出荷 P.39
	E7022140					*7022140	2,930	2,960		
	E90-120					90-120	3,730	3,860		
	E90-140					*90-140	4,330	4,360		
	E100-140					100-140	6,770	6,800		
	E100-140									

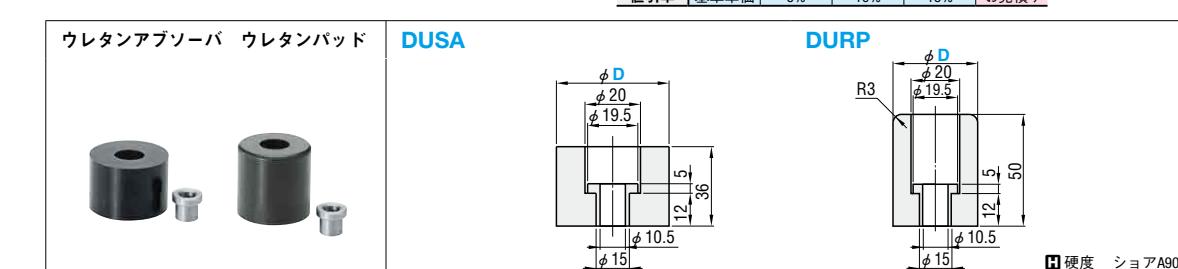

型式		¥ 基準単価	Order 注文例	型式	Delivery 出荷日	在庫品	翌日出荷	P.3
Type	D	1 ~ 9本						
DUSA	50	550	 <b>DUSA 50</b>					
	70	900						
DURP	40	740						
	50	1,060	<b>Price 価格</b>					

