


WASHERS・SPACERS
ワッシャ・スペーサ

RoHS10



K・W (内ネジ式ストリッパボルト用スペーサ)

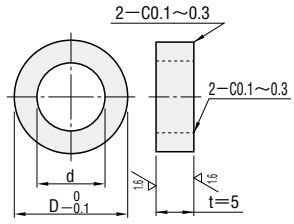


2-C0.1~0.3
2-C0.1~0.3
t=5
D-0.1
d
1/8
1/8

材質 S45C
硬度 48~52HRC

RoHS10



T・R (ブッシュ式ストリッパボルト用スペーサ)

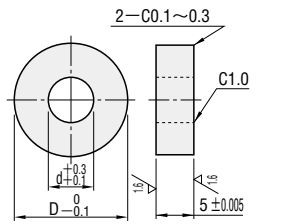


2-C0.1~0.3
C1.0
D-0.1
d
1/8
1/8
5±0.005

材質 S45C
硬度 48~52HRC

RoHS10



J (ブッシュ式ストリッパボルト用ザグリ付スペーサ)

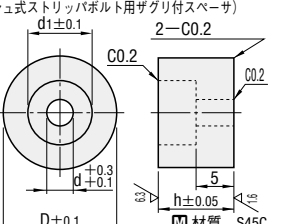


2-C0.2
C0.2
D±0.1
d±0.1
h±0.05
t
1/8
1/8

材質 S45C
硬度 48~52HRC

RoHS10



SW (ストリッパボルト用・コイルスプリング用ワッシャ)

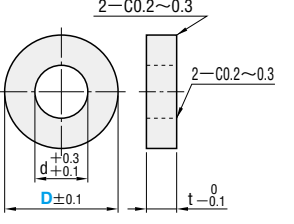

2-C0.2~0.3
2-C0.2~0.3
D±0.1
d±0.1
t-0.1

材質 S45C
硬度 48~52HRC

t	D	d	型式	
±0.005	10	6	K	10
	13	8		13
	16	10		16
	20	12		20
±0.01	8	5	W	10
	11	6		13
	14	8		16
	17	10		20

D	d	型式	
11.5	4	T	6.5
13	5		8
15	6		10
18	8		13
21	10		16
23	12		20
16	4	R	6.5—16
18			6.5—18
18	5		8—18
20			8—20
22			8—22
20			10—20
22	6		10—22
25			10—25
27			10—27
25			13—25
27	8		13—27
30			13—30
30			16—30
35	10		16—35
40			16—40
35			20—35
40	12		20—40


D	d ₁	d	h	型式	
12	8	4	9	J	6.5
14	10	5	10		8
18	11	6	11		10
24	14	8	13		13
27	17.5	10	15		16
32	19.5	12	17		20

D	d	t	型式	
10	4.5	3	SW	10
12	5.5			12
	6			12—6
16	6.5	4		16
20	8	5		20
22	10			22
25				25
27	12			25—12
	13	8		27
30				30
35				35
40	16			40
50		20		10

RoHS10



SRW (ストリッパガイドピン用ワッシャ)

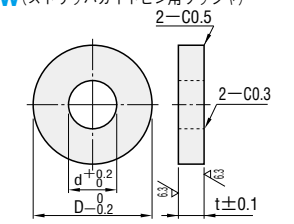


2-C0.5
2-C0.3
d+0.2
D-0.2
t±0.1
1/8
1/8

材質 SS400

RoHS10



WSS (長円穴用ワッシャ)

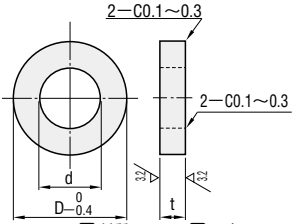


2-C0.1~0.3
2-C0.1~0.3
d
D-0.4
t
1/8
1/8

材質 S45C
硬度 23~30HRC

RoHS10



MSRB (MSB用スペーサ)

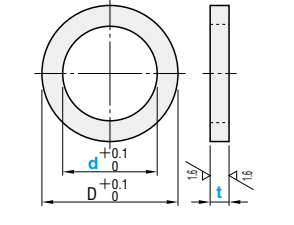


D-0.1
d
t
1/8
1/8

材質 SK5

RoHS10



LRB (ガイドリフタ・リフタピン用スペーサ)

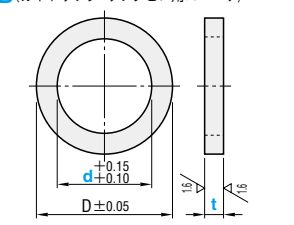


D±0.05
d+0.15
d+0.10
t
1/8
1/8

材質 SK5

RoHS10



SBW (プレッシャーピン・吊りカラ-用ワッシャ)

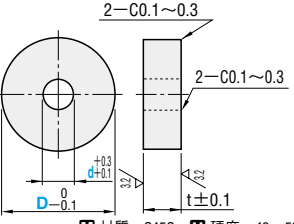

2-C0.1~0.3
2-C0.1~0.3
d+0.3
D-0.1
t±0.1
1/8
1/8

材質 S45C
硬度 48~52HRC

D	d	t	型式	
12	5.3	3	SRW	8
15				10
19				13
22	6.4	4		16
26				20
30				25

D		d 		t 		型式			
12.5	6.4	+0.25 0	2.5	±0.25	WSS	6			
17	8.4					8			
21	10.5	+0.3 0	3	±0.3		10			
24	13					4	±0.4	12	
30	17							16	
37	21	5	±0.5	20					

t	D	d	型式		t
0.1	6.5	4	MSRB	*4	0.1 0.2 0.3 0.5 1.0 2.0
0.2	7	4.5		4.5	
0.3	8	5		*5	
0.5	9	5.5		5.5	
1.0	9	6		*6	
2.0	10	6.5		6.5	
	13	8		8	
	16	10		10	
	17	12		*12	
	18	13		13	
	24	16		16	
	27	20		20	

*の付いたサイズにt=2.0はありません。

t	D	d	型式		t
0.1	6	4	LRB	4	0.1 0.2 0.3 0.5 1.0
0.2	7	5		5	
0.3	8	6		6	
0.5	10	8		8	
1.0	13	10		10	
	16	13		13	
	19	16		16	
	23	20		20	

t	型式		d
	Type	D	
5	SBW	20	5
		22	5
		25	6
7		27	5
		30	6
		35	8

Order 注文例


型式

K 10
W 16
T 10
R 10-20
J 16
SW 25

Delivery 出荷日

在庫品

Example 使用例

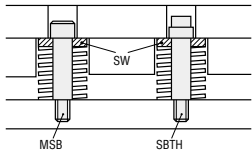

Order 注文例

型式

SRW 20
WSS 8

MSRB・LRB

型式

MSRB 10
LRB 8

型式

SBW 20

t

0.1
0.5

d

5

Delivery 出荷日

在庫品