


RoHS10




CS15W (銅合金タイプ)

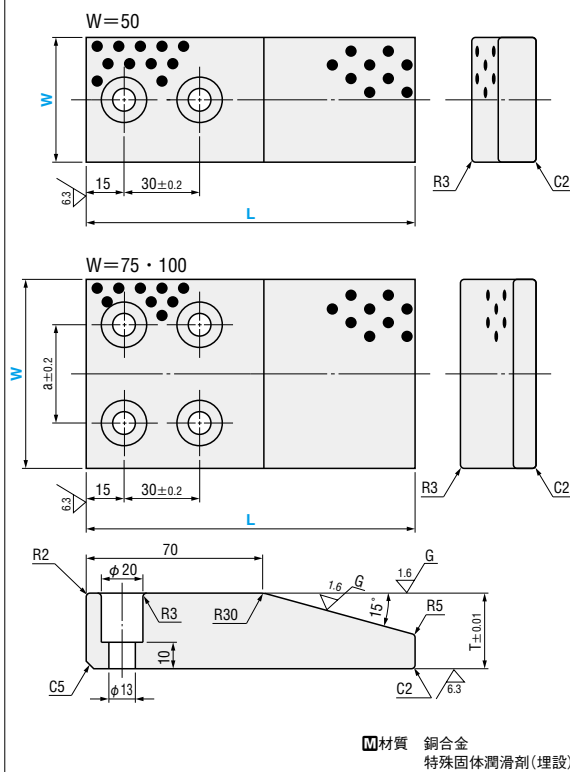

CS15F (スチールタイプ)

CS15FN (スチールタイプ 油溝無し)

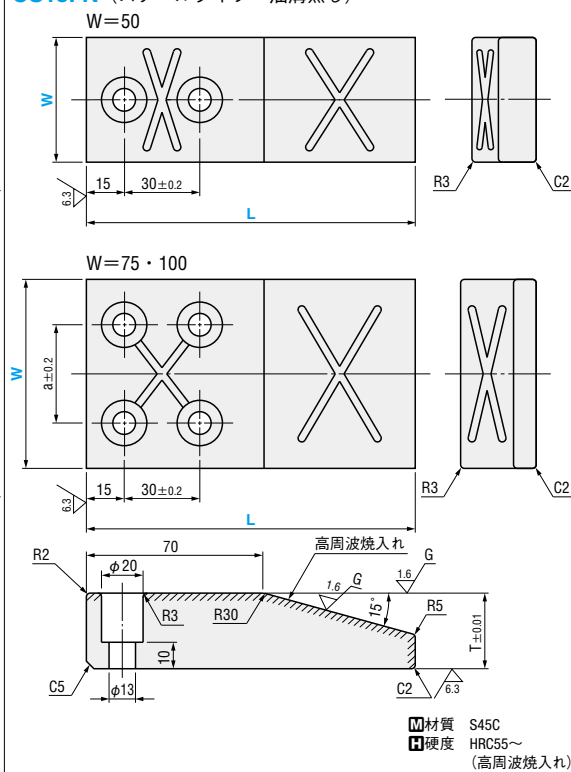


T	a	型式	W	L
25	—	CS15W CS15F CS15FN	50	110
30				130
35				150
25	40		75	110
30				130
35				150
25	60		100	110
30				130
35				150


Order 注文例
型式 CS15W W 50 L 110

Delivery 出荷日 在庫品


EX Example 使用例

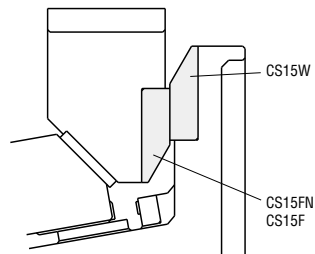

RoHS10

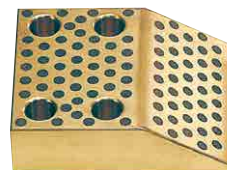


CS30W (銅合金タイプ)

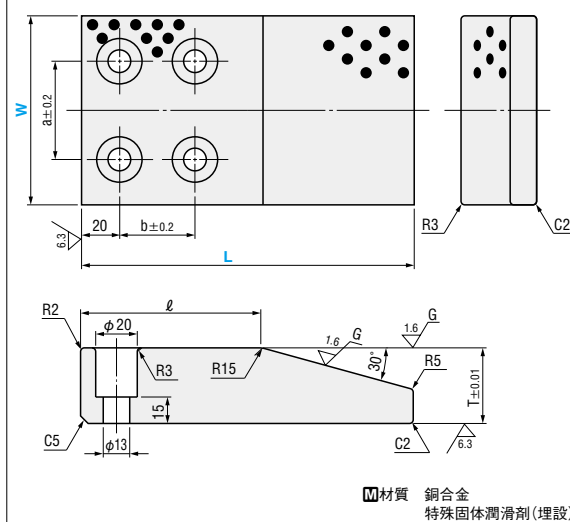


CS30F (スチールタイプ)

CS30FN (スチールタイプ 油溝無し)

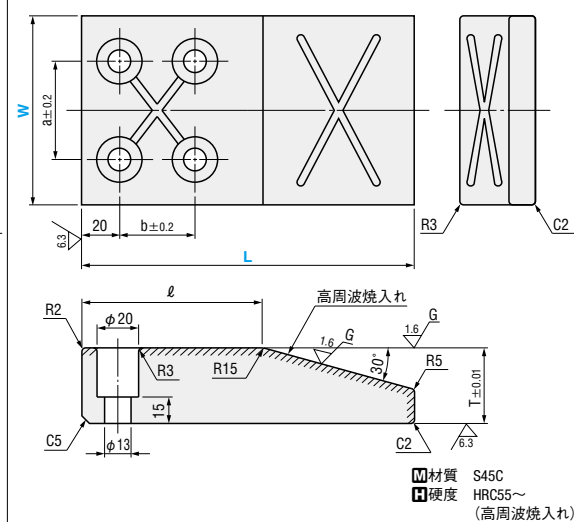

SPCSP

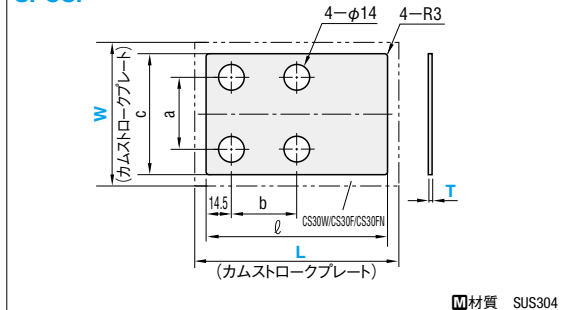


カムストロークプレート用シム

c	ℓ	a	b	型式	W	L	板厚 T
65	120	40	50	SPCSP	75	130	0.05 0.1
	140		45			150	
90	120	60	50		100	130	
	140		45			150	
115	120	85	50		125	130	
	140		45			150	
140	120	110	50		150	130	
	140		45			150	

Order 注文例
型式 CS30W W 100 L 200
SPCSP 75 130 0.1

Delivery 出荷日 在庫品

EX Example 使用例

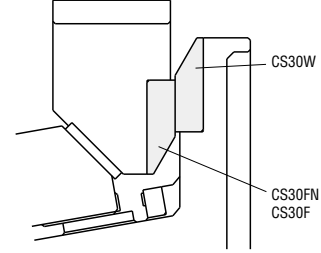

T	ℓ	a	b	型式	W	L
30	95	40	50	CS30W CS30F CS30FN	75	130
45	90		45			150
60						170
	120		75			200
30	95	60	50		100	130
45	90		45			150
60						120
						200
30	95	85	50		125	130
45	90		45			150
60						120
						200
30	95	110	50	150	130	
45	90		45		150	
60					120	75
					200	