


■ガススプリング用プレート一覧

固定方法	型式	ページ	適用ガススプリング							
			GSV	GST	GSH	GSK	GSSC	GSU		
下溝固定	FT	P.1604	38	500	500	—	250	1000	—	
			45	750	750	—	500	—	—	
			50	1000	—	1000	1800	—	—	
			63	1500	—	1500	—	3000	—	
			75	2400	—	2400	1500	4700	—	
			95	4200	—	4200	3000	7500	—	
			120	6600	—	6600	5000	12000	—	
	150	9500	—	—	—	18500	—			
	FTP	P.1604	38	500	500	—	250	1000	—	
			45	750	750	—	500	—	—	
			50	1000	—	1000	1800	—	—	
			63	1500	—	1500	—	3000	—	
			75	2400	—	2400	1500	4700	—	
			95	4200	—	4200	3000	7500	—	
			120	6600	—	6600	5000	12000	—	
	150	9500	—	—	—	18500	—			
	下溝固定	FFC	P.1605	32	350	350	—	150	750	300
				38	500	500	—	250	1000	—
45				750	750	—	500	—	—	
50				1000	—	1000	1800	—	—	
63				1500	—	1500	—	3000	—	
75				2400	—	2400	1500	4700	—	
95				4200	—	4200	3000	7500	—	
120		6600	—	6600	5000	12000	—			
150		9500	—	—	—	18500	—			
FFCA		P.1605	32	350	350	—	150	750	300	
	38		500	500	—	250	1000	—		
	45		750	750	—	500	—	—		
	50		1000	—	1000	1800	—	—		
	63		1500	—	1500	—	3000	—		
	75		2400	—	2400	1500	4700	—		
	95		4200	—	4200	3000	7500	—		
120	6600	—	6600	5000	12000	—				
150	9500	—	—	—	18500	—				
FFCB	P.1605	1500	—	1500	—	3000	—			
		170	—	—	—	—	—			
		320	—	—	—	—	—			
		FFS	P.1606	50	—	1000	—	—	—	
				63	—	1500	—	—	—	
				75	—	2400	—	—	—	
				95	—	4200	—	—	—	
120	—	6600	—	—	—					
150	—	9500	—	—	—					
上溝固定	FCC	P.1607	12	—	—	—	—	50		
			15	—	—	—	—	70		
			19	170	—	—	—	90		
			25	320	—	—	—	400	200	
			19	170	—	—	—	90		
			25	320	—	—	—	400	200	
			32	350	350	—	150	750	300	
	FC	P.1607	38	500	500	—	250	1000	—	
			45	750	750	—	500	—	—	
			50	1000	1000	1000	750	—	—	
			63	1500	1500	1500	—	—	—	
			75	2400	2400	2400	1500	—	—	
			95	4200	4200	4200	3000	—	—	
			120	6600	6600	6600	5000	12000	—	
	150	9500	9500	—	—	18500	—			
	上溝固定	FCB	P.1607	50	—	—	—	—	1800	—
				63	—	—	—	—	3000	—
				75	—	—	—	—	4700	—
95				—	—	—	—	7500	—	
32				350	350	—	150	750	300	
38				500	500	—	250	1000	—	
45				750	750	—	500	—	—	
FCQ		P.1608	50	1000	1000	1000	750	—	—	
			63	1500	1500	1500	—	—	—	
			75	2400	2400	2400	1500	—	—	
			95	4200	4200	4200	3000	—	—	
			120	6600	6600	6600	5000	12000	—	
			9500	9500	—	—	18500	—		
			12000	—	—	—	—	—		
FCQB		P.1608	50	—	—	—	—	1800	—	
			63	—	—	—	—	3000	—	
			75	—	—	—	—	4700	—	
			95	—	—	—	—	7500	—	
	FB		P.1609	45	750	750	—	500	—	—
				50	1000	1500	1000	750	—	—
				75	2400	—	2400	1500	4700	—
95		4200		—	4200	3000	—	—		
120		6600		6600	6600	5000	—	—		
9500		9500		—	—	—	—			
12000		—		—	—	—	—			
FBA	P.1609	45	750	750	—	500	—	—		
		50	1000	1500	1000	750	—	—		
		75	2400	—	2400	1500	4700	—		
		95	4200	—	4200	3000	—	—		
		120	6600	6600	6600	5000	—	—		
		9500	9500	—	—	—	—			
		12000	—	—	—	—	—			
FBB	P.1610	45	750	750	—	500	—	—		
		50	1000	1500	1000	750	—	—		
		63	1500	1500	1500	—	—	—		
		75	2400	—	2400	1500	4700	—		
		95	4200	—	4200	3000	—	—		
		120	6600	6600	6600	5000	—	—		
		9500	9500	—	—	—	—			
12000	—	—	—	—	—					
横置き	FSA	P.1611	32	350	350	—	150	750	300	
			38	500	500	—	250	1000	—	
			45	750	750	—	500	—	—	
			50	1000	1000	1000	750	1800	—	
			75	2400	2400	2400	1500	4700	—	
			95	4200	4200	4200	3000	7500	—	
			120	6600	6600	6600	5000	12000	—	
	FSD	P.1611	63	1500	1500	1500	—	3000	—	
			75	2400	2400	2400	1500	4700	—	
			95	4200	4200	4200	3000	7500	—	
FSC	P.1611	32	350	350	—	150	750	300		
		38	500	500	—	250	1000	—		
		45	750	750	—	500	—	—		
		50	1000	1000	1000	750	1800	—		
		63	1500	1500	1500	—	3000	—		
		75	2400	2400	2400	1500	4700	—		
		95	4200	4200	4200	3000	7500	—		
120	6600	6600	6600	5000	12000	—				
150	9500	9500	—	—	18500	—				

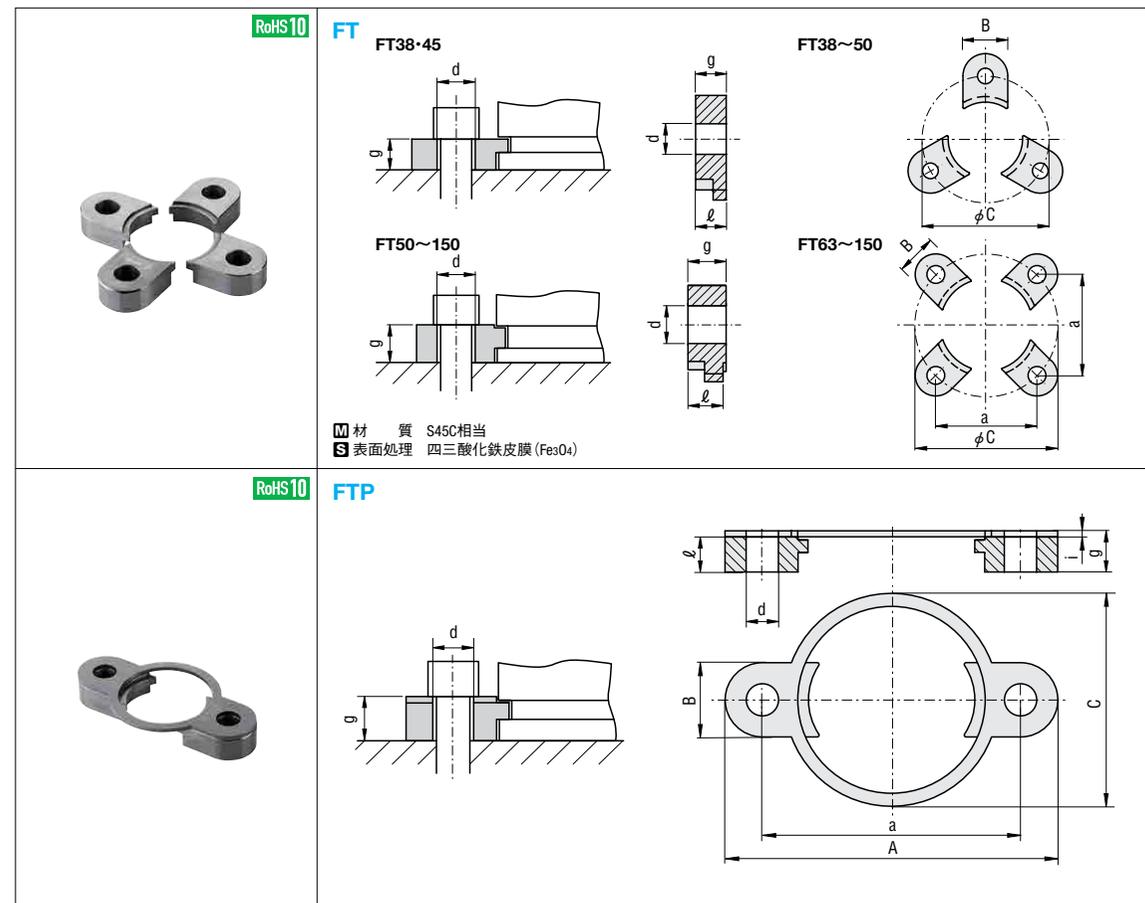

a	B	C	d	g	ℓ	型式	適用ガススプリング						推奨ボルト 3本 or 4本		
							GSV	GST	GSH	GSK	GSSC	GSU			
—	20	56.6	7	7	7	FT	38	500	500	—	250	1000	—	CB 6-16	
50	25	70.7	9	7	7		45	750	750	—	500	—	—	CB 8-20	
56.5	30	80	13	14.2	13		50	1000	—	1000	750	1800	—	CB12-35	
65	30	92	13	14.2	13		63	1500	—	1500	—	3000	—	CB12-35	
73.5	30	104	13	14.2	13		75	2400	—	2400	1500	4700	—	CB12-35	
92	40	130	17	14.2	13		95	4200	—	4200	3000	7500	—	CB16-40	
109.5	50	155	17	14.2	13		120	6600	—	6600	5000	12000	—	CB16-40	
138	50	195	21	14.2	13		9500	9500	—	—	—	18500	—	—	CB20-45
							12000	—	—	—	—	—	—	—	—

A	a	B	C	g	d	i	ℓ	型式	適用ガススプリング						推奨ボルト 2本		
									GSV	GST	GSH	GSK	GSSC	GSU			
76.6	56.6	20	48	9.5	7	2.5	7	FTP	38	500	500	—	250	1000	—	CB 6-20	
95.7	70.7	25	56	9.5	9	2.5	7		45	750	750	—	500	—	—	CB 8-22	
110	80.0	30	61	16.7	13	2.5	14.2		50	1000	—	1000	750	1800	—	CB12-35	
122	92	30	73	16.7	13	2.5	14.2		63	1500	—	1500	—	3000	—	CB12-35	
134	104.0	30	86	16.7	13	2.5	14.2		75	2400	—	2400	1500	4700	—	CB12-35	
170	130	40	106	16.7	17	2.5	14.2		95	4200	—	4200	3000	7500	—	CB16-45	
205	155.0	50	131	16.7	17	2.5	14.2		120	6600	—	6600	5000	12000	—	CB16-45	
245	195	50	170	16.7	21	2.5	14.2		9500	9500	—	—	—	18500	—	—	CB20-50
									12000	—	—	—	—	—	—	—	—



型式
FT45
FTP63



MiSUMI-VONAにてお見積りください。
(http://ec.misumi.jp)