


PLATES FOR GAS SPRINGS ガススプリング用プレート -上溝固定タイプ-

RoHS10



FCC **FC19-25**

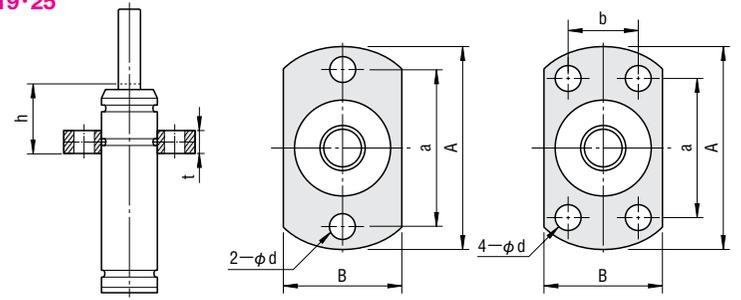


材 質 S45C相当
表面処理 四三酸化鉄皮膜 (Fe₃O₄)

RoHS10



FC32・38・45・50・63・75・95・120・150
FCB

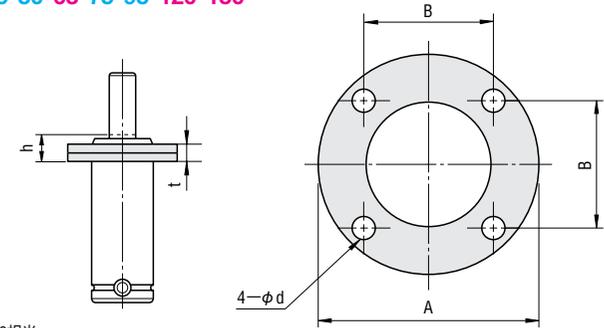

材 質 S45C相当
表面処理 四三酸化鉄皮膜 (Fe₃O₄)

A	a	B	d	t	h			型式	適用ガススプリング						推奨ボルト 2本	
					GSV	GSSC	GSU		GSV	GST	GSH	GSK	GSSC	GSU		
34	24	21	6.6	9	-	-	21.5	FCC	12	-	-	-	-	-	50	CB6-18
37	27	24	6.6	9	-	-	21.5		15	-	-	-	-	-	70	CB6-18
44	32	25	6.6	9	21.5	-	21.5		19	170	-	-	-	-	90	CB6-18
50	38	30	6.6	9	21.5	18	21.5		25	320	-	-	-	400	200	CB6-18


A	a	B	b	d	t	h				型式	適用ガススプリング						推奨ボルト 4本	
						GSV	GST	GSK	GSU		GSV	GST	GSH	GSK	GSSC	GSU		
44	30	25	12	6.6	9	21.5	-	-	21.5	FC	19	170	-	-	-	-	90	CB6-18
50	34	30	18	6.6	9	21.5	-	18	21.5		25	320	-	-	-	400	200	CB6-18
60	-	35	-	7	9	17	-	16	15		32	350	350	-	150	750	300	CB6-18
68	-	40	-	7	9	17	-	15	-		38	500	500	-	250	1000	-	CB6-18
86	-	50	-	9	13	23	-	-	-		45	750	750	-	500	-	-	CB8-25
95	-	56.5	-	9	13	24	22	-	-		50	1000	1000 1200	1000	750	-	-	CB8-25
122	-	73.5	-	11	16	27	27	-	-		63	1500	1500	1500	-	-	-	CB10-35
122	-	73.5	-	11	16	29	29	-	-		75	2400	2400	2400	1500	-	-	CB10-35
150	-	92	-	13.5	18	33	33	-	-		95	4200	4200	4200	3000	-	-	CB12-40
175	-	109.5	-	13.5	21	36	36	33	-		120	6600	6600	6600	5000	12000	-	CB12-40
220	-	138	-	17.5	27	41	-	38	-		150	9500 12000	9500	-	-	18500	-	CB16-55

A	B	d	t	h	型式	適用ガススプリング GSSC	推奨ボルト 4本
95	56.5	9.0	13	21	FCB	50	1800
122	73.5	11.0	16	27		63	3000
122	73.5	11.0	16	26		75	4700
150	92.0	13.5	18	30		95	7500

RoHS10



FCQ
FCQB

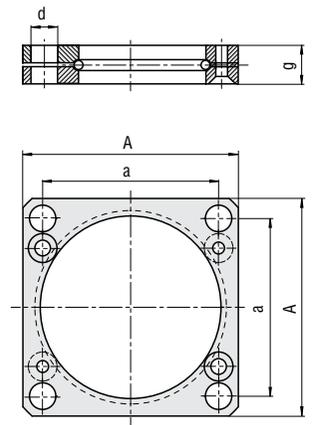

材 質 S45C相当
表面処理 四三酸化鉄皮膜 (Fe₃O₄)

A	a	d	g	型式	適用ガススプリング						推奨ボルト 4本	
					GSV	GST	GSH	GSK	GSSC	GSU		
45	35	6.6	9	FCQ	32	350	350	-	150	750	300	CB 6-18
52	40	6.6	9		38	500	500	-	250	1000	-	CB 6-18
64	50	9	13		45	750	750	-	500	-	-	CB 8-25
70	56.5	9	13		50	1000	1000 2000	1000	750	-	-	CB 8-25
90	73.5	11	16		63	1500	1500	1500	-	-	-	CB10-35
90	73.5	11	16		75	2400	2400	2400	1500	-	-	CB10-35
110	92	13.5	18		95	4200	4200	4200	3000	-	-	CB12-40
130	109.5	13.5	21		120	6600	6600	6600	5000	12000	-	CB12-40
162	138	17.5	27		150	9500 12000	9500	-	-	18500	-	CB16-55
210	170	17.5	27		195	20000	-	-	10000	-	-	CB16-55

A	a	d	g	型式	適用ガススプリング						推奨ボルト 4本	
					GSV	GST	GSH	GSK	GSSC	GSU		
70	56.5	9	13	FCQB	50	-	-	-	-	1800	-	CB 8-25
90	73.5	11	16		63	-	-	-	-	3000	-	CB10-35
90	73.5	11	16		75	-	-	-	-	4700	-	CB10-35
110	92	13.5	18		95	-	-	-	-	7500	-	CB12-40

■上溝固定タイプのプレートは荷重をプレートで受ける事が可能です。
但し、荷重は取付部全面で受けてください。



Order
注文例

型式
FC12
FC38
FCB63
FCQ50
FCQB63



Delivery
出荷日

MISUMI-VONA にてお見積りください。
(<http://ec.misumi.jp>)