


# 低反発座ぐり穴付ウレタン

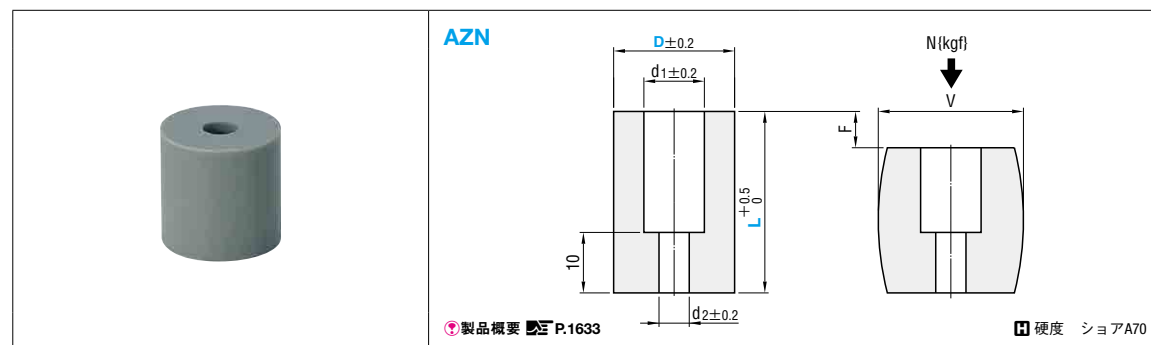

| F=L×10% |           | F=L×15% |           | F=L×20% |           | V  | D  | d1 | d2 | M   | L  | 型式    |       |
|---------|-----------|---------|-----------|---------|-----------|----|----|----|----|-----|----|-------|-------|
| F mm    | 荷重 N(kgf) | F mm    | 荷重 N(kgf) | F mm    | 荷重 N(kgf) |    |    |    |    |     |    | Type  | D - L |
| 2.5     |           | 3.7     |           | 5.0     |           |    |    |    |    |     | 25 | AZN25 | 25    |
| 3.0     | 304       | 4.5     | 442       | 6.0     | 647       | 29 | 25 | 11 | 7  | M6  | 30 |       | 30    |
| 3.5     | {31}      | 5.2     | {45}      | 7.0     | {66}      |    |    |    |    |     | 35 |       | 35    |
| 4.0     |           | 6.0     |           | 8.0     |           |    |    |    |    |     | 40 |       | 40    |
| 3.0     | 362       | 4.5     | 627       | 6.0     | 892       | 35 | 30 | 14 | 9  | M8  | 30 | AZN30 | 30    |
| 3.5     | {37}      | 5.2     | {64}      | 7.0     | {91}      |    |    |    |    |     | 35 |       | 35    |
| 4.0     |           | 6.0     |           | 8.0     |           |    |    |    |    |     | 40 |       | 40    |
| 3.0     | 735       | 4.5     | 1274      | 6.0     | 1814      | 46 | 40 | 18 | 11 | M10 | 30 | AZN40 | 30    |
| 3.5     | {75}      | 5.2     | {130}     | 7.0     | {185}     |    |    |    |    |     | 35 |       | 35    |
| 4.0     |           | 6.0     |           | 8.0     |           |    |    |    |    |     | 40 |       | 40    |
| 3.0     |           | 4.5     |           | 6.0     |           |    |    |    |    |     | 30 | AZN50 | 30    |
| 3.5     | 1117      | 5.2     | 1971      | 7.0     | 2824      | 57 | 50 | 20 | 14 | M12 | 35 |       | 35    |
| 4.0     | {114}     | 6.0     | {201}     | 8.0     | {288}     |    |    |    |    |     | 40 |       | 40    |
| 5.0     |           | 7.5     |           | 10.0    |           |    |    |    |    |     | 50 |       | 50    |

●荷重(kgf)=荷重N×0.101972



Order  
注文例


型式  
AZN 25-30



Delivery  
出荷日

在庫品

# 低反発ウレタンシート/低反発ウレタンダイパッド

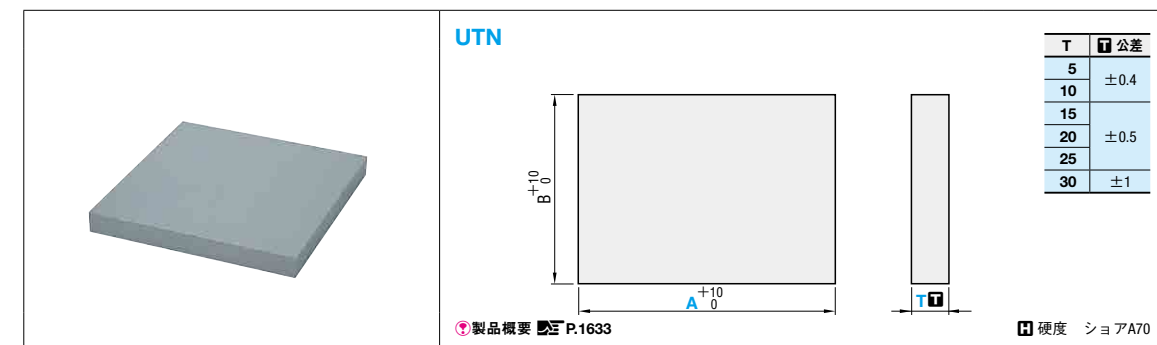

| A   | B   | T  | 型式   |          |
|-----|-----|----|------|----------|
|     |     |    | Type | T - A    |
| 250 | 250 | 5  | UTN  | 5 - 250  |
|     |     | 10 |      | 10 - 250 |
|     |     | 15 |      | 15 - 250 |
|     |     | 20 |      | 20 - 250 |
|     |     | 25 |      | 25 - 250 |
|     |     | 30 |      | 30 - 250 |



Order  
注文例


型式  
UTN 25-250



Delivery  
出荷日

在庫品

| T  | 公差   |
|----|------|
| 5  | ±0.4 |
| 10 |      |
| 15 | ±0.5 |
| 20 |      |
| 25 |      |
| 30 | ±1   |

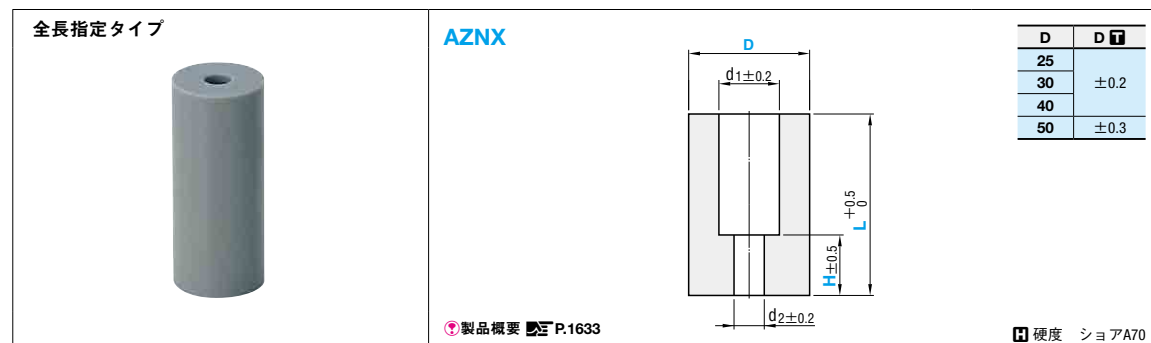

| 型式   |    | L<br>指定1mm単位 | M   | H<br>指定1mm単位 |
|------|----|--------------|-----|--------------|
| Type | D  |              |     |              |
| AZNX | 25 | 20 ~ 60      | M 6 | 5≤H<L        |
|      | 30 |              | M 8 |              |
|      | 40 | 25 ~ 100     | M10 |              |
|      | 50 |              | M12 |              |

| M   | d1 | d2 |
|-----|----|----|
| M 6 | 11 | 7  |
| M 8 | 14 | 9  |
| M10 | 18 | 11 |
| M12 | 20 | 14 |




Order  
注文例

型式 - L - M - H  
AZNX 25 - 42 - M6 - 15



Delivery  
出荷日

3 日目出荷  
ストーク T  
ストーク A

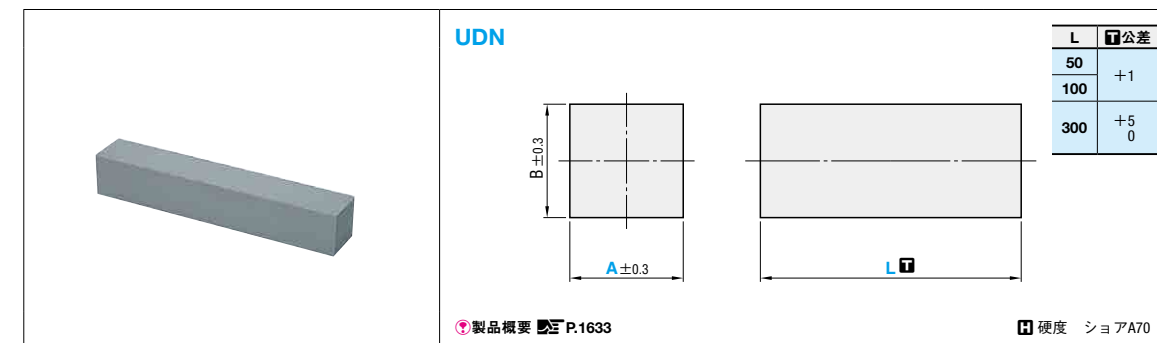

| A  | B  | L   | 型式   |         |
|----|----|-----|------|---------|
|    |    |     | Type | A - L   |
| 25 | 25 | 50  | UDN  | 25 - 50 |
|    |    | 100 |      | 100     |
|    |    | 300 |      | 300     |
| 50 | 50 | 50  | UDN  | 50 - 50 |
|    |    | 100 |      | 100     |
|    |    | 300 |      | 300     |



Order  
注文例

型式  
UDN 25-300



Delivery  
出荷日

在庫品

| L   | 公差   |
|-----|------|
| 50  | ±1   |
| 100 |      |
| 300 | ±5.0 |

ウレタンダイパッド