


ミスミ

T SLOT CUTTERS

Tスロットカッター

●直刃・ショートタイプ -STRAIGHT FLUTE/SHORT-

TSC

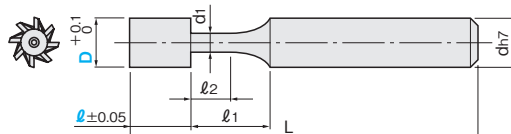

①外周、両サイド共に切れ刃があります。

材質



仕様

型番 **TSC** 1本単位 ○在庫品 ●製作品

刃径 D	刃幅ℓ(選択)																			首径 d1	首長 ℓ1	首長 ℓ2	全長 L	シャンク径 d	刃数 Z
	3	4	5	6	7	8	9	10	11	12	13	14	15	16	17	18	19	20							
8	○	○	●	●	●	●													3.5	8	3	50	8	8	
10	○	○	●	●	●	●	●												4	9	3.5	50	10	8	
11	●	●	●	●	●	●	●	●											4.5	10	3.5	50	10	8	
12	●	●	●	●	●	●	●	●	●										4.5	10	3.5	60	12	8	
13	○	○	●	●	●	●	●	●											5	10	4	60	12	8	
14	●	●	●	●	●	●	●	●	●										5.5	10	4	60	12	8	
15	●	●	●	●	●	●	●	●	●	●	●								6.5	12	5	65	12	8	
16	○	○	○	○	○	○	○	○	○	○	○								6.5	12	6	65	12	8	
18	●	●	●	●	●	●	●	●	●	●	●	●							7.5	12	6	70	12	10	
19	●	●	●	●	●	●	●	●	●	●	●	●							8	12	6	70	12	10	
20	○	○	○	○	○	○	○	○	○	○	○	○							9	12	8	70	12	10	
22	●	●	●	●	●	●	●	●	●	●	●	●							9.5	12	8	70	12	10	
24	●	●	●	●	●	●	●	●	●	●	●	●							10	12	10	70	12	10	
25	○	○	○	○	○	○	○	○	○	○	○	○							10.5	12	10	70	12	10	
													●	●	●				10.5	12	10	80	12	10	
26	●	●	●	●	●	●	●	●	●	●	●	●							10.5	12	10	70	12	10	
													●	●	●				10.5	12	10	80	12	10	
28	●	●	●	●	●	●	●	●	●	●	●	●							11	12	11	70	12	12	
													●	●	●				11	12	11	80	12	12	
30	●	●	●	●	●	●	●	●	●	●	●	●							11	12	11	70	12	12	
													●	●	●				11	12	11	80	12	12	
32	●	●	●	●	●	●	●	●	●	●	●	●							11	12	11	75	12	12	
													●	●	●				11	12	11	80	12	12	
35	●	●	●	●	●	●	●	●	●	●	●	●							11	12	11	75	12	12	
													●	●	●				11	12	11	80	12	12	
36	●	●	●	●	●	●	●	●	●	●	●	●							11	12	11	75	12	12	
													●	●	●				11	12	11	80	12	12	
38	●	●	●	●	●	●	●	●	●	●	●	●							11	12	11	75	12	14	
													●	●	●				11	12	11	80	12	14	
40	●	●	●	●	●	●	●	●	●	●	●	●							15	15	14	85	16	14	
													●	●	●	●	●	●	15	15	14	100	16	14	
45	●	●	●	●	●	●	●	●	●	●	●	●							15	15	14	85	16	14	
													●	●	●	●	●	●	15	15	14	100	16	14	
50	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	15	15	14	100	16	16	
60	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	19	20	19	120	20	18	

Price
価格

■数量スライド価格 (①1円未満切捨て)

数量	1~4	5~9	10~19	20~29	30~
値引率	3%	3%	5%	7%	7%

お見積り

刃径 D	¥通常単価 1~4本	
	刃幅ℓ 3~10	刃幅ℓ 11~20
8	3,110	—
10	2,420	—
11	3,330	—
12	3,430	—
13	2,850	—
14	3,990	—
15	4,060	4,490
16	3,340	4,750
18	4,600	5,060
19	4,750	5,240
20	3,810	5,400
22	5,250	5,790
24	5,950	6,550

刃径 D	¥通常単価 1~4本	
	刃幅ℓ 3~10	刃幅ℓ 11~20
25	5,190	7,350
26	7,280	8,010
28	7,890	8,690
30	8,530	9,390
32	9,760	10,740
35	11,110	12,240
36	12,410	13,680
38	13,740	15,110
40	15,280	16,800
45	18,410	20,260
50	23,380	26,410
60	28,640	31,500

切削条件 P.534

Order
注文例TSC 20-10
型番 刃径(D) 刃幅(ℓ)Delivery
出荷日○在庫品
在庫品 巻末-7

①ご希望によりPM6:00迄、当日出荷受付致します。

●製作品

3 日目出荷

急 ストックA 800円/1本 巻末-8

①同一サイズ3本以上は一律2,160円



WEBならスペック指定で簡単検索

●通常単価・数量スライド単価・出荷日等の最新情報は、ミスミVONAをご参照ください。

ミスミ チップ

