


J-515

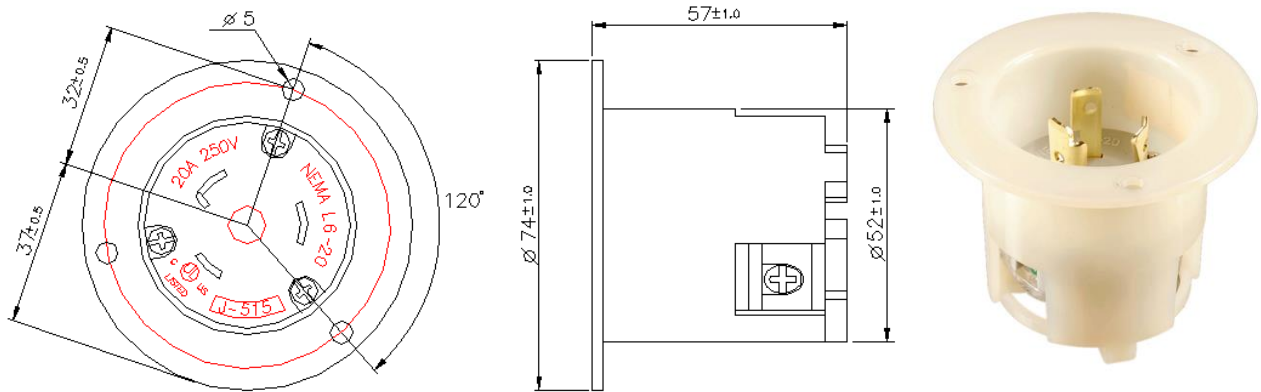

Product Specifications

Product Item	Flanged Inlet
Wiring Scheme	2 Pole, 3 Wire Grounding 20A 250V AC
NEMA Configuration	L6-20
Housing Material	Nylon-Natural
Blade Holder Material	Gray Polycarbonate
Terminal Retainer Material	Clear Polycarbonate
Blade Material	Brass
Terminal Screw Material	#8-32 solid brass
Ground Screw Material	#8-32 solid brass (Green)
Flammability	V-2
Operating Temperatures	Maximum Continuous 75 °C, Minimum -40 °C (w/o impact)
Listings	UL/cUL E237606
RoHS Compliant	Yes