


J-518

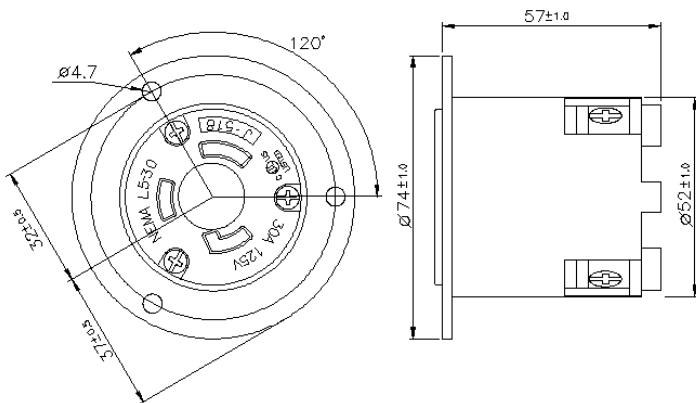

Product Specifications

Product Item	Flanged Outlet
Rating	2 Pole, 3 Wire Grounding 30A 125V AC
NEMA Configuration	L5-30
Housing Material	Nylon-Natural
Contact Holder Material	Gray Polycarbonate
Retainer Material	Clear Polycarbonate
Contact Material	Copper Alloy
Terminal Screw Material	#10-32 solid brass
Ground Screw Material	#10-32 solid brass (Green)
Flammability	V-2
Operating Temperatures	Maximum Continuous 75 °C, Minimum -40 °C (w/o impact)
Listings	UL/cUL E237606
RoHS Compliant	Yes