


J-712

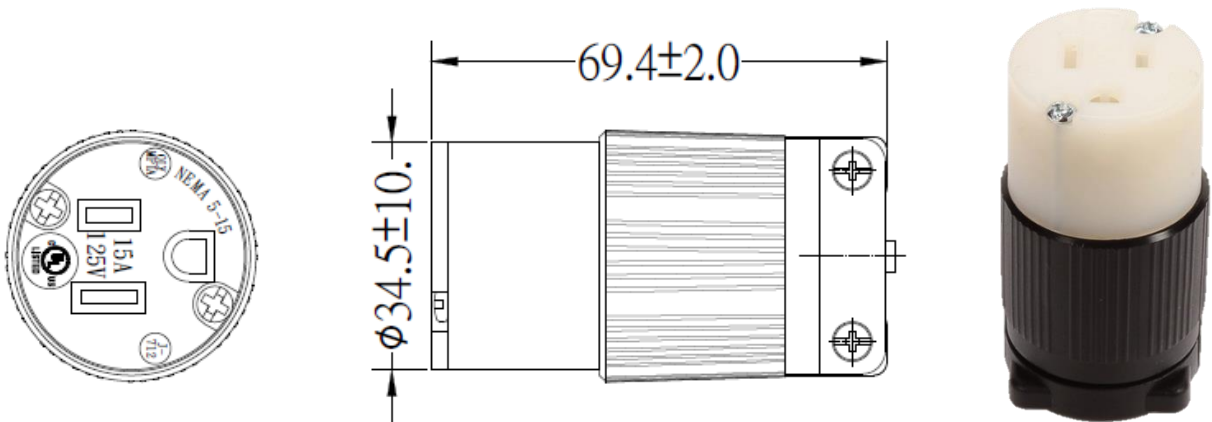

Product Specifications

Product Item	Straight Blade Connector
Rating	2Pole, 3 Wire Grounding 15A 125V AC
NEMA Configuration	5-15
Color	White - Black
Housing Material	Nylon-Black
Contact Holder Material	Natural Nylon
Terminal Retainer Material	Polycarbonate-Clear
Cord Clamp Material	Black Nylon
Contact Material	Copper Alloy
Terminal Screw Material	Brass
Ground Screw Material	Brass (Green)
Flammability	UL 94 V-2
Wire Size	.300" to .480"
Operating Temperatures	Maximum Continuous 75 °C, Minimum -40 °C (w/o impact)
Listings	UL/cUL E237606
RoHS Compliant	Yes