


WJ-6323B

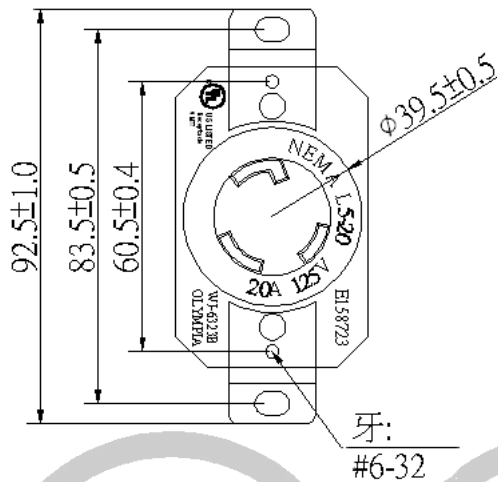

Product Specifications

Product Item	Single Receptacle Locking Type
Rating	2 Pole, 3 Wire Grounding 20A 125V AC
NEMA Configuration	L5-20
Color	Black
Contact Material	Brass
Terminal Screw Material	Brass
Ground Screw Material	Brass (Green)
Cover (Top) Material	P.B.T. (Poly Butylene Terephthalate Resin) 94V-0
Base Material	P.B.T. (Poly Butylene Terephthalate Resin) 94V-0
Operating Temperatures	Maximum Continuous 75°C, Minimum -40°C (w/o impact)
Listings	UL/cUL E158723
RoHS Compliant	Yes