


WJ-8331

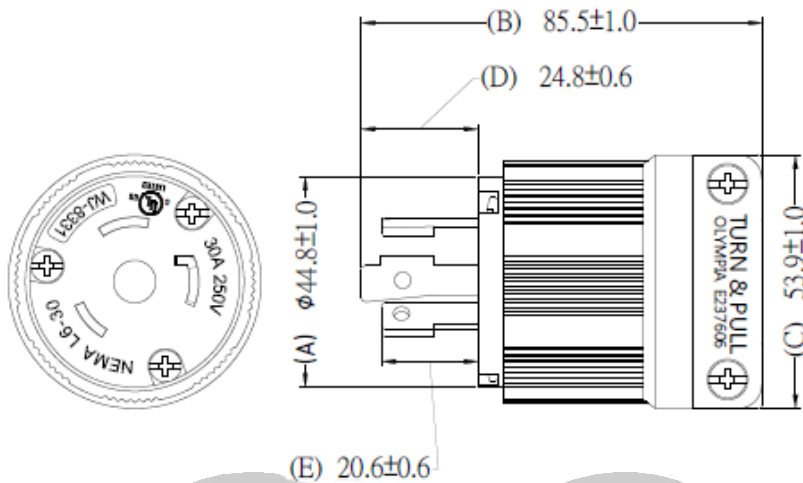

Product Specifications

Product Item	Locking Plug
Rating	2 Pole, 3 Wire Grounding 30A 250V AC
NEMA Configuration	L6-30
Color	Gray - Black
Blade Holder Material	Gray Polycarbonate
Terminal Retainer Material	Clear Polycarbonate
Housing Material	Black Nylon
Cord Clamp Material	Black Nylon
Blade Material	Brass
Terminal Screw Material	Brass
Ground Screw Material	Brass (Green)
Flammability	UL 94 V-0
Wire Size	.375" to 1.156"
Operating Temperatures	Maximum Continuous 75 °C, Minimum -40 °C (w/o impact)
Listings	UL/cUL E237606
RoHS Compliant	Yes

嶸光電器有限公司

Rong Kuang Electric Co., LTD.